

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Neutral Density \(ND\) Filters](#)

Mounted Circular Neutral Density (ND) Filters



- Complete Package
- Smooth Rotation
- Stainless Steel Post is Included

Common Specifications


Physical & Mechanical Properties

Inner Diameter (mm):	8.3	Thickness (mm):	2.00
Parallelism (arcmin):	3.00		

Optical Properties

Angle of Incidence (°):	0.00		
Substrate:	B270	Coating:	Variable
Blocking Wavelength Range (nm):	400 - 700	Optical Density Tolerance (%):	±8
Coating Specification:	Continuously Variable Inconel from 0 - 310°		

Technical Information

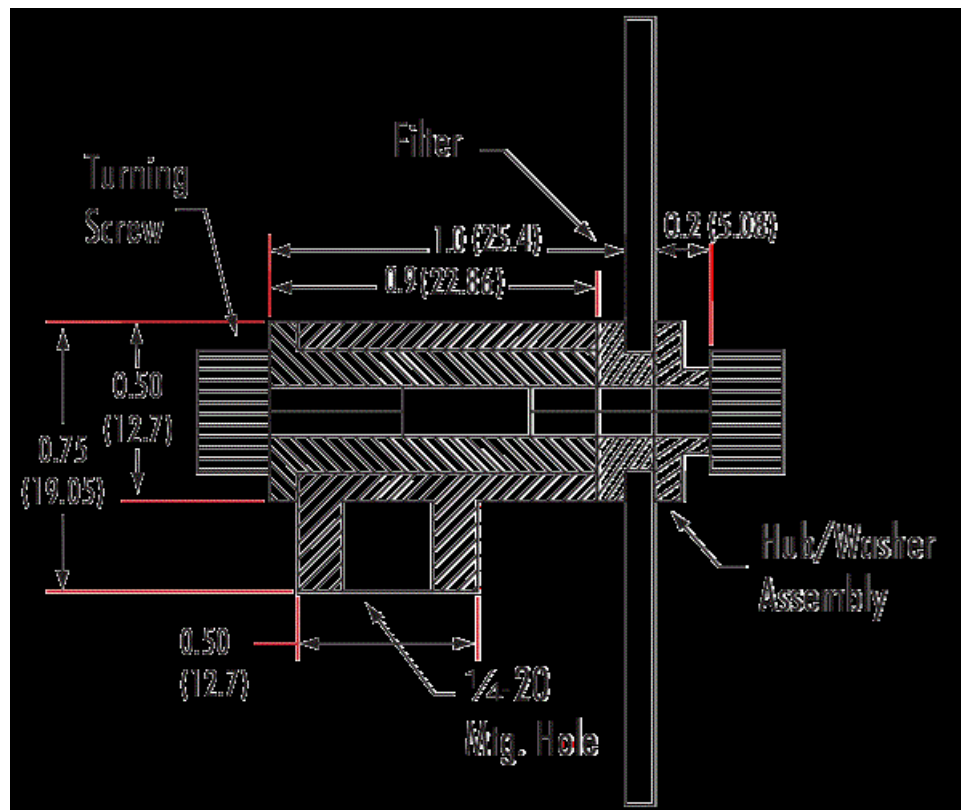

Products

Dia. (mm)	Optical Density OD (Average)	Thickness (mm)	Stock Number	Price	Buy
25.00	0.04 - 1.5	2.00	#54-079	₹27,248 Volume Pricing	1 In Stock
25.00	0.04 - 3.0	2.00	#54-080	₹27,248 Volume Pricing	7 In Stock
60.00	0.04 - 1.5	2.00	#53-212	₹29,583 Volume Pricing	5 In Stock
60.00	0.04 - 3.0	2.00	#54-081	₹29,583 Volume Pricing	Contact Us
100.00	0.04 - 1.5	2.00	#49-086	₹31,919 Volume Pricing	6 In Stock
100.00	0.04 - 4.0	2.00	#54-082	₹31,919 Volume Pricing	4 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com