


[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Specialty Mirrors](#)

Cold Mirrors

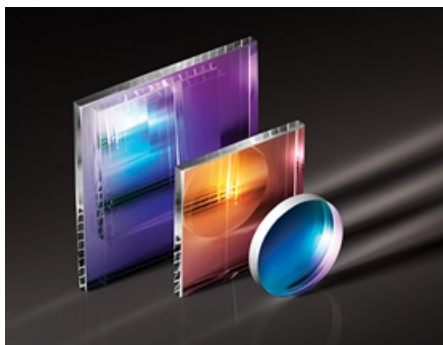



- 0° and 45° Angle of Incidence Options Available
- Reflects 90% of Visible Light
- Transmits 80% of the NIR and IR

Common Specifications

Optical Properties

Substrate: BOROFLOAT®	Surface Quality: 80-50
Wavelength Range (nm): 425 - 1200	Surface Flatness (P-V): 4 - 6λ
Coating Type: Dielectric	

Technical Information

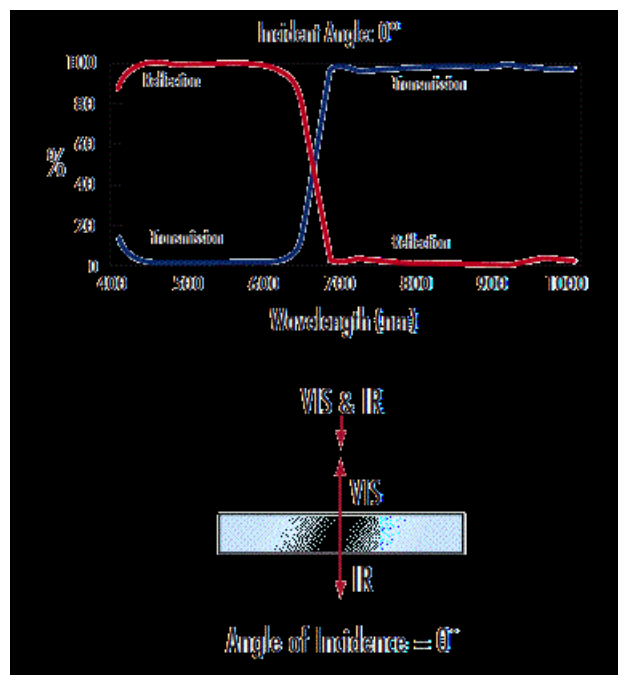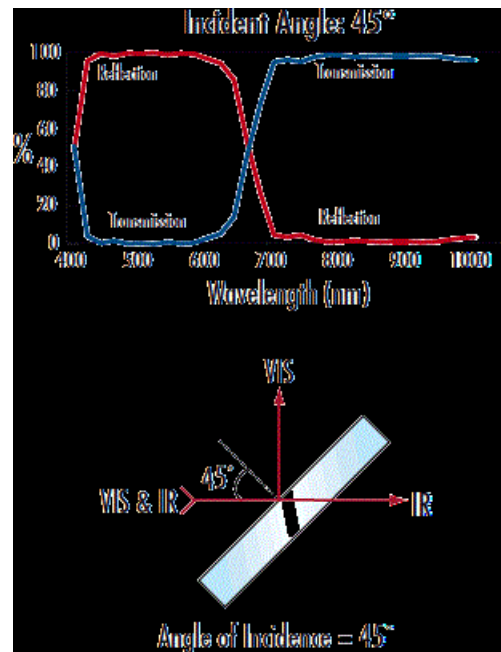

Products

AOI (°)	Dia. (mm)	Dimensions (mm)	Thickness (mm)	Stock Number	Price	Buy
#62-634 Clearance						
						
Clearance						
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.						
45.00	-	12.5 x 12.5	1.10		₹985	20+ In Stock
#43-844 Clearance						
						
Clearance						
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.						
0.00	25.00	-	3.30		₹1,256	20+ In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com