

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

Traditional Coated 193 – 399nm Bandpass Interference Filters



- Available in UV, Visible, and IR Center Wavelengths
- 10 – 80nm Bandwidths Available
- Ideal for Biomedical Applications and Instrumentation Integration
- 193-399nm, [400-699nm](#), and [700-1650nm](#) CWL Options Available

Common Specifications




Physical & Mechanical Properties

Construction:	Mounted in Black Anodized Ring
---------------	--------------------------------

Optical Properties

Angle of Incidence (°):		0	
Coating:		Traditional Coated	
Surface Quality:		80-50	

Technical Information

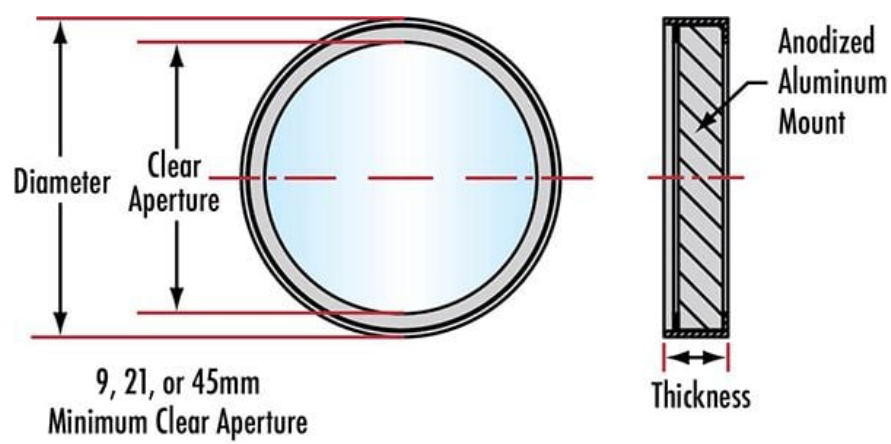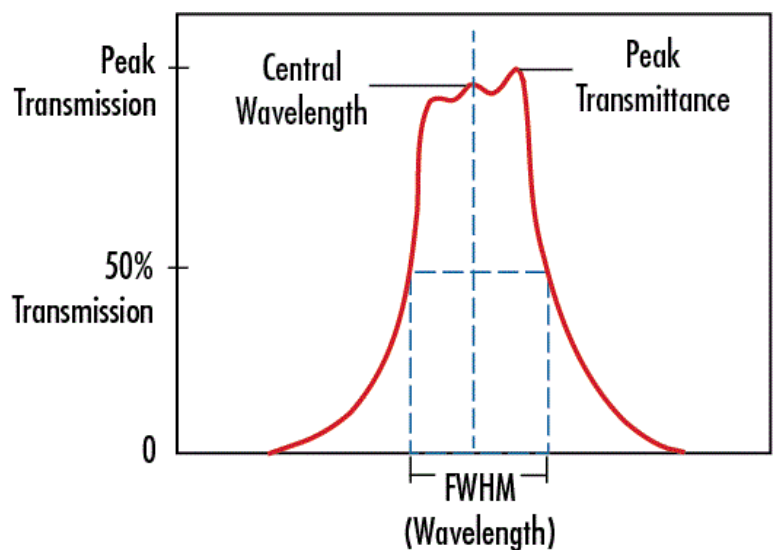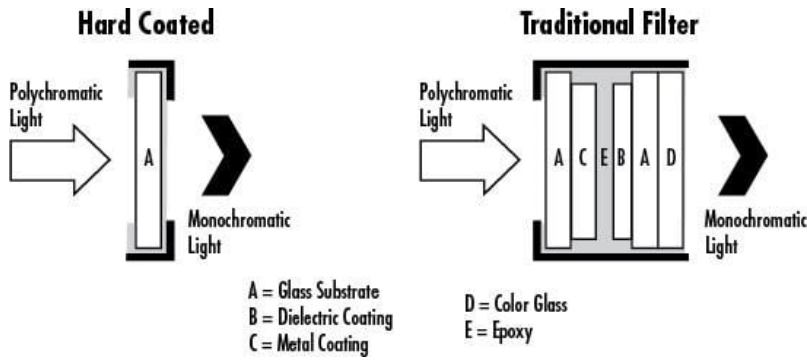

Products

Dia. (mm)	CWL (nm)	FWHM (nm)	Minimum Transmission (%)	Blocking Wavelength Range (nm)	Dimensions (mm)	Stock Number	Price	Buy
12.50	193.00	15.00	>12	200 - 10000	-	#67-732	₹17,127 Volume Pricing	3 In Stock
25.00	193.00	15.00	>12	200 - 10000	-	#67-799	₹26,080 Volume Pricing	4 In Stock
50.00	193.00	15.00	>12	200 - 10000	-	#67-866	₹44,375 Volume Pricing	1 In Stock
12.50	200.00	10.00	>12	200 - 10000	-	#67-733	₹17,127 Volume Pricing	3 In Stock
25.00	200.00	10.00	>12	200 - 10000	-	#67-800	₹26,080 Volume Pricing	3 In Stock
50.00	200.00	10.00	>12	200 - 10000	-	#67-867	₹44,375 Volume Pricing	2 In Stock
12.50	214.00	10.00	>12	200 - 10000	-	#67-734	₹17,127 Volume Pricing	5 In Stock
25.00	214.00	10.00	>12	200 - 10000	-	#67-801	₹26,080 Volume Pricing	2 In Stock
50.00	214.00	10.00	>12	200 - 10000	-	#67-868	₹44,375 Volume Pricing	2 In Stock
12.50	220.00	10.00	>12	200 - 10000	-	#67-735	₹17,127 Volume Pricing	20+ In Stock
25.00	220.00	10.00	12	200 - 10000	-	#67-802	₹26,080 Volume Pricing	9 In Stock
50.00	220.00	10.00	>12	200 - 10000	-	#67-869	₹44,375 Volume Pricing	2 In Stock
12.50	228.00	10.00	>15	200 - 10000	-	#67-736	₹17,127 Volume Pricing	20+ In Stock
25.00	228.00	10.00	>15	200 - 10000	-	#67-803	₹26,080 Volume Pricing	1 In Stock
50.00	228.00	10.00	>15	200 - 10000	-	#67-870	₹44,375 Volume Pricing	2 In Stock
12.50	228.00	25.00	>20	200 - 10000	-	#68-336	₹17,127 Volume Pricing	Contact Us
25.00	228.00	25.00	>20	200 - 10000	-	#68-337	₹26,080 Volume Pricing	3 In Stock
50.00	228.00	25.00	>20	200 - 10000	-	#68-338	₹44,375 Volume Pricing	2 In Stock
12.50	232.00	10.00	>15	200 - 10000	-	#67-737	₹17,127 Volume Pricing	6 In Stock

25.00	232.00	10.00	>15	200 - 10000	-	#67-804	₹26,080 Volume Pricing	2 In Stock
50.00	232.00	10.00	>15	200 - 10000	-	#67-871	₹44,375 Volume Pricing	2 In Stock
12.50	239.00	10.00	>15	200 - 10000	-	#67-738	₹17,127 Volume Pricing	3 In Stock
25.00	239.00	10.00	>15	200 - 10000	-	#67-805	₹26,080 Volume Pricing	1 In Stock
50.00	239.00	10.00	>15	200 - 10000	-	#67-872	₹44,375 Volume Pricing	2 In Stock
12.50	248.00	10.00	>12	200 - 10000	-	#67-739	₹17,127 Volume Pricing	3 In Stock
25.00	248.00	10.00	>12	200 - 10000	-	#67-806	₹26,080 Volume Pricing	2 In Stock
50.00	248.00	10.00	>12	200 - 10000	-	#67-873	₹44,375 Volume Pricing	1 In Stock
12.50	250.00	10.00	>12	200 - 10000	-	#67-740	₹12,612 Volume Pricing	5 In Stock
25.00	250.00	10.00	>12	200 - 10000	-	#67-807	₹21,564 Volume Pricing	1 In Stock
50.00	250.00	10.00	>12	200 - 10000	-	#67-874	₹39,704 Volume Pricing	2 In Stock
12.50	254.00	10.00	>12	200 - 10000	-	#67-741	₹12,612 Volume Pricing	10 In Stock
25.00	254.00	10.00	>12	200 - 10000	-	#67-808	₹21,564 Volume Pricing	3 In Stock
50.00	254.00	10.00	>12	200 - 10000	-	#67-875	₹39,704 Volume Pricing	1 In Stock
12.50	254.00	40.00	>20	200 - 10000	-	#67-742	₹12,612 Volume Pricing	4 In Stock
25.00	254.00	40.00	>20	200 - 10000	-	#67-809	₹21,564 Volume Pricing	2 In Stock
50.00	254.00	40.00	>20	200 - 10000	-	#67-876	₹39,704 Volume Pricing	1 In Stock
12.50	260.00	10.00	>12	200 - 10000	-	#67-743	₹12,612 Volume Pricing	3 In Stock
25.00	260.00	10.00	>12	200 - 10000	-	#67-810	₹21,564 Volume Pricing	3 In Stock
50.00	260.00	10.00	>12	200 - 10000	-	#67-877	₹39,704 Volume Pricing	1 In Stock
12.50	265.00	10.00	>12	200 - 10000	-	#67-744	₹12,612 Volume Pricing	5 In Stock
25.00	265.00	10.00	>12	200 - 10000	-	#67-811	₹21,564 Volume Pricing	6 In Stock

50.00	265.00	10.00	>12	200 - 10000	-	#67-878	₹39,704 Volume Pricing	1 In Stock
12.50	270.00	10.00	>12	200 - 10000	-	#67-745	₹12,612 Volume Pricing	3 In Stock
25.00	270.00	10.00	>12	200 - 10000	-	#67-812	₹21,564 Volume Pricing	1 In Stock
50.00	270.00	10.00	>12	200 - 10000	-	#67-879	₹39,704 Volume Pricing	1 In Stock
12.50	280.00	10.00	>12	200 - 10000	-	#67-746	₹12,612 Volume Pricing	12 In Stock
25.00	280.00	10.00	>12	200 - 10000	-	#67-813	₹21,564 Volume Pricing	2 In Stock
50.00	280.00	10.00	>12	200 - 10000	-	#67-880	₹39,704 Volume Pricing	2 In Stock
12.50	289.00	10.00	>15	200 - 10000	-	#67-747	₹12,612 Volume Pricing	2 In Stock
25.00	289.00	10.00	>15	200 - 10000	-	#67-814	₹21,564 Volume Pricing	Contact Us
50.00	289.00	10.00	>15	200 - 10000	-	#67-881	₹39,704 Volume Pricing	1 In Stock
12.50	297.00	10.00	>15	200 - 10000	-	#67-748	₹12,612 Volume Pricing	3 In Stock
25.00	297.00	10.00	>15	200 - 10000	-	#67-815	₹21,564 Volume Pricing	1 In Stock
50.00	297.00	10.00	>15	200 - 10000	-	#67-882	₹39,704 Volume Pricing	1 In Stock
12.50	300.00	10.00	>15	200 - 10000	-	#67-749	₹12,612 Volume Pricing	3 In Stock
12.50	300.00	40.00	>20	200 - 10000	-	#67-750	₹12,612 Volume Pricing	4 In Stock
25.00	300.00	10.00	>15	200 - 10000	-	#67-816	₹21,564 Volume Pricing	3 In Stock
25.00	300.00	40.00	>20	200 - 10000	-	#67-817	₹21,564 Volume Pricing	2 In Stock
50.00	300.00	10.00	>15	200 - 10000	-	#67-883	₹39,704 Volume Pricing	2 In Stock
50.00	300.00	40.00	>20	200 - 10000	-	#67-884	₹39,704 Volume Pricing	1 In Stock
25.00	320.00	10.00	>25	200 - 10000	-	#67-821	₹21,564 Volume Pricing	3 In Stock
12.50	307.00	10.00	>15	200 - 10000	-	#67-751	₹12,612 Volume Pricing	5 In Stock
25.00	307.00	10.00	>15	200 - 10000	-	#67-818	₹21,564 Volume Pricing	1 In Stock

50.00	307.00	10.00	>15	200 - 10000	-	#67-885	₹39,704 Volume Pricing	2 In Stock
12.50	310.00	10.00	>15	200 - 10000	-	#67-752	₹12,612 Volume Pricing	11 In Stock
25.00	310.00	10.00	>15	200 - 10000	-	#67-819	₹21,564 Volume Pricing	Contact Us
50.00	310.00	10.00	>15	200 - 10000	-	#67-886	₹39,704 Volume Pricing	2 In Stock
12.50	313.00	10.00	>15	200 - 10000	-	#67-753	₹12,612 Volume Pricing	2 In Stock
25.00	313.00	10.00	>15	200 - 10000	-	#67-820	₹21,564 Volume Pricing	1 In Stock
50.00	313.00	10.00	>15	200 - 10000	-	#67-887	₹39,704 Volume Pricing	2 In Stock
12.50	320.00	10.00	>25	200 - 10000	-	#67-754	₹12,612 Volume Pricing	1 In Stock
50.00	320.00	10.00	>25	200 - 10000	-	#67-888	₹39,704 Volume Pricing	1 In Stock
12.50	326.00	10.00	>25	200 - 10000	-	#67-755	₹12,612 Volume Pricing	4 In Stock
25.00	326.00	10.00	>25	200 - 10000	-	#67-822	₹21,564 Volume Pricing	3 In Stock
50.00	326.00	10.00	>25	200 - 10000	-	#67-889	₹39,704 Volume Pricing	Contact Us
12.50	330.00	10.00	>25	200 - 10000	-	#67-756	₹12,612 Volume Pricing	5 In Stock
25.00	330.00	10.00	>25	200 - 10000	-	#67-823	₹21,564 Volume Pricing	Contact Us
50.00	330.00	10.00	>25	200 - 10000	-	#67-890	₹39,704 Volume Pricing	14 In Stock
12.50	350.00	10.00	>25	200 - 10000	-	#67-757	₹12,612 Volume Pricing	2 In Stock
12.50	350.00	40.00	>25	200 - 10000	-	#67-758	₹12,612 Volume Pricing	5 In Stock
25.00	350.00	10.00	>25	200 - 10000	-	#67-824	₹21,564 Volume Pricing	1 In Stock
25.00	350.00	40.00	>25	200 - 10000	-	#67-825	₹21,564 Volume Pricing	3 In Stock
50.00	350.00	10.00	>25	200 - 10000	-	#67-891	₹39,704 Volume Pricing	1 In Stock
50.00	350.00	40.00	>25	200 - 10000	-	#67-892	₹39,704 Volume Pricing	1 In Stock
12.50	355.00	10.00	>25	200 - 10000	-	#67-759	₹12,612 Volume Pricing	3 In Stock

25.00	355.00	10.00	>25	200 - 10000	-	#67-826	₹21,564 Volume Pricing	2 In Stock
50.00	355.00	10.00	>25	200 - 10000	-	#67-893	₹39,704 Volume Pricing	2 In Stock
12.50	360.00	10.00	>25	200 - 10000	-	#67-760	₹12,612 Volume Pricing	5 In Stock
25.00	360.00	10.00	>25	200 - 10000	-	#67-827	₹21,564 Volume Pricing	2 In Stock
50.00	360.00	10.00	>25	200 - 10000	-	#67-894	₹39,704 Volume Pricing	1 In Stock
12.50	370.00	10.00	>25	200 - 10000	-	#67-761	₹12,612 Volume Pricing	5 In Stock
25.00	370.00	10.00	>25	200 - 10000	-	#67-828	₹21,564 Volume Pricing	2 In Stock
50.00	370.00	10.00	>25	200 - 10000	-	#67-895	₹39,704 Volume Pricing	1 In Stock
12.50	380.00	10.00	>25	200 - 10000	-	#67-762	₹12,612 Volume Pricing	3 In Stock
25.00	380.00	10.00	>25	200 - 10000	-	#67-829	₹21,564 Volume Pricing	3 In Stock
50.00	380.00	10.00	>25	200 - 10000	-	#67-896	₹39,704 Volume Pricing	Contact Us
12.50	390.00	10.00	>40	200 - 10000	-	#67-763	₹12,612 Volume Pricing	11 In Stock
25.00	390.00	10.00	>40	200 - 10000	-	#67-830	₹21,564 Volume Pricing	2 In Stock
50.00	390.00	10.00	>40	200 - 10000	-	#67-897	₹39,704 Volume Pricing	1 In Stock
12.50	394.00	10.00	≥30	200 - 1200	-	#65-616	₹12,612 Volume Pricing	3 In Stock
25.00	394.00	10.00	≥30	200 - 1200	-	#65-676	₹21,564 Volume Pricing	5 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com