

[All Products](#) / [Optics](#) / [Prisms](#) / [Specialty Prisms](#)

TECHSPEC® N-BK7 Wedge Prisms



- Ideal for Beam Steering
- 0.5° - 15° Beam Deviation Options
- Available Uncoated or Anti-Reflection Coated
- [Anamorphic Prism Pair](#) Also Available

Common Specifications

General

Note:

Specify this is S1 & S2 power and irregularity, not the overall power of the wedge

Physical & Mechanical Properties

Bevel:

Protective as needed

Optical Properties



Angle Tolerance (arcsec):	±30	Design Wavelength DWL (nm):	632.8
Substrate:	N-BK7	Surface Quality:	20-10
Image Orientation:	Beam Deviation	Power (fringes) @ 632.8nm:	0.50
Irregularity (fringes) @ 632.8nm:	0.20		

Material Properties

 Coefficient of Thermal Expansion CTE ($10^{-6}/^{\circ}\text{C}$):

7.1

Technical Information

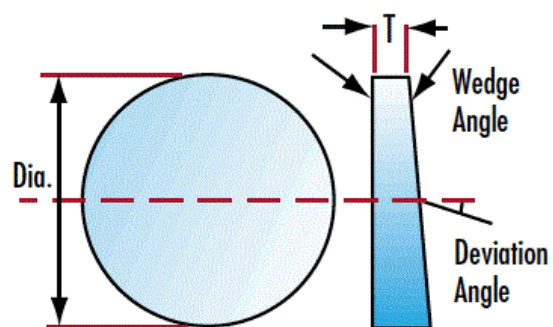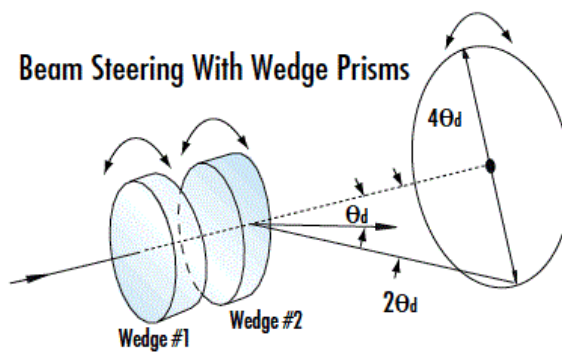

Products

Coating	Dia. (mm)	Thickness (mm)	Power (diopters)	Wedge Angle (°)	Wedge Angle (arcmin)	Stock Number	Price	Buy
Uncoated	12.50	1.50	0.87	0.97°	58	#35-734	₹3,555 Volume Pricing	20+ In Stock
VIS-NIR (400-1000nm)	12.50	1.50	0.87	0.97°	58	#35-794	₹4,725 Volume Pricing	10 In Stock
VIS 0° (425-675nm)	12.50	1.50	0.87	0.97°	58	#35-785	₹4,500 Volume Pricing	9 In Stock
Uncoated	12.50	1.50	1.74	1.93°	1° 56'	#35-735	₹3,555 Volume Pricing	20+ In Stock
VIS-NIR (400-1000nm)	12.50	1.50	1.74	1.93°	1° 56'	#35-795	₹4,725 Volume Pricing	5 In Stock
VIS 0° (425-675nm)	12.50	1.50	1.74	1.93°	1° 56'	#35-786	₹4,500 Volume Pricing	3 In Stock
Uncoated	12.50	1.50	3.49	3.87°	3° 52'	#35-736	₹3,555 Volume Pricing	20+ In Stock
VIS-NIR (400-1000nm)	12.50	1.50	3.49	3.87°	3° 52'	#35-796	₹4,725 Volume Pricing	5 In Stock
VIS 0° (425-675nm)	12.50	1.50	3.49	3.87°	3° 52'	#35-787	₹4,500 Volume Pricing	5 In Stock
Uncoated	12.50	1.50	6.99	7.68°	7° 41'	#35-737	₹3,555 Volume Pricing	3 In Stock
VIS-NIR (400-1000nm)	12.50	1.50	6.99	7.68°	7° 41'	#35-797	₹4,725 Volume Pricing	Contact Us
VIS 0° (425-675nm)	12.50	1.50	6.99	7.68°	7° 41'	#35-788	₹4,500 Volume Pricing	Contact Us
Uncoated	12.50	1.50	10.51	11.35°	11° 21'	#35-738	₹3,555 Volume Pricing	13 In Stock
VIS-NIR (400-1000nm)	12.50	1.50	10.51	11.35°	11° 21'	#35-798	₹4,725 Volume Pricing	5 In Stock

VIS 0° (425-675nm)	12.50	1.50	10.51	11.35°	11° 21'	#35-789	₹4,500 Volume Pricing	Contact Us
Uncoated	12.50	1.50	14.05	14.85°	14° 51'	#35-739	₹3,555 Volume Pricing	11 In Stock
VIS-NIR (400-1000nm)	12.50	1.50	14.05	14.85°	14° 51'	#35-799	₹4,725 Volume Pricing	1 In Stock
VIS 0° (425-675nm)	12.50	1.50	14.05	14.85°	14° 51'	#35-790	₹4,500 Volume Pricing	Contact Us
Uncoated	12.50	1.50	17.63	18.13°	18° 8'	#35-740	₹3,555 Volume Pricing	Contact Us
VIS-NIR (400-1000nm)	12.50	1.50	17.63	18.13°	18° 8'	#35-800	₹4,725 Volume Pricing	1 In Stock
VIS 0° (425-675nm)	12.50	1.50	17.63	18.13°	18° 8'	#35-791	₹4,500 Volume Pricing	Contact Us
Uncoated	12.50	1.50	21.26	21.17°	21° 10'	#35-741	₹3,555 Volume Pricing	7 In Stock
VIS-NIR (400-1000nm)	12.50	1.50	21.26	21.17°	21° 10'	#35-801	₹4,725 Volume Pricing	Contact Us
VIS 0° (425-675nm)	12.50	1.50	21.26	21.17°	21° 10'	#35-792	₹4,500 Volume Pricing	2 In Stock
Uncoated	12.50	1.50	26.79	25.23°	25° 14'	#35-742	₹3,555 Volume Pricing	17 In Stock
VIS-NIR (400-1000nm)	12.50	1.50	26.79	25.23°	25° 14'	#35-802	₹4,725 Volume Pricing	Contact Us
VIS 0° (425-675nm)	12.50	1.50	26.79	25.23°	25° 14'	#35-793	₹4,500 Volume Pricing	5 In Stock
Uncoated	25.00	3.00	0.87	0.97°	0° 58'	#49-436	₹4,500 Volume Pricing	20+ In Stock
VIS-NIR (400-1000nm)	25.00	3.00	0.87	0.97°	0° 58'	#49-437	₹5,670 Volume Pricing	12 In Stock
VIS 0° (425-675nm)	25.00	3.00	0.87	0.97°	0° 58'	#49-438	₹5,445 Volume Pricing	Contact Us
Uncoated	25.00	3.00	1.74	1.93°	1° 56'	#45-555	₹4,500 Volume Pricing	20+ In Stock

VIS-NIR (400-1000nm)	25.00	3.00	1.74	1.93°	1° 56'	#45-558	₹5,670 Volume Pricing	Contact Us
VIS 0° (425-675nm)	25.00	3.00	1.74	1.93°	1° 56'	#49-439	₹5,445 Volume Pricing	7 In Stock
Uncoated	25.00	3.00	3.49	3.87°	3° 52'	#43-651	₹4,500 Volume Pricing	20+ In Stock
VIS-NIR (400-1000nm)	25.00	3.00	3.49	3.87°	3° 52'	#45-559	₹5,670 Volume Pricing	3 In Stock
VIS 0° (425-675nm)	25.00	3.00	3.49	3.87°	3° 52'	#49-440	₹5,445 Volume Pricing	3 In Stock
Uncoated	25.00	3.00	6.99	7.68°	7° 41'	#43-650	₹4,500 Volume Pricing	20+ In Stock
VIS-NIR (400-1000nm)	25.00	3.00	6.99	7.68°	7° 41'	#45-560	₹5,670 Volume Pricing	3 In Stock
VIS 0° (425-675nm)	25.00	3.00	6.99	7.68°	7° 41'	#49-441	₹5,445 Volume Pricing	8 In Stock
Uncoated	25.00	3.00	10.51	11.35°	11° 21'	#45-556	₹4,500 Volume Pricing	20+ In Stock
VIS-NIR (400-1000nm)	25.00	3.00	10.51	11.35°	11° 21'	#45-561	₹5,670 Volume Pricing	8 In Stock
VIS 0° (425-675nm)	25.00	3.00	10.51	11.35°	11° 21'	#49-442	₹5,445 Volume Pricing	10 In Stock
Uncoated	25.00	3.00	14.05	14.85°	14° 51'	#45-401	₹4,500 Volume Pricing	20+ In Stock
VIS-NIR (400-1000nm)	25.00	3.00	14.05	14.85°	14° 51'	#45-562	₹5,670 Volume Pricing	1 In Stock
VIS 0° (425-675nm)	25.00	3.00	14.05	14.85°	14° 51'	#49-443	₹5,445 Volume Pricing	7 In Stock
Uncoated	25.00	3.00	17.63	18.13°	18° 8'	#45-557	₹4,500 Volume Pricing	20+ In Stock
VIS-NIR (400-1000nm)	25.00	3.00	17.63	18.13°	18° 8'	#45-563	₹5,670 Volume Pricing	Contact Us

VIS 0° (425-675nm)	25.00	3.00	17.63	18.13°	18° 8'	#49-444	₹5,445 Volume Pricing	5 In Stock
Uncoated	25.00	3.00	21.26	21.17°	21° 10'	#47-621	₹4,500 Volume Pricing	20+ In Stock
VIS-NIR (400-1000nm)	25.00	3.00	21.26	21.17°	21° 10'	#47-623	₹5,670 Volume Pricing	2 In Stock
VIS 0° (425-675nm)	25.00	3.00	21.26	21.17°	21° 10'	#49-445	₹5,445 Volume Pricing	2 In Stock
Uncoated	25.00	3.00	26.79	25.23°	25° 14'	#47-622	₹4,500 Volume Pricing	20+ In Stock
VIS-NIR (400-1000nm)	25.00	3.00	26.79	25.23°	25° 14'	#47-624	₹5,670 Volume Pricing	20+ In Stock
VIS 0° (425-675nm)	25.00	3.00	26.79	25.23°	25° 14'	#49-446	₹5,445 Volume Pricing	5 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com