


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)

TECHSPEC® 1λ UV Fused Silica Windows

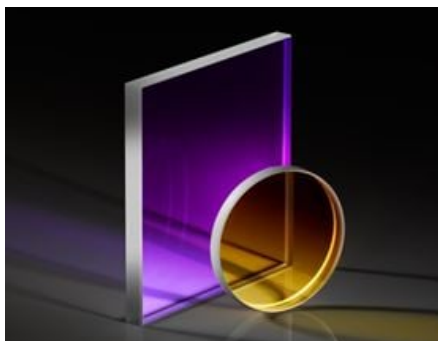

- Available Uncoated or with Broadband Anti-Reflection Coatings
- Ideal for Cost Sensitive Broadband Applications
- Circular and Square Sizes from 5mm to 100mm
- [λ/4](#) or [λ/10](#) UV Fused Silica Windows Also Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	90
Edges:	Fine Ground	Knoop Hardness (kg/mm²):	522.00
Parallelism (arcmin):	<5	Poisson's Ratio:	0.16
Young's Modulus (GPa):	73		


Optical Properties

Abbe Number (v_d):	67.8		
Index of Refraction (n_d):	1.458	Surface Quality:	60-40



Material Properties

Coefficient of Thermal Expansion CTE (10⁻⁶/°C):	0.52 (+5 to +35°C) 0.57 (0 to +200°C) 0.48 (-100 to +200°C)	Density (g/cm³):	2.20
---	---	------------------------------------	------


Technical Information

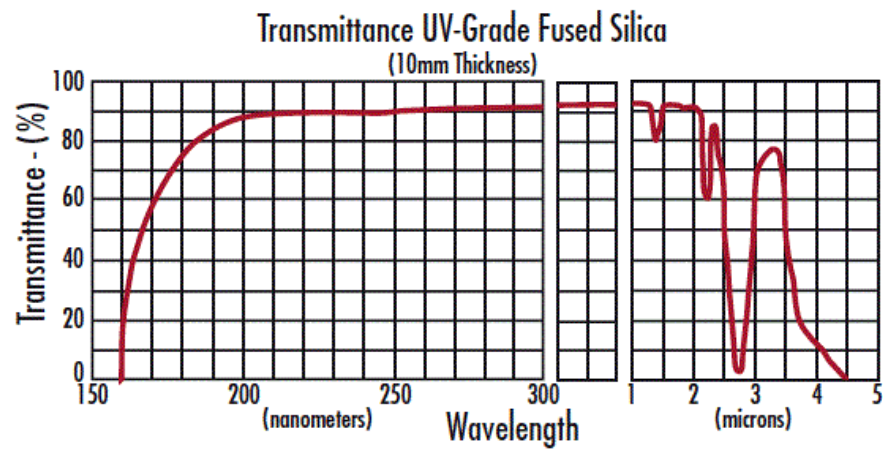


UV FS Transmission Curve

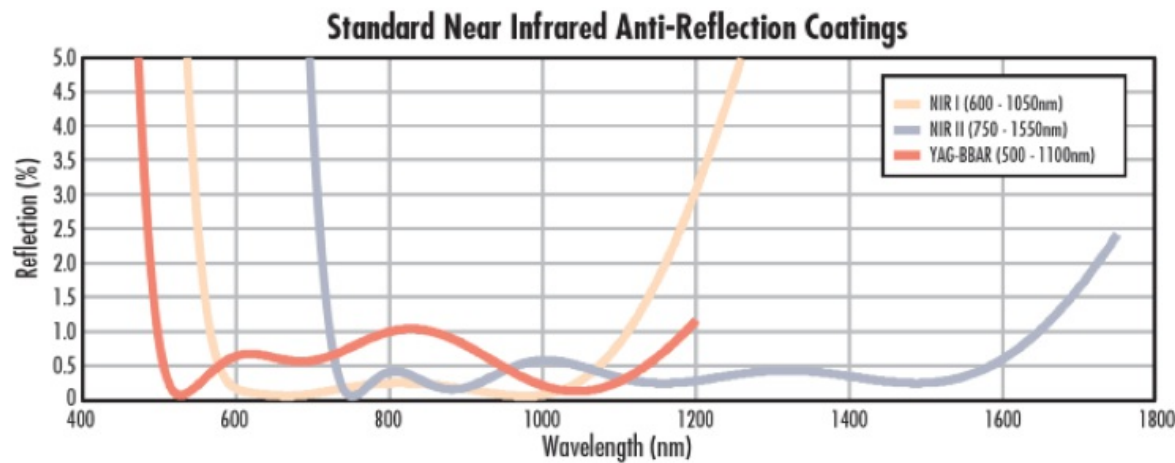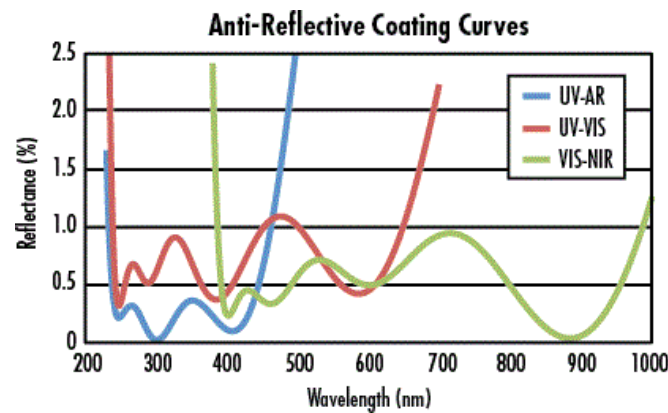

Standard Visible Anti-Reflection Coatings

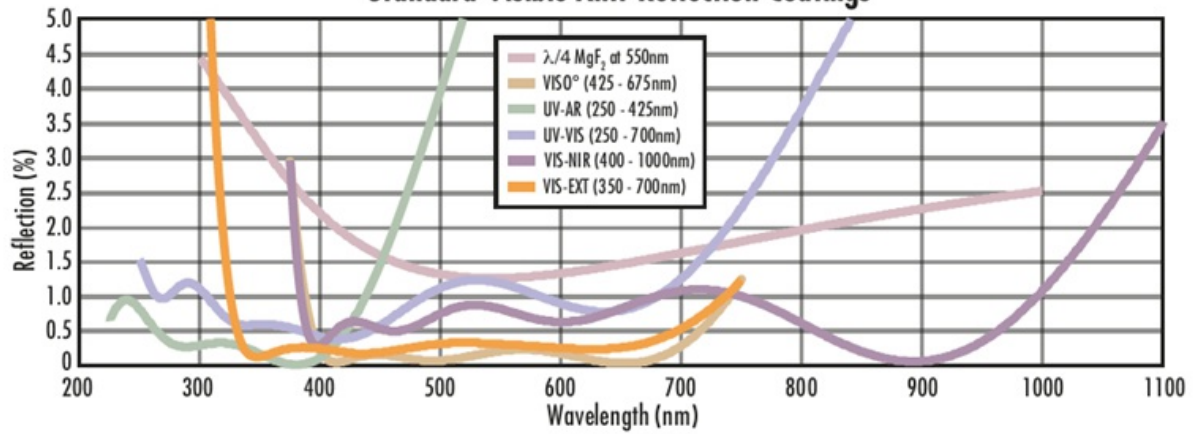

Standard Near Infrared Anti-Reflection Coatings

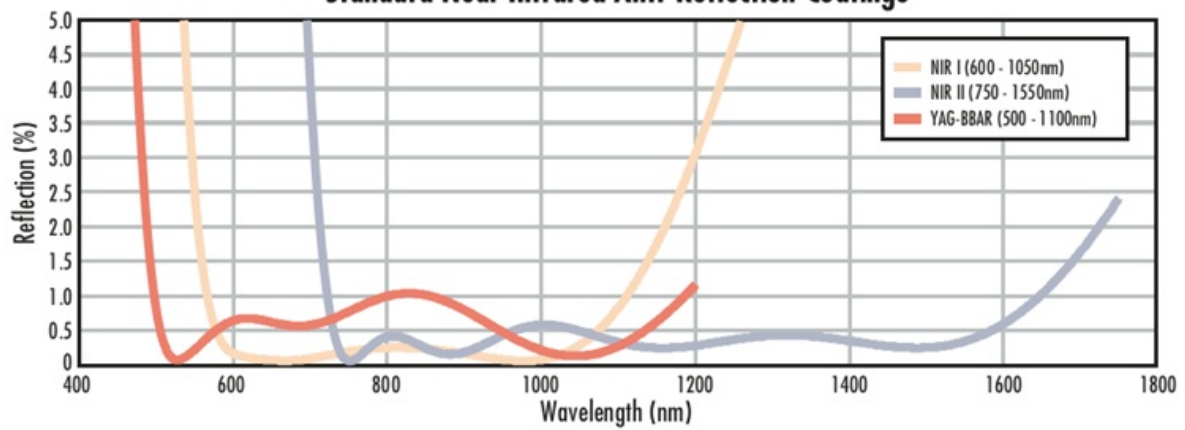

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
5.00	-	1.00	Uncoated	#45-463	₹4,731 Volume Pricing	20+ In Stock
5.00	-	1.00	UV-AR (250-425nm)	#45-807	₹6,638 Volume Pricing	20+ In Stock
5.00	-	1.00	UV-VIS (250-700nm)	#84-469	₹6,638 Volume Pricing	5 In Stock
5.00	-	1.00	VIS-EXT (350-700nm)	#25-184	₹6,858 Volume Pricing	4 In Stock
5.00	-	1.00	MgF ₂ (400-700nm)	#11-917	₹5,685 Volume Pricing	5 In Stock
5.00	-	1.00	VIS 0° (425-675nm)	#36-990	₹6,455 Volume Pricing	20+ In Stock
5.00	-	1.00	VIS-NIR (400-1000nm)	#49-637	₹6,858 Volume Pricing	9 In Stock
5.00	-	1.00	YAG-BBAR (500-1100nm)	#25-213	₹6,858 Volume Pricing	8 In Stock
5.00	-	1.00	NIR I (600-1050nm)	#36-989	₹6,455 Volume Pricing	20+ In Stock
5.00	-	1.00	NIR II (750-1550nm)	#39-293	₹6,455 Volume Pricing	1 In Stock
10.00	-	1.00	Uncoated	#45-308	₹4,731 Volume Pricing	20+ In Stock
10.00	-	1.00	UV-AR (250-425nm)	#45-808	₹6,638 Volume Pricing	14 In Stock
10.00	-	1.00	UV-VIS (250-700nm)	#84-470	₹6,638 Volume Pricing	Contact Us

10.00	-	1.00	VIS-EXT (350-700nm)	#25-185	₹6,858 Volume Pricing	3 In Stock
10.00	-	1.00	MgF ₂ (400-700nm)	#11-918	₹5,685 Volume Pricing	8 In Stock
10.00	-	1.00	VIS 0° (425-675nm)	#36-968	₹6,455 Volume Pricing	20+ In Stock
10.00	-	1.00	VIS-NIR (400-1000nm)	#49-638	₹6,858 Volume Pricing	20+ In Stock
10.00	-	1.00	YAG-BBAR (500-1100nm)	#25-214	₹6,858 Volume Pricing	11 In Stock
10.00	-	1.00	NIR I (600-1050nm)	#36-967	₹6,455 Volume Pricing	Contact Us
10.00	-	1.00	NIR II (750-1550nm)	#39-294	₹6,455 Volume Pricing	20+ In Stock
12.50	-	1.00	Uncoated	#22-692	₹4,731 Volume Pricing	20+ In Stock
12.50	-	1.00	UV-AR (250-425nm)	#23-302	₹6,638 Volume Pricing	Contact Us
12.50	-	1.00	UV-VIS (250-700nm)	#23-303	₹6,638 Volume Pricing	2 In Stock
12.50	-	1.00	VIS-EXT (350-700nm)	#25-186	₹6,858 Volume Pricing	3 In Stock
12.50	-	1.00	MgF ₂ (400-700nm)	#23-301	₹5,685 Volume Pricing	4 In Stock
12.50	-	1.00	VIS 0° (425-675nm)	#23-304	₹6,455 Volume Pricing	9 In Stock
12.50	-	1.00	VIS-NIR (400-1000nm)	#23-305	₹6,858 Volume Pricing	6 In Stock

12.50	-	1.00	YAG-BBAR (500-1100nm)	#25-215	₹6,858 Volume Pricing	3 In Stock
12.50	-	1.00	NIR I (600-1050nm)	#23-306	₹6,455 Volume Pricing	7 In Stock
12.50	-	1.00	NIR II (750-1550nm)	#23-307	₹6,455 Volume Pricing	5 In Stock
12.50	-	2.00	Uncoated	#45-309	₹4,731 Volume Pricing	20+ In Stock
12.50	-	2.00	UV-AR (250-425nm)	#45-809	₹6,638 Volume Pricing	20+ In Stock
12.50	-	2.00	UV-VIS (250-700nm)	#84-471	₹6,638 Volume Pricing	2 In Stock
12.50	-	2.00	VIS-EXT (350-700nm)	#25-187	₹6,858 Volume Pricing	5 In Stock
12.50	-	2.00	MgF ₂ (400-700nm)	#11-919	₹5,685 Volume Pricing	5 In Stock
12.50	-	2.00	VIS 0° (425-675nm)	#36-970	₹6,455 Volume Pricing	5 In Stock
12.50	-	2.00	VIS-NIR (400-1000nm)	#49-639	₹6,858 Volume Pricing	11 In Stock
12.50	-	2.00	YAG-BBAR (500-1100nm)	#25-216	₹6,858 Volume Pricing	4 In Stock
12.50	-	2.00	NIR I (600-1050nm)	#36-969	₹6,455 Volume Pricing	9 In Stock
12.50	-	2.00	NIR II (750-1550nm)	#39-295	₹6,455 Volume Pricing	20+ In Stock
-	12.50 x 12.50	2.00	Uncoated	#48-200	₹4,914 Volume Pricing	20+ In Stock

-	12.50 x 12.50	2.00	UV-AR (250-425nm)	#48-202	₹6,858 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	UV-VIS (250-700nm)	#84-472	₹6,858 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	VIS-EXT (350-700nm)	#25-188	₹7,042 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	MgF ₂ (400-700nm)	#11-920	₹5,868 Volume Pricing	6 In Stock
-	12.50 x 12.50	2.00	VIS 0° (425-675nm)	#36-972	₹6,638 Volume Pricing	Contact Us
-	12.50 x 12.50	2.00	VIS-NIR (400-1000nm)	#49-640	₹7,042 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	YAG-BBAR (500-1100nm)	#25-217	₹7,042 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	NIR I (600-1050nm)	#36-971	₹6,638 Volume Pricing	9 In Stock
-	12.50 x 12.50	2.00	NIR II (750-1550nm)	#39-296	₹6,455 Volume Pricing	1 In Stock
-	12.50 x 17.50	2.00	Uncoated	#71-192	₹4,988 Volume Pricing	8 In Stock
12.70	-	2.00	Uncoated	#15-307	₹4,731 Volume Pricing	1 In Stock
12.70	-	2.00	UV-AR (250-425nm)	#25-252	₹6,638 Volume Pricing	3 In Stock
12.70	-	2.00	UV-VIS (250-700nm)	#25-263	₹6,638 Volume Pricing	2 In Stock
12.70	-	2.00	VIS-EXT (350-700nm)	#25-189	₹6,858 Volume Pricing	3 In Stock

12.70	-	2.00	MgF ₂ (400-700nm)	#25-318	₹5,685 Volume Pricing	5 In Stock
12.70	-	2.00	VIS 0° (425-675nm)	#25-274	₹6,455 Volume Pricing	3 In Stock
12.70	-	2.00	VIS-NIR (400-1000nm)	#25-307	₹6,858 Volume Pricing	2 In Stock
12.70	-	2.00	YAG-BBAR (500-1100nm)	#25-218	₹6,858 Volume Pricing	5 In Stock
12.70	-	2.00	NIR I (600-1050nm)	#25-285	₹6,455 Volume Pricing	3 In Stock
12.70	-	2.00	NIR II (750-1550nm)	#25-296	₹6,455 Volume Pricing	4 In Stock
15.00	-	1.00	Uncoated	#22-693	₹4,914 Volume Pricing	20+ In Stock
15.00	-	1.00	UV-AR (250-425nm)	#23-309	₹6,858 Volume Pricing	1 In Stock
15.00	-	1.00	UV-VIS (250-700nm)	#23-310	₹6,858 Volume Pricing	5 In Stock
15.00	-	1.00	VIS-EXT (350-700nm)	#25-190	₹7,042 Volume Pricing	5 In Stock
15.00	-	1.00	MgF ₂ (400-700nm)	#23-308	₹5,868 Volume Pricing	3 In Stock
15.00	-	1.00	VIS 0° (425-675nm)	#23-311	₹6,638 Volume Pricing	4 In Stock
15.00	-	1.00	VIS-NIR (400-1000nm)	#23-312	₹7,042 Volume Pricing	2 In Stock
15.00	-	1.00	YAG-BBAR (500-1100nm)	#25-219	₹7,042 Volume Pricing	5 In Stock

15.00	-	1.00	NIR I (600-1050nm)	#23-313	₹6,638 Volume Pricing	1 In Stock
15.00	-	1.00	NIR II (750-1550nm)	#23-314	₹6,638 Volume Pricing	2 In Stock
15.00	-	2.00	Uncoated	#45-310	₹4,914 Volume Pricing	20+ In Stock
15.00	-	2.00	UV-AR (250-425nm)	#45-810	₹6,858 Volume Pricing	20+ In Stock
15.00	-	2.00	UV-VIS (250-700nm)	#84-473	₹6,858 Volume Pricing	5 In Stock
15.00	-	2.00	VIS-EXT (350-700nm)	#25-191	₹7,042 Volume Pricing	6 In Stock
15.00	-	2.00	MgF ₂ (400-700nm)	#11-921	₹5,868 Volume Pricing	2 In Stock
15.00	-	2.00	VIS 0° (425-675nm)	#36-974	₹6,638 Volume Pricing	17 In Stock
15.00	-	2.00	VIS-NIR (400-1000nm)	#49-641	₹7,042 Volume Pricing	Contact Us
15.00	-	2.00	YAG-BBAR (500-1100nm)	#25-220	₹7,042 Volume Pricing	2 In Stock
15.00	-	2.00	NIR I (600-1050nm)	#36-973	₹6,638 Volume Pricing	5 In Stock
15.00	-	2.00	NIR II (750-1550nm)	#39-297	₹6,638 Volume Pricing	3 In Stock
20.00	-	1.00	Uncoated	#22-694	₹5,098 Volume Pricing	20+ In Stock
20.00	-	1.00	UV-AR (250-425nm)	#23-316	₹7,042 Volume Pricing	5 In Stock
20.00	-	1.00	UV-VIS (250-700nm)	#23-317	₹7,042 Volume Pricing	3 In Stock

20.00	-	1.00	VIS-EXT (350-700nm)	#25-192	₹7,225 Volume Pricing	5 In Stock
20.00	-	1.00	MgF ₂ (400-700nm)	#23-315	₹6,088 Volume Pricing	Contact Us
20.00	-	1.00	VIS 0° (425-675nm)	#23-318	₹6,858 Volume Pricing	Contact Us
20.00	-	1.00	VIS-NIR (400-1000nm)	#23-319	₹7,225 Volume Pricing	Contact Us
20.00	-	1.00	YAG-BBAR (500-1100nm)	#25-221	₹7,225 Volume Pricing	4 In Stock
20.00	-	1.00	NIR I (600-1050nm)	#23-320	₹6,858 Volume Pricing	4 In Stock
20.00	-	1.00	NIR II (750-1550nm)	#23-321	₹6,858 Volume Pricing	4 In Stock
20.00	-	2.00	Uncoated	#45-464	₹5,098 Volume Pricing	20+ In Stock
20.00	-	2.00	UV-AR (250-425nm)	#45-811	₹7,042 Volume Pricing	5 In Stock
20.00	-	2.00	UV-VIS (250-700nm)	#84-474	₹7,042 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS-EXT (350-700nm)	#25-193	₹7,225 Volume Pricing	5 In Stock
20.00	-	2.00	MgF ₂ (400-700nm)	#11-922	₹6,088 Volume Pricing	4 In Stock
20.00	-	2.00	VIS 0° (425-675nm)	#36-976	₹6,858 Volume Pricing	20+ In Stock

20.00	-	2.00	VIS-NIR (400-1000nm)	#49-642	₹7,225 Volume Pricing	20+ In Stock
20.00	-	2.00	YAG-BBAR (500-1100nm)	#25-222	₹7,225 Volume Pricing	8 In Stock
20.00	-	2.00	NIR I (600-1050nm)	#36-975	₹6,858 Volume Pricing	12 In Stock
20.00	-	2.00	NIR II (750-1550nm)	#39-298	₹6,858 Volume Pricing	5 In Stock
25.00	-	1.00	Uncoated	#19-837	₹5,428 Volume Pricing	20+ In Stock
25.00	-	1.00	UV-AR (250-425nm)	#19-846	₹7,335 Volume Pricing	7 In Stock
25.00	-	1.00	UV-VIS (250-700nm)	#19-847	₹7,335 Volume Pricing	1 In Stock
25.00	-	2.00	VIS-EXT (350-700nm)	#25-195	₹7,555 Volume Pricing	9 In Stock
25.00	-	1.00	MgF ₂ (400-700nm)	#19-845	₹6,381 Volume Pricing	1 In Stock
25.00	-	1.00	VIS 0° (425-675nm)	#19-848	₹7,152 Volume Pricing	5 In Stock
25.00	-	1.00	VIS-NIR (400-1000nm)	#19-849	₹7,555 Volume Pricing	15 In Stock
25.00	-	2.00	YAG-BBAR (500-1100nm)	#25-224	₹7,555 Volume Pricing	Contact Us
25.00	-	1.00	NIR I (600-1050nm)	#19-850	₹7,152 Volume Pricing	4 In Stock
25.00	-	1.00	NIR II (750-1550nm)	#19-851	₹7,152 Volume Pricing	6 In Stock

25.00	-	2.00	Uncoated	#45-311	₹5,428 Volume Pricing	20+ In Stock
25.00	-	2.00	UV-AR (250-425nm)	#45-812	₹7,335 Volume Pricing	20+ In Stock
25.00	-	2.00	UV-VIS (250-700nm)	#84-475	₹7,335 Volume Pricing	20+ In Stock
25.00	-	1.00	VIS-EXT (350-700nm)	#25-194	₹7,555 Volume Pricing	8 In Stock
25.00	-	2.00	MgF ₂ (400-700nm)	#11-923	₹6,381 Volume Pricing	10 In Stock
25.00	-	2.00	VIS 0° (425-675nm)	#36-978	₹7,152 Volume Pricing	8 In Stock
25.00	-	2.00	VIS-NIR (400-1000nm)	#49-643	₹7,555 Volume Pricing	20+ In Stock
25.00	-	1.00	YAG-BBAR (500-1100nm)	#25-223	₹7,555 Volume Pricing	2 In Stock
25.00	-	2.00	NIR I (600-1050nm)	#36-977	₹7,152 Volume Pricing	5 In Stock
25.00	-	2.00	NIR II (750-1550nm)	#39-299	₹7,152 Volume Pricing	9 In Stock
25.00	-	3.00	Uncoated	#19-838	₹5,428 Volume Pricing	14 In Stock
25.00	-	3.00	UV-AR (250-425nm)	#19-853	₹7,335 Volume Pricing	5 In Stock
25.00	-	3.00	UV-VIS (250-700nm)	#19-854	₹7,335 Volume Pricing	9 In Stock
25.00	-	3.00	VIS-EXT (350-700nm)	#25-196	₹7,555 Volume Pricing	9 In Stock

25.00	-	3.00	MgF ₂ (400-700nm)	#19-852	₹6,381 Volume Pricing	5 In Stock
25.00	-	3.00	VIS 0° (425-675nm)	#19-855	₹7,152 Volume Pricing	1 In Stock
25.00	-	3.00	VIS-NIR (400-1000nm)	#19-856	₹7,555 Volume Pricing	8 In Stock
25.00	-	3.00	YAG-BBAR (500-1100nm)	#25-225	₹7,555 Volume Pricing	4 In Stock
25.00	-	3.00	NIR I (600-1050nm)	#19-857	₹7,152 Volume Pricing	3 In Stock
25.00	-	3.00	NIR II (750-1550nm)	#19-858	₹7,152 Volume Pricing	14 In Stock
25.00	-	4.00	Uncoated	#19-839	₹5,428 Volume Pricing	16 In Stock
25.00	-	4.00	UV-AR (250-425nm)	#19-860	₹7,335 Volume Pricing	3 In Stock
25.00	-	4.00	UV-VIS (250-700nm)	#19-861	₹7,335 Volume Pricing	3 In Stock
25.00	-	4.00	VIS-EXT (350-700nm)	#25-197	₹7,555 Volume Pricing	2 In Stock
25.00	-	4.00	MgF ₂ (400-700nm)	#19-859	₹6,381 Volume Pricing	4 In Stock
25.00	-	4.00	VIS 0° (425-675nm)	#19-862	₹7,152 Volume Pricing	1 In Stock
25.00	-	4.00	VIS-NIR (400-1000nm)	#19-863	₹7,555 Volume Pricing	8 In Stock
25.00	-	4.00	YAG-BBAR (500-1100nm)	#25-226	₹7,555 Volume Pricing	7 In Stock

25.00	-	4.00	NIR I (600-1050nm)	#19-864	₹7,152 Volume Pricing	5 In Stock
25.00	-	4.00	NIR II (750-1550nm)	#19-865	₹7,152 Volume Pricing	10 In Stock
25.00	-	5.00	Uncoated	#19-840	₹5,428 Volume Pricing	1 In Stock
25.00	-	5.00	UV-AR (250-425nm)	#19-867	₹7,335 Volume Pricing	4 In Stock
25.00	-	5.00	UV-VIS (250-700nm)	#19-868	₹7,335 Volume Pricing	4 In Stock
25.00	-	5.00	VIS-EXT (350-700nm)	#25-198	₹7,555 Volume Pricing	5 In Stock
25.00	-	5.00	MgF ₂ (400-700nm)	#19-866	₹6,381 Volume Pricing	5 In Stock
25.00	-	5.00	VIS 0° (425-675nm)	#19-869	₹7,152 Volume Pricing	4 In Stock
25.00	-	5.00	VIS-NIR (400-1000nm)	#19-870	₹7,555 Volume Pricing	5 In Stock
25.00	-	5.00	YAG-BBAR (500-1100nm)	#25-227	₹7,555 Volume Pricing	5 In Stock
25.00	-	5.00	NIR I (600-1050nm)	#19-871	₹7,152 Volume Pricing	3 In Stock
25.00	-	5.00	NIR II (750-1550nm)	#19-872	₹7,152 Volume Pricing	6 In Stock
-	25.00 x 25.00	2.00	Uncoated	#48-201	₹5,611 Volume Pricing	20+ In Stock
-	25.00 x 25.00	2.00	UV-AR (250-425nm)	#48-203	₹7,555 Volume Pricing	Contact Us
-	25.00 x 25.00	2.00	UV-VIS (250-700nm)	#84-476	₹7,555 Volume Pricing	6 In Stock

-	25.00 x 25.00	2.00	VIS-EXT (350-700nm)	#25-199	₹7,775 Volume Pricing	9 In Stock
-	25.00 x 25.00	2.00	MgF ₂ (400-700nm)	#11-924	₹6,565 Volume Pricing	15 In Stock
-	25.00 x 25.00	2.00	VIS 0° (425-675nm)	#36-980	₹7,335 Volume Pricing	20+ In Stock
-	25.00 x 25.00	2.00	VIS-NIR (400-1000nm)	#49-644	₹7,775 Volume Pricing	15 In Stock
-	25.00 x 25.00	2.00	YAG-BBAR (500-1100nm)	#25-228	₹7,775 Volume Pricing	6 In Stock
-	25.00 x 25.00	2.00	NIR I (600-1050nm)	#36-979	₹7,335 Volume Pricing	5 In Stock
-	25.00 x 25.00	2.00	NIR II (750-1550nm)	#39-300	₹7,335 Volume Pricing	10 In Stock
-	25.00 x 35.00	3.00	Uncoated	#71-193	₹5,941 Volume Pricing	6 In Stock
25.40	-	1.00	Uncoated	#25-244	₹5,428 Volume Pricing	20+ In Stock
25.40	-	1.00	UV-AR (250-425nm)	#25-253	₹7,335 Volume Pricing	9 In Stock
25.40	-	1.00	UV-VIS (250-700nm)	#25-264	₹7,335 Volume Pricing	4 In Stock
25.40	-	1.00	VIS-EXT (350-700nm)	#25-329	₹7,555 Volume Pricing	3 In Stock
25.40	-	1.00	MgF ₂ (400-700nm)	#25-319	₹6,381 Volume Pricing	5 In Stock

25.40	-	1.00	VIS 0° (425-675nm)	#25-275	₹7,152 Volume Pricing	6 In Stock
25.40	-	1.00	VIS-NIR (400-1000nm)	#25-308	₹7,555 Volume Pricing	5 In Stock
25.40	-	1.00	YAG-BBAR (500-1100nm)	#25-337	₹7,555 Volume Pricing	2 In Stock
25.40	-	1.00	NIR I (600-1050nm)	#25-286	₹7,152 Volume Pricing	1 In Stock
25.40	-	1.00	NIR II (750-1550nm)	#25-297	₹7,152 Volume Pricing	Contact Us
25.40	-	2.00	Uncoated	#15-308	₹5,428 Volume Pricing	5 In Stock
25.40	-	2.00	UV-AR (250-425nm)	#25-254	₹7,335 Volume Pricing	1 In Stock
25.40	-	2.00	UV-VIS (250-700nm)	#25-265	₹7,335 Volume Pricing	3 In Stock
25.40	-	2.00	VIS-EXT (350-700nm)	#25-200	₹7,555 Volume Pricing	5 In Stock
25.40	-	2.00	MgF ₂ (400-700nm)	#25-320	₹6,381 Volume Pricing	1 In Stock
25.40	-	2.00	VIS 0° (425-675nm)	#25-276	₹7,152 Volume Pricing	4 In Stock
25.40	-	2.00	VIS-NIR (400-1000nm)	#25-309	₹7,555 Volume Pricing	1 In Stock
25.40	-	2.00	YAG-BBAR (500-1100nm)	#25-229	₹7,555 Volume Pricing	4 In Stock
25.40	-	2.00	NIR I (600-1050nm)	#25-287	₹7,152 Volume Pricing	4 In Stock

25.40	-	2.00	NIR II (750- 1550nm)	#25-298	₹7,152 Volume Pricing	2 In Stock
25.40	-	3.00	Uncoated	#25-245	₹5,428 Volume Pricing	20+ In Stock
25.40	-	3.00	UV-AR (250- 425nm)	#25-255	₹7,335 Volume Pricing	5 In Stock
25.40	-	3.00	UV-VIS (250- 700nm)	#25-266	₹7,335 Volume Pricing	2 In Stock
25.40	-	3.00	VIS-EXT (350- 700nm)	#25-330	₹7,555 Volume Pricing	1 In Stock
25.40	-	3.00	MgF ₂ (400- 700nm)	#25-321	₹6,381 Volume Pricing	3 In Stock
25.40	-	3.00	VIS 0° (425- 675nm)	#25-277	₹7,152 Volume Pricing	5 In Stock
25.40	-	3.00	VIS-NIR (400- 1000nm)	#25-310	₹7,555 Volume Pricing	2 In Stock
25.40	-	3.00	YAG- BBAR (500- 1100nm)	#25-338	₹7,555 Volume Pricing	5 In Stock
25.40	-	3.00	NIR I (600- 1050nm)	#25-288	₹7,152 Volume Pricing	3 In Stock
25.40	-	3.00	NIR II (750- 1550nm)	#25-299	₹7,152 Volume Pricing	1 In Stock
25.40	-	4.00	Uncoated	#25-246	₹5,428 Volume Pricing	20+ In Stock
25.40	-	4.00	UV-AR (250- 425nm)	#25-256	₹7,335 Volume Pricing	4 In Stock
25.40	-	4.00	UV-VIS (250- 700nm)	#25-267	₹7,335 Volume Pricing	5 In Stock
25.40	-	4.00	VIS-EXT (350- 700nm)	#25-331	₹7,555 Volume Pricing	5 In Stock

25.40	-	4.00	MgF ₂ (400-700nm)	#25-322	₹6,381 Volume Pricing	5 In Stock
25.40	-	4.00	VIS 0° (425-675nm)	#25-278	₹7,152 Volume Pricing	5 In Stock
25.40	-	4.00	VIS-NIR (400-1000nm)	#25-311	₹7,555 Volume Pricing	14 In Stock
25.40	-	4.00	YAG-BBAR (500-1100nm)	#25-339	₹7,555 Volume Pricing	5 In Stock
25.40	-	4.00	NIR I (600-1050nm)	#25-289	₹7,152 Volume Pricing	4 In Stock
25.40	-	4.00	NIR II (750-1550nm)	#25-300	₹7,152 Volume Pricing	Contact Us
25.40	-	5.00	Uncoated	#25-247	₹5,428 Volume Pricing	20+ In Stock
25.40	-	5.00	UV-AR (250-425nm)	#25-257	₹7,335 Volume Pricing	5 In Stock
25.40	-	5.00	UV-VIS (250-700nm)	#25-268	₹7,335 Volume Pricing	5 In Stock
25.40	-	5.00	VIS-EXT (350-700nm)	#25-332	₹7,555 Volume Pricing	3 In Stock
25.40	-	5.00	MgF ₂ (400-700nm)	#25-323	₹6,381 Volume Pricing	5 In Stock
25.40	-	5.00	VIS 0° (425-675nm)	#25-279	₹7,152 Volume Pricing	2 In Stock
25.40	-	5.00	VIS-NIR (400-1000nm)	#25-312	₹7,555 Volume Pricing	3 In Stock

25.40	-	5.00	YAG-BBAR (500-1100nm)	#25-340	₹7,555 Volume Pricing	4 In Stock
25.40	-	5.00	NIR I (600-1050nm)	#25-290	₹7,152 Volume Pricing	4 In Stock
25.40	-	5.00	NIR II (750-1550nm)	#25-301	₹7,152 Volume Pricing	3 In Stock
30.00	-	1.00	Uncoated	#22-695	₹6,381 Volume Pricing	5 In Stock
30.00	-	1.00	UV-AR (250-425nm)	#23-323	₹8,729 Volume Pricing	3 In Stock
30.00	-	1.00	UV-VIS (250-700nm)	#23-324	₹8,729 Volume Pricing	3 In Stock
30.00	-	1.00	VIS-EXT (350-700nm)	#25-201	₹8,875 Volume Pricing	2 In Stock
30.00	-	1.00	MgF ₂ (400-700nm)	#23-322	₹7,775 Volume Pricing	4 In Stock
30.00	-	1.00	VIS 0° (425-675nm)	#23-325	₹8,509 Volume Pricing	2 In Stock
30.00	-	1.00	VIS-NIR (400-1000nm)	#23-326	₹8,875 Volume Pricing	Contact Us
30.00	-	1.00	YAG-BBAR (500-1100nm)	#25-230	₹8,875 Volume Pricing	2 In Stock
30.00	-	1.00	NIR I (600-1050nm)	#23-327	₹8,509 Volume Pricing	1 In Stock
30.00	-	1.00	NIR II (750-1550nm)	#23-328	₹8,509 Volume Pricing	5 In Stock
30.00	-	3.00	Uncoated	#45-569	₹6,381 Volume Pricing	7 In Stock

30.00	-	3.00	UV-AR (250-425nm)	#45-813	₹8,729 Volume Pricing	5 In Stock
30.00	-	3.00	UV-VIS (250-700nm)	#84-477	₹8,729 Volume Pricing	17 In Stock
30.00	-	3.00	VIS-EXT (350-700nm)	#25-202	₹8,875 Volume Pricing	1 In Stock
30.00	-	3.00	MgF ₂ (400-700nm)	#11-925	₹7,775 Volume Pricing	9 In Stock
30.00	-	3.00	VIS 0° (425-675nm)	#36-982	₹8,509 Volume Pricing	7 In Stock
30.00	-	3.00	VIS-NIR (400-1000nm)	#49-645	₹8,875 Volume Pricing	7 In Stock
30.00	-	3.00	YAG-BBAR (500-1100nm)	#25-231	₹8,875 Volume Pricing	3 In Stock
30.00	-	3.00	NIR I (600-1050nm)	#36-981	₹8,509 Volume Pricing	8 In Stock
30.00	-	3.00	NIR II (750-1550nm)	#39-301	₹8,509 Volume Pricing	4 In Stock
-	35.00 x 50.00	4.00	Uncoated	#71-194	₹7,262 Volume Pricing	20+ In Stock
40.00	-	1.00	Uncoated	#22-696	₹6,785 Volume Pricing	20+ In Stock
40.00	-	1.00	UV-AR (250-425nm)	#23-330	₹9,095 Volume Pricing	2 In Stock
40.00	-	1.00	UV-VIS (250-700nm)	#23-331	₹9,095 Volume Pricing	2 In Stock
40.00	-	1.00	VIS-EXT (350-700nm)	#25-203	₹9,315 Volume Pricing	2 In Stock

40.00	-	1.00	MgF ₂ (400-700nm)	#23-329	₹8,142 Volume Pricing	4 In Stock
40.00	-	1.00	VIS 0° (425-675nm)	#23-332	₹8,875 Volume Pricing	2 In Stock
40.00	-	1.00	VIS-NIR (400-1000nm)	#23-333	₹9,315 Volume Pricing	3 In Stock
40.00	-	1.00	YAG-BBAR (500-1100nm)	#25-232	₹9,315 Volume Pricing	Contact Us
40.00	-	1.00	NIR I (600-1050nm)	#23-334	₹8,875 Volume Pricing	7 In Stock
40.00	-	1.00	NIR II (750-1550nm)	#23-335	₹8,875 Volume Pricing	2 In Stock
40.00	-	4.00	Uncoated	#45-570	₹6,785 Volume Pricing	20+ In Stock
40.00	-	4.00	UV-AR (250-425nm)	#45-814	₹9,095 Volume Pricing	20+ In Stock
40.00	-	4.00	UV-VIS (250-700nm)	#84-478	₹9,095 Volume Pricing	3 In Stock
40.00	-	4.00	VIS-EXT (350-700nm)	#25-204	₹9,315 Volume Pricing	2 In Stock
40.00	-	4.00	MgF ₂ (400-700nm)	#11-926	₹8,142 Volume Pricing	1 In Stock
40.00	-	4.00	VIS 0° (425-675nm)	#36-984	₹8,875 Volume Pricing	12 In Stock
40.00	-	4.00	VIS-NIR (400-1000nm)	#49-646	₹9,315 Volume Pricing	7 In Stock
40.00	-	4.00	YAG-BBAR (500-1100nm)	#25-233	₹9,315 Volume Pricing	4 In Stock

40.00	-	4.00	NIR I (600-1050nm)	#36-983	₹8,875 Volume Pricing	3 In Stock
40.00	-	4.00	NIR II (750-1550nm)	#39-302	₹8,875 Volume Pricing	5 In Stock
50.00	-	1.00	Uncoated	#19-841	₹8,289 Volume Pricing	20+ In Stock
50.00	-	1.00	UV-AR (250-425nm)	#19-874	₹11,003 Volume Pricing	4 In Stock
50.00	-	1.00	UV-VIS (250-700nm)	#19-875	₹11,003 Volume Pricing	2 In Stock
50.00	-	1.00	VIS-EXT (350-700nm)	#25-205	₹11,223 Volume Pricing	5 In Stock
50.00	-	1.00	MgF ₂ (400-700nm)	#19-873	₹9,682 Volume Pricing	1 In Stock
50.00	-	1.00	VIS 0° (425-675nm)	#19-876	₹10,856 Volume Pricing	2 In Stock
50.00	-	5.00	NIR II (750-1550nm)	#19-900	₹10,856 Volume Pricing	1 In Stock
50.00	-	1.00	VIS-NIR (400-1000nm)	#19-877	₹11,223 Volume Pricing	1 In Stock
50.00	-	1.00	YAG-BBAR (500-1100nm)	#25-234	₹11,223 Volume Pricing	3 In Stock
50.00	-	5.00	NIR I (600-1050nm)	#19-899	₹10,856 Volume Pricing	1 In Stock
50.00	-	2.00	Uncoated	#19-842	₹8,289 Volume Pricing	14 In Stock
50.00	-	2.00	UV-AR (250-425nm)	#19-881	₹11,003 Volume Pricing	3 In Stock
50.00	-	2.00	UV-VIS (250-700nm)	#19-882	₹11,003 Volume Pricing	13 In Stock

50.00	-	2.00	VIS-EXT (350-700nm)	#25-206	₹11,223 Volume Pricing	6 In Stock
50.00	-	2.00	MgF ₂ (400-700nm)	#19-880	₹9,682 Volume Pricing	5 In Stock
50.00	-	2.00	VIS 0° (425-675nm)	#19-883	₹10,856 Volume Pricing	3 In Stock
50.00	-	2.00	VIS-NIR (400-1000nm)	#19-884	₹11,223 Volume Pricing	5 In Stock
50.00	-	2.00	YAG-BBAR (500-1100nm)	#25-235	₹11,223 Volume Pricing	1 In Stock
50.00	-	1.00	NIR I (600-1050nm)	#19-878	₹10,856 Volume Pricing	5 In Stock
50.00	-	1.00	NIR II (750-1550nm)	#19-879	₹10,856 Volume Pricing	5 In Stock
50.00	-	3.00	Uncoated	#19-843	₹8,289 Volume Pricing	20+ In Stock
50.00	-	3.00	UV-AR (250-425nm)	#19-888	₹11,003 Volume Pricing	2 In Stock
50.00	-	3.00	UV-VIS (250-700nm)	#19-889	₹11,003 Volume Pricing	4 In Stock
50.00	-	3.00	VIS-EXT (350-700nm)	#25-207	₹11,223 Volume Pricing	8 In Stock
50.00	-	3.00	MgF ₂ (400-700nm)	#19-887	₹9,682 Volume Pricing	1 In Stock
50.00	-	3.00	VIS 0° (425-675nm)	#19-890	₹10,856 Volume Pricing	1 In Stock

50.00	-	3.00	VIS-NIR (400-1000nm)	#19-891	₹11,223 Volume Pricing	4 In Stock
50.00	-	3.00	YAG-BBAR (500-1100nm)	#25-236	₹11,223 Volume Pricing	Contact Us
50.00	-	2.00	NIR I (600-1050nm)	#19-885	₹10,856 Volume Pricing	2 In Stock
50.00	-	2.00	NIR II (750-1550nm)	#19-886	₹10,856 Volume Pricing	1 In Stock
50.00	-	4.00	Uncoated	#47-230	₹8,289 Volume Pricing	20+ In Stock
50.00	-	4.00	UV-AR (250-425nm)	#49-635	₹11,003 Volume Pricing	Contact Us
50.00	-	4.00	UV-VIS (250-700nm)	#84-479	₹11,003 Volume Pricing	8 In Stock
50.00	-	4.00	VIS-EXT (350-700nm)	#25-208	₹11,223 Volume Pricing	3 In Stock
50.00	-	4.00	MgF ₂ (400-700nm)	#11-927	₹9,682 Volume Pricing	7 In Stock
50.00	-	4.00	VIS 0° (425-675nm)	#36-986	₹10,856 Volume Pricing	4 In Stock
50.00	-	4.00	VIS-NIR (400-1000nm)	#49-647	₹11,223 Volume Pricing	10 In Stock
50.00	-	4.00	YAG-BBAR (500-1100nm)	#25-237	₹11,223 Volume Pricing	4 In Stock
50.00	-	3.00	NIR I (600-1050nm)	#19-892	₹10,856 Volume Pricing	3 In Stock
50.00	-	3.00	NIR II (750-1550nm)	#19-893	₹10,856 Volume Pricing	4 In Stock

50.00	-	5.00	Uncoated	#19-844	₹8,289 Volume Pricing	20+ In Stock
50.00	-	5.00	UV-AR (250-425nm)	#19-895	₹11,003 Volume Pricing	3 In Stock
50.00	-	5.00	UV-VIS (250-700nm)	#19-896	₹11,003 Volume Pricing	3 In Stock
50.00	-	5.00	VIS-EXT (350-700nm)	#25-209	₹11,223 Volume Pricing	4 In Stock
50.00	-	5.00	MgF ₂ (400-700nm)	#19-894	₹9,682 Volume Pricing	5 In Stock
50.00	-	5.00	VIS 0° (425-675nm)	#19-897	₹10,856 Volume Pricing	1 In Stock
50.00	-	5.00	VIS-NIR (400-1000nm)	#19-898	₹11,223 Volume Pricing	5 In Stock
50.00	-	5.00	YAG-BBAR (500-1100nm)	#25-238	₹11,223 Volume Pricing	3 In Stock
50.00	-	4.00	NIR I (600-1050nm)	#36-985	₹10,856 Volume Pricing	5 In Stock
50.00	-	4.00	NIR II (750-1550nm)	#39-303	₹10,856 Volume Pricing	4 In Stock
-	50.00 x 50.00	4.00	Uncoated	#47-231	₹8,509 Volume Pricing	20+ In Stock
-	50.00 x 50.00	4.00	UV-AR (250-425nm)	#49-636	₹11,223 Volume Pricing	3 In Stock
-	50.00 x 50.00	4.00	UV-VIS (250-700nm)	#84-480	₹11,223 Volume Pricing	1 In Stock
-	50.00 x 50.00	4.00	VIS-EXT (350-700nm)	#25-210	₹11,443 Volume Pricing	Contact Us

-	50.00 x 50.00	4.00	MgF ₂ (400-700nm)	#11-928	₹9,902 Volume Pricing	5 In Stock
-	50.00 x 50.00	4.00	VIS 0° (425-675nm)	#36-988	₹11,003 Volume Pricing	5 In Stock
-	50.00 x 50.00	4.00	VIS-NIR (400-1000nm)	#49-648	₹11,443 Volume Pricing	5 In Stock
-	50.00 x 50.00	4.00	YAG-BBAR (500-1100nm)	#25-239	₹11,443 Volume Pricing	2 In Stock
-	50.00 x 50.00	4.00	NIR I (600-1050nm)	#36-987	₹11,003 Volume Pricing	1 In Stock
-	50.00 x 50.00	4.00	NIR II (750-1550nm)	#39-304	₹11,003 Volume Pricing	2 In Stock
50.80	-	1.00	Uncoated	#25-248	₹8,289 Volume Pricing	20+ In Stock
50.80	-	1.00	UV-AR (250-425nm)	#25-258	₹11,003 Volume Pricing	4 In Stock
50.80	-	1.00	UV-VIS (250-700nm)	#25-269	₹11,003 Volume Pricing	Contact Us
50.80	-	1.00	VIS-EXT (350-700nm)	#25-333	₹11,223 Volume Pricing	4 In Stock
50.80	-	1.00	MgF ₂ (400-700nm)	#25-324	₹9,682 Volume Pricing	Contact Us
50.80	-	1.00	VIS 0° (425-675nm)	#25-280	₹10,856 Volume Pricing	5 In Stock
50.80	-	1.00	VIS-NIR (400-1000nm)	#25-313	₹11,223 Volume Pricing	3 In Stock
50.80	-	1.00	YAG-BBAR (500-1100nm)	#25-341	₹11,223 Volume Pricing	6 In Stock

50.80	-	1.00	NIR I (600-1050nm)	#25-291	₹10,856 Volume Pricing	5 In Stock
50.80	-	1.00	NIR II (750-1550nm)	#25-302	₹10,856 Volume Pricing	2 In Stock
50.80	-	2.00	Uncoated	#25-249	₹8,289 Volume Pricing	20+ In Stock
50.80	-	2.00	UV-AR (250-425nm)	#25-259	₹11,003 Volume Pricing	Contact Us
50.80	-	2.00	UV-VIS (250-700nm)	#25-270	₹11,003 Volume Pricing	4 In Stock
50.80	-	2.00	VIS-EXT (350-700nm)	#25-334	₹11,223 Volume Pricing	Contact Us
50.80	-	2.00	MgF ₂ (400-700nm)	#25-325	₹9,682 Volume Pricing	5 In Stock
50.80	-	2.00	VIS 0° (425-675nm)	#25-281	₹10,856 Volume Pricing	5 In Stock
50.80	-	2.00	VIS-NIR (400-1000nm)	#25-314	₹11,223 Volume Pricing	1 In Stock
50.80	-	2.00	YAG-BBAR (500-1100nm)	#25-342	₹11,223 Volume Pricing	2 In Stock
50.80	-	2.00	NIR I (600-1050nm)	#25-292	₹10,856 Volume Pricing	1 In Stock
50.80	-	2.00	NIR II (750-1550nm)	#25-303	₹10,856 Volume Pricing	3 In Stock
50.80	-	3.00	Uncoated	#25-250	₹8,289 Volume Pricing	20+ In Stock
50.80	-	3.00	UV-AR (250-425nm)	#25-260	₹11,003 Volume Pricing	2 In Stock
50.80	-	3.00	UV-VIS (250-700nm)	#25-271	₹11,003 Volume Pricing	2 In Stock

50.80	-	3.00	VIS-EXT (350-700nm)	#25-335	₹11,223 Volume Pricing	Contact Us
50.80	-	3.00	MgF ₂ (400-700nm)	#25-326	₹9,682 Volume Pricing	5 In Stock
50.80	-	3.00	VIS 0° (425-675nm)	#25-282	₹10,856 Volume Pricing	5 In Stock
50.80	-	3.00	VIS-NIR (400-1000nm)	#25-315	₹11,223 Volume Pricing	3 In Stock
50.80	-	3.00	YAG-BBAR (500-1100nm)	#25-343	₹11,223 Volume Pricing	9 In Stock
50.80	-	3.00	NIR I (600-1050nm)	#25-293	₹10,856 Volume Pricing	4 In Stock
50.80	-	3.00	NIR II (750-1550nm)	#25-304	₹10,856 Volume Pricing	1 In Stock
50.80	-	4.00	Uncoated	#15-309	₹8,289 Volume Pricing	Contact Us
50.80	-	4.00	UV-AR (250-425nm)	#25-261	₹11,003 Volume Pricing	5 In Stock
50.80	-	4.00	UV-VIS (250-700nm)	#25-272	₹11,003 Volume Pricing	6 In Stock
50.80	-	4.00	VIS-EXT (350-700nm)	#25-211	₹11,223 Volume Pricing	5 In Stock
50.80	-	4.00	MgF ₂ (400-700nm)	#25-327	₹9,682 Volume Pricing	5 In Stock
50.80	-	4.00	VIS 0° (425-675nm)	#25-283	₹10,856 Volume Pricing	5 In Stock

50.80	-	4.00	VIS-NIR (400-1000nm)	#25-316	₹11,223 Volume Pricing	3 In Stock
50.80	-	4.00	YAG-BBAR (500-1100nm)	#25-240	₹11,223 Volume Pricing	5 In Stock
50.80	-	4.00	NIR I (600-1050nm)	#25-294	₹10,856 Volume Pricing	4 In Stock
50.80	-	4.00	NIR II (750-1550nm)	#25-305	₹10,856 Volume Pricing	5 In Stock
50.80	-	5.00	Uncoated	#25-251	₹8,289 Volume Pricing	7 In Stock
50.80	-	5.00	UV-AR (250-425nm)	#25-262	₹11,003 Volume Pricing	4 In Stock
50.80	-	5.00	UV-VIS (250-700nm)	#25-273	₹11,003 Volume Pricing	3 In Stock
50.80	-	5.00	VIS-EXT (350-700nm)	#25-336	₹11,223 Volume Pricing	6 In Stock
50.80	-	5.00	MgF ₂ (400-700nm)	#25-328	₹9,682 Volume Pricing	5 In Stock
50.80	-	5.00	VIS 0° (425-675nm)	#25-284	₹10,856 Volume Pricing	5 In Stock
50.80	-	5.00	VIS-NIR (400-1000nm)	#25-317	₹11,223 Volume Pricing	5 In Stock
50.80	-	5.00	YAG-BBAR (500-1100nm)	#25-344	₹11,223 Volume Pricing	5 In Stock
50.80	-	5.00	NIR I (600-1050nm)	#25-295	₹10,856 Volume Pricing	5 In Stock
50.80	-	5.00	NIR II (750-1550nm)	#25-306	₹10,856 Volume Pricing	5 In Stock

75.00	-	5.00	Uncoated	#39-291	₹12,176 Volume Pricing	11 In Stock
-	75.00 x 75.00	5.00	Uncoated	#70-700	₹13,496 Volume Pricing	7 In Stock
75.00	-	5.00	VIS-EXT (350-700nm)	#25-212	₹17,604 Volume Pricing	2 In Stock
75.00	-	5.00	MgF ₂ (400-700nm)	#11-929	₹14,890 Volume Pricing	Contact Us
75.00	-	5.00	YAG-BBAR (500-1100nm)	#25-241	₹17,604 Volume Pricing	Contact Us
-	100.00 x 100.00	5.00	Uncoated	#70-701	₹28,900 Volume Pricing	8 In Stock
100.00	-	8.00	Uncoated	#39-292	₹29,047 Volume Pricing	14 In Stock
100.00	-	8.00	UV-AR (250-425nm)	#23-614	₹49,511 Volume Pricing	1 In Stock
100.00	-	8.00	UV-VIS (250-700nm)	#22-052	₹49,511 Volume Pricing	Contact Us
100.00	-	8.00	MgF ₂ (400-700nm)	#11-930	₹33,668 Volume Pricing	5 In Stock
100.00	-	8.00	VIS 0° (425-675nm)	#22-053	₹48,411 Volume Pricing	2 In Stock
100.00	-	8.00	VIS-NIR (400-1000nm)	#22-054	₹49,511 Volume Pricing	5 In Stock
100.00	-	8.00	VIS-EXT (350-700nm)	#29-630	₹49,511 Volume Pricing	Contact Us
100.00	-	8.00	NIR II (750-1550nm)	#29-629	₹48,411 Volume Pricing	Contact Us
100.00	-	8.00	NIR I (600-1050nm)	#29-628	₹48,411 Volume Pricing	Contact Us

[#29-631 New](#)



New

Copyright 2023, Edmund Optics India Private Limited, #29-631, 2nd Floor, Keystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 : [www.edmundoptics.com](#)
100.00 - 8.00 YAG-BBAR (500-1100nm) [Volume Pricing](#) ₹49,511 4 In Stock

on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

