

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Float Glass](#)

4-6λ First Surface Mirrors



- Wide Variety of Shapes and Sizes Available
- >85% Reflection of Visible Light
- [Contact Us](#) for Custom Sizes

Common Specifications

Physical & Mechanical Properties


Bevel: Protective as needed

Optical Properties

Surface Flatness (P-V): 4 - 6λ

Substrate:	Float Glass	Surface Quality:	80-50
Coating Specification:	R _{avg} >85% @ 400 - 700nm	Coating:	Protected Aluminum (400-700nm)
Coating Type:	Metal	Angle of Incidence (°):	45.00
Wavelength Range (nm):	400 - 700		

Technical Information

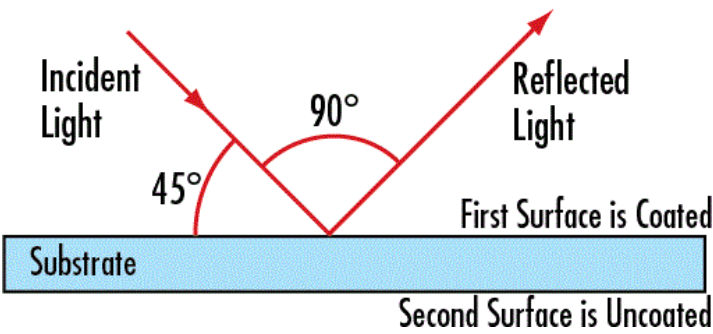

Products

Dia. (mm)	Surface Flatness (P-V)	Dimensions (mm)	Coating Specification	Coating	AOI (°)	Stock Number	Price	Buy
-	4 - 6λ	3.0 x 3.0	Ravg >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-001	₹545 Volume Pricing	20+ In Stock
5.00	4 - 6λ	-	Ravg >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#27-400	₹993 Volume Pricing	5 In Stock
6.30	4 - 6λ	-	Ravg >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-354	₹1,129 Volume Pricing	20+ In Stock
9.00	4 - 6λ	-	Ravg >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-647	₹1,246 Volume Pricing	20+ In Stock
-	4 - 6λ	9.0 x 9.0	Ravg >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-004	₹1,246 Volume Pricing	20+ In Stock
-	4 - 6λ	9.5 x 11.2	Ravg >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-418	₹1,246 Volume Pricing	20+ In Stock
12.50	4 - 6λ	-	Ravg >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#27-402	₹1,246 Volume Pricing	6 In Stock
12.70	4 - 6λ	-	Ravg >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-243	₹1,246 Volume Pricing	20+ In Stock
-	4 - 6λ	12.7 x 12.7	Ravg >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-244	₹1,246 Volume Pricing	20+ In Stock
-	4 - 6λ	12.7 x 18.0	Ravg >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#83-535	₹1,323 Volume Pricing	20+ In Stock
15.00	4 - 6λ	-	Ravg >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-006	₹1,401 Volume Pricing	20+ In Stock

16.00	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-648	₹1,401 Volume Pricing	15 In Stock
-	4 - 6λ	17.0 x 23.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-417	₹1,401 Volume Pricing	20+ In Stock
19.00	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-649	₹1,401 Volume Pricing	20+ In Stock
-	4 - 6λ	19.0 x 19.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-650	₹1,401 Volume Pricing	20+ In Stock
-	4 - 6λ	21.0 x 26.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#40-286	₹1,557 Volume Pricing	20+ In Stock
-	4 - 6λ	22.0 x 22.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-368	₹1,557 Volume Pricing	20+ In Stock
-	4 - 6λ	22.0 x 29.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-419	₹1,557 Volume Pricing	20+ In Stock
25.40	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-245	₹1,557 Volume Pricing	20+ In Stock
-	4 - 6λ	25.4 x 25.4	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-246	₹1,557 Volume Pricing	20+ In Stock
-	4 - 6λ	25.4 x 35.4	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#83-536	₹1,693 Volume Pricing	20+ In Stock
26.00	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-009	₹1,615 Volume Pricing	20+ In Stock
-	4 - 6λ	30.0 x 40.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#30-429	₹2,024 Volume Pricing	20+ In Stock
-	4 - 6λ	31.0 x 77.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-366	₹2,024 Volume Pricing	20+ In Stock

32.00	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-651	₹2,024 Volume Pricing	20+ In Stock
-	4 - 6λ	35.0 x 109.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-359	₹2,024 Volume Pricing	20+ In Stock
-	4 - 6λ	38.0 x 38.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-652	₹2,024 Volume Pricing	Contact Us
-	4 - 6λ	38.0 x 38.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-422	₹2,024 Volume Pricing	20+ In Stock
-	4 - 6λ	38.0 x 51.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-425	₹2,024 Volume Pricing	20+ In Stock
-	4 - 6λ	38.0 x 150.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-442	₹2,238 Volume Pricing	20+ In Stock
38.10	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-247	₹2,024 Volume Pricing	8 In Stock
-	4 - 6λ	38.1 x 38.1	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-248	₹2,024 Volume Pricing	20+ In Stock
-	4 - 6λ	38.1 x 53.9	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#83-537	₹2,024 Volume Pricing	5 In Stock
-	4 - 6λ	50.0 x 125.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-365	₹2,686 Volume Pricing	20+ In Stock
50.80	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-249	₹2,686 Volume Pricing	20+ In Stock
-	4 - 6λ	50.8 x 50.8	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-250	₹2,686 Volume Pricing	20+ In Stock
-	4 - 6λ	50.8 x 71.8	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#83-538	₹2,686 Volume Pricing	20+ In Stock

-	4 - 6λ	51.0 x 76.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#40-040	₹2,686 Volume Pricing	20+ In Stock
-	4 - 6λ	60.0 x 270.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-279	₹8,953 Volume Pricing	2 In Stock
-	4 - 6λ	73.0 x 116.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-371	₹3,153 Volume Pricing	20+ In Stock
-	4 - 6λ	76.0 x 102.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#40-041	₹3,153 Volume Pricing	15 In Stock
76.20	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-251	₹3,153 Volume Pricing	20+ In Stock

[#69-252 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

-	4 - 6λ	76.2 x 76.2	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00		₹3,153 Volume Pricing	20+ In Stock
-	4 - 6λ	76.2 x 107.8	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#83-539	₹3,153 Volume Pricing	20+ In Stock
-	4 - 6λ	81.0 x 100.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#41-621	₹3,153 Volume Pricing	20+ In Stock
-	4 - 6λ	85.0 x 101.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-362	₹3,153 Volume Pricing	20+ In Stock

-	4 - 6λ	102.0 x 127.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#40-042	₹5,839 Volume Pricing	20+ In Stock
-	4 - 6λ	127.0 x 178.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#41-320	₹5,839 Volume Pricing	20+ In Stock
-	4 - 6λ	127.0 x 178.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#40-043	₹5,839 Volume Pricing	Contact Us
-	4 - 6λ	169.0 x 194.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#41-405	₹5,839 Volume Pricing	13 In Stock
-	4 - 6λ	200.0 x 235.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-358	₹12,378 Volume Pricing	20+ In Stock
-	4 - 6λ	204.0 x 254.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#41-321	₹12,378 Volume Pricing	20+ In Stock
-	4 - 6λ	204.0 x 254.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#40-067	₹12,378 Volume Pricing	9 In Stock
-	4 - 6λ	254.0 x 254.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-653	₹12,378 Volume Pricing	20+ In Stock
-	4 - 6λ	254.0 x 313.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-654	₹12,845 Volume Pricing	8 In Stock
-	4 - 6λ	254.0 x 313.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-248	₹12,845 Volume Pricing	20+ In Stock
-	4 - 6λ	254.0 x 356.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#85-036	₹18,684 Volume Pricing	1 In Stock
-	4 - 6λ	356.0 x 356.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-655	₹18,684 Volume Pricing	5 In Stock
-	4 - 6λ	406.0 x 406.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-656	₹20,942 Volume Pricing	11 In Stock

-	4 - 6λ	406.0 x 406.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#85-206	₹22,966 Volume Pricing	7 In Stock
-	4 - 6λ	408.0 x 609.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#85-207	₹33,086 Volume Pricing	20+ In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
 Phone: 1-800-363-1992 :
www.edmundoptics.com