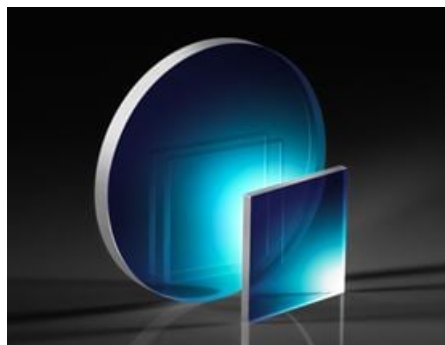


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)
TECHSPEC® $\lambda/10$ UV Fused Silica Windows


- UV, Visible, and NIR Anti-Reflection Coated Versions Available
- $\lambda/10$ Transmitted Wavefront Distortion
- Circular and Square Sizes from 2mm to 150mm
- [1 \$\lambda\$](#) or [\$\lambda/4\$](#) UV Fused Silica Windows Also Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Edges:	Fine Ground
Knoop Hardness (kg/mm²):	522.00	Poisson's Ratio:	0.16
Young's Modulus (GPa):	73		



Optical Properties

Abbe Number (v_d):	67.8
Index of Refraction (n_d):	1.458

Material Properties

Density (g/cm³):	2.20
------------------------------------	------

Technical Information

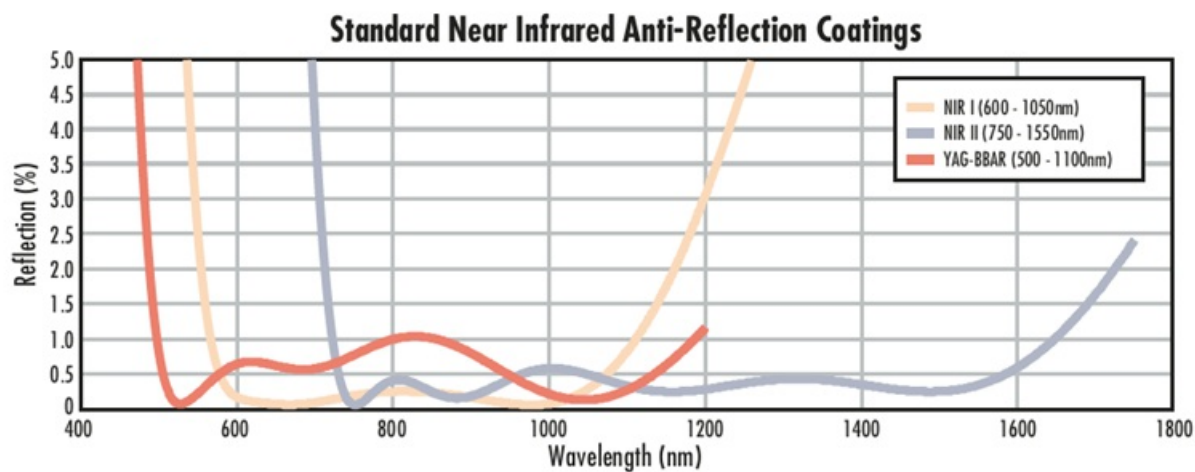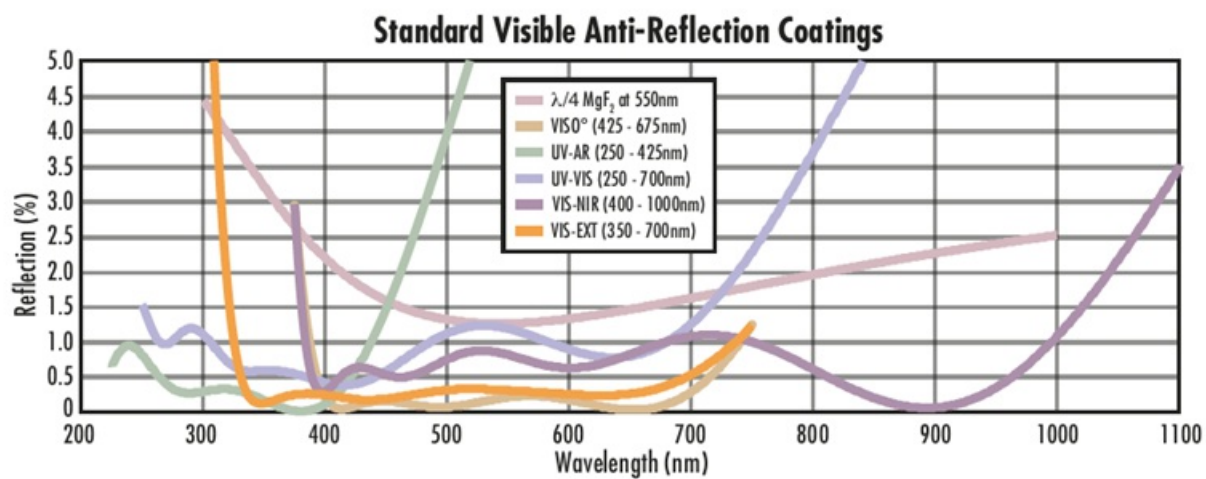

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
2.00	-	1.00	Uncoated	#27-669	₹6,968 Volume Pricing	Contact Us
2.50	-	1.00	Uncoated	#27-670	₹6,968 Volume Pricing	20+ In Stock
3.00	-	1.00	Uncoated	#27-671	₹7,335 Volume Pricing	20+ In Stock
4.00	-	1.00	Uncoated	#27-672	₹7,775 Volume Pricing	17 In Stock
5.00	-	1.00	Uncoated	#47-833	₹8,729 Volume Pricing	20+ In Stock
10.00	-	1.25	Uncoated	#47-192	₹8,289 Volume Pricing	20+ In Stock
12.50	-	1.50	Uncoated	#47-193	₹8,509 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	Uncoated	#23-136	₹8,509 Volume Pricing	20+ In Stock
12.50	-	2.00	Uncoated	#63-107	₹8,509 Volume Pricing	20+ In Stock
12.70	-	1.50	Uncoated	#15-402	₹8,509 Volume Pricing	Contact Us
15.00	-	2.00	Uncoated	#47-194	₹8,875 Volume Pricing	20+ In Stock
20.00	-	2.00	Uncoated	#63-204	₹9,462 Volume Pricing	20+ In Stock
25.00	-	1.00	Uncoated	#11-876	₹10,049 Volume Pricing	Contact Us
25.00	-	2.00	Uncoated	#11-877	₹10,049 Volume Pricing	20+ In Stock
25.00	-	3.00	Uncoated	#47-195	₹10,049 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	Uncoated	#23-137	₹10,049 Volume Pricing	20+ In Stock
25.00	-	5.00	Uncoated	#11-878	₹10,049 Volume Pricing	20+ In Stock

25.40	-	3.00	Uncoated	#15-403	₹10,049 Volume Pricing	1 In Stock
30.00	-	4.00	Uncoated	#47-834	₹12,763 Volume Pricing	20+ In Stock
40.00	-	4.00	Uncoated	#47-835	₹14,523 Volume Pricing	20+ In Stock
50.00	-	1.00	Uncoated	#34-599	₹17,604 Volume Pricing	20+ In Stock
50.00	-	2.00	Uncoated	#34-600	₹17,604 Volume Pricing	Contact Us
50.00	-	3.00	Uncoated	#34-601	₹17,604 Volume Pricing	20+ In Stock
50.00	-	5.00	Uncoated	#47-836	₹17,604 Volume Pricing	20+ In Stock
-	50.00 x 50.00	5.00	Uncoated	#23-138	₹17,604 Volume Pricing	Contact Us
50.00	-	6.00	Uncoated	#34-602	₹17,604 Volume Pricing	5 In Stock
50.80	-	5.00	Uncoated	#15-404	₹17,604 Volume Pricing	8 In Stock
75.00	-	3.00	Uncoated	#36-935	₹29,413 Volume Pricing	20+ In Stock
75.00	-	5.00	Uncoated	#36-936	₹29,413 Volume Pricing	20+ In Stock
100.00	-	5.00	Uncoated	#17-561	₹37,409 Volume Pricing	20+ In Stock
125.00	-	6.00	Uncoated	#17-562	₹47,311 Volume Pricing	17 In Stock
150.00	-	8.00	Uncoated	#17-563	₹65,648 Volume Pricing	20+ In Stock
5.00	-	1.00	UV-AR (250-425nm)	#65-870	₹10,856 Volume Pricing	11 In Stock
10.00	-	1.25	UV-AR (250-425nm)	#65-871	₹10,416 Volume Pricing	6 In Stock
12.50	-	1.50	UV-AR (250-425nm)	#65-872	₹10,636 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	UV-AR (250-425nm)	#24-296	₹10,636 Volume Pricing	2 In Stock

12.50	-	2.00	UV-AR (250-425nm)	#68-487	₹10,636 Volume Pricing	17 In Stock
12.70	-	1.50	UV-AR (250-425nm)	#15-405	₹10,636 Volume Pricing	Contact Us
15.00	-	2.00	UV-AR (250-425nm)	#65-873	₹11,003 Volume Pricing	20+ In Stock
20.00	-	2.00	UV-AR (250-425nm)	#65-874	₹11,589 Volume Pricing	20+ In Stock
25.00	-	1.00	UV-AR (250-425nm)	#11-879	₹12,176 Volume Pricing	1 In Stock
25.00	-	2.00	UV-AR (250-425nm)	#11-880	₹12,176 Volume Pricing	5 In Stock
25.00	-	3.00	UV-AR (250-425nm)	#65-875	₹12,176 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	UV-AR (250-425nm)	#24-304	₹12,176 Volume Pricing	8 In Stock
25.00	-	5.00	UV-AR (250-425nm)	#11-881	₹12,176 Volume Pricing	6 In Stock
25.40	-	3.00	UV-AR (250-425nm)	#15-406	₹12,176 Volume Pricing	8 In Stock
30.00	-	4.00	UV-AR (250-425nm)	#65-876	₹15,257 Volume Pricing	8 In Stock
40.00	-	4.00	UV-AR (250-425nm)	#65-877	₹17,017 Volume Pricing	1 In Stock
50.00	-	1.00	UV-AR (250-425nm)	#36-938	₹20,098 Volume Pricing	3 In Stock
50.00	-	2.00	UV-AR (250-425nm)	#36-943	₹20,098 Volume Pricing	Contact Us
50.00	-	3.00	UV-AR (250-425nm)	#36-948	₹20,098 Volume Pricing	5 In Stock
50.00	-	5.00	UV-AR (250-425nm)	#65-878	₹20,098 Volume Pricing	9 In Stock
-	50.00 x 50.00	5.00	UV-AR (250-425nm)	#24-312	₹20,098 Volume Pricing	1 In Stock
50.00	-	6.00	UV-AR (250-425nm)	#36-953	₹20,098 Volume Pricing	4 In Stock
50.80	-	5.00	UV-AR (250-425nm)	#15-407	₹20,098 Volume Pricing	1 In Stock

75.00	-	3.00	UV-AR (250-425nm)	#36-958	₹34,401 Volume Pricing	3 In Stock
75.00	-	5.00	UV-AR (250-425nm)	#36-963	₹34,401 Volume Pricing	4 In Stock
5.00	-	1.00	UV-VIS (250-700nm)	#48-062	₹10,856 Volume Pricing	15 In Stock
10.00	-	1.25	UV-VIS (250-700nm)	#48-063	₹10,416 Volume Pricing	20+ In Stock
12.50	-	1.50	UV-VIS (250-700nm)	#48-064	₹10,636 Volume Pricing	14 In Stock
-	12.50 x 12.50	1.50	UV-VIS (250-700nm)	#24-297	₹10,636 Volume Pricing	1 In Stock
12.50	-	2.00	UV-VIS (250-700nm)	#68-488	₹10,636 Volume Pricing	Contact Us
12.70	-	1.50	UV-VIS (250-700nm)	#15-408	₹10,636 Volume Pricing	1 In Stock
15.00	-	2.00	UV-VIS (250-700nm)	#48-065	₹11,003 Volume Pricing	3 In Stock
20.00	-	2.00	UV-VIS (250-700nm)	#63-206	₹11,589 Volume Pricing	12 In Stock
25.00	-	1.00	UV-VIS (250-700nm)	#11-882	₹12,176 Volume Pricing	7 In Stock
25.00	-	2.00	UV-VIS (250-700nm)	#11-883	₹12,176 Volume Pricing	15 In Stock
25.00	-	3.00	UV-VIS (250-700nm)	#48-066	₹12,176 Volume Pricing	5 In Stock
-	25.00 x 25.00	3.00	UV-VIS (250-700nm)	#24-305	₹12,176 Volume Pricing	4 In Stock
25.00	-	5.00	UV-VIS (250-700nm)	#11-884	₹12,176 Volume Pricing	11 In Stock
25.40	-	3.00	UV-VIS (250-700nm)	#15-409	₹12,176 Volume Pricing	5 In Stock
30.00	-	4.00	UV-VIS (250-700nm)	#48-067	₹15,257 Volume Pricing	10 In Stock
40.00	-	4.00	UV-VIS (250-700nm)	#48-068	₹17,017 Volume Pricing	2 In Stock
50.00	-	1.00	UV-VIS (250-700nm)	#36-939	₹20,098 Volume Pricing	Contact Us

50.00	-	2.00	UV-VIS (250-700nm)	#36-944	₹20,098 Volume Pricing	Contact Us
50.00	-	3.00	UV-VIS (250-700nm)	#36-949	₹20,098 Volume Pricing	7 In Stock
50.00	-	5.00	UV-VIS (250-700nm)	#48-069	₹20,098 Volume Pricing	5 In Stock
-	50.00 x 50.00	5.00	UV-VIS (250-700nm)	#24-313	₹20,098 Volume Pricing	6 In Stock
50.00	-	6.00	UV-VIS (250-700nm)	#36-954	₹20,098 Volume Pricing	1 In Stock
50.80	-	5.00	UV-VIS (250-700nm)	#15-410	₹20,098 Volume Pricing	3 In Stock
75.00	-	3.00	UV-VIS (250-700nm)	#36-959	₹34,401 Volume Pricing	20+ In Stock
75.00	-	5.00	UV-VIS (250-700nm)	#36-964	₹34,401 Volume Pricing	Contact Us
100.00	-	5.00	UV-VIS (250-700nm)	#22-064	₹57,947 Volume Pricing	8 In Stock
125.00	-	6.00	UV-VIS (250-700nm)	#22-065	₹74,450 Volume Pricing	5 In Stock
150.00	-	8.00	UV-VIS (250-700nm)	#22-066	₹98,656 Volume Pricing	2 In Stock
5.00	-	1.00	VIS-EXT (350-700nm)	#13-330	₹11,003 Volume Pricing	5 In Stock
10.00	-	1.25	VIS-EXT (350-700nm)	#13-331	₹10,636 Volume Pricing	7 In Stock
-	12.50 x 12.50	1.50	VIS-EXT (350-700nm)	#24-301	₹10,856 Volume Pricing	4 In Stock
12.50	-	1.50	VIS-EXT (350-700nm)	#13-332	₹10,856 Volume Pricing	7 In Stock
12.50	-	2.00	VIS-EXT (350-700nm)	#13-333	₹10,856 Volume Pricing	5 In Stock
12.70	-	1.50	VIS-EXT (350-700nm)	#15-781	₹10,856 Volume Pricing	11 In Stock
15.00	-	2.00	VIS-EXT (350-700nm)	#13-334	₹11,223 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS-EXT (350-700nm)	#13-335	₹11,809 Volume Pricing	9 In Stock

25.00	-	1.00	VIS-EXT (350-700nm)	#13-336	₹12,396 Volume Pricing	Contact Us
25.00	-	2.00	VIS-EXT (350-700nm)	#13-337	₹12,396 Volume Pricing	12 In Stock
-	25.00 x 25.00	3.00	VIS-EXT (350-700nm)	#24-309	₹12,396 Volume Pricing	1 In Stock
25.00	-	3.00	VIS-EXT (350-700nm)	#13-338	₹12,396 Volume Pricing	5 In Stock
25.00	-	5.00	VIS-EXT (350-700nm)	#13-339	₹12,396 Volume Pricing	8 In Stock
25.40	-	3.00	VIS-EXT (350-700nm)	#15-782	₹12,396 Volume Pricing	4 In Stock
30.00	-	4.00	VIS-EXT (350-700nm)	#16-461	₹15,477 Volume Pricing	2 In Stock
40.00	-	4.00	VIS-EXT (350-700nm)	#13-341	₹17,237 Volume Pricing	Contact Us
50.00	-	1.00	VIS-EXT (350-700nm)	#13-342	₹20,318 Volume Pricing	3 In Stock
50.00	-	2.00	VIS-EXT (350-700nm)	#13-343	₹20,318 Volume Pricing	Contact Us
50.00	-	3.00	VIS-EXT (350-700nm)	#13-344	₹20,318 Volume Pricing	2 In Stock
50.00	-	5.00	VIS-EXT (350-700nm)	#13-345	₹20,318 Volume Pricing	5 In Stock
-	50.00 x 50.00	5.00	VIS-EXT (350-700nm)	#24-317	₹20,318 Volume Pricing	7 In Stock
50.00	-	6.00	VIS-EXT (350-700nm)	#13-346	₹20,318 Volume Pricing	5 In Stock
50.80	-	5.00	VIS-EXT (350-700nm)	#15-783	₹20,318 Volume Pricing	Contact Us
75.00	-	3.00	VIS-EXT (350-700nm)	#15-799	₹34,841 Volume Pricing	2 In Stock
75.00	-	5.00	VIS-EXT (350-700nm)	#15-800	₹34,841 Volume Pricing	Contact Us
5.00	-	1.00	VIS-NIR (400-1000nm)	#84-449	₹11,003 Volume Pricing	4 In Stock

10.00	-	1.25	VIS-NIR (400-1000nm)	#84-450	₹10,636 Volume Pricing	9 In Stock
12.50	-	1.50	VIS-NIR (400-1000nm)	#84-451	₹10,856 Volume Pricing	11 In Stock
-	12.50 x 12.50	1.50	VIS-NIR (400-1000nm)	#24-302	₹10,856 Volume Pricing	1 In Stock
12.50	-	2.00	VIS-NIR (400-1000nm)	#84-452	₹10,856 Volume Pricing	1 In Stock
12.70	-	1.50	VIS-NIR (400-1000nm)	#15-414	₹10,856 Volume Pricing	1 In Stock
15.00	-	2.00	VIS-NIR (400-1000nm)	#84-453	₹11,223 Volume Pricing	1 In Stock
20.00	-	2.00	VIS-NIR (400-1000nm)	#84-454	₹11,809 Volume Pricing	20+ In Stock
25.00	-	1.00	VIS-NIR (400-1000nm)	#11-888	₹12,396 Volume Pricing	20+ In Stock
25.00	-	2.00	VIS-NIR (400-1000nm)	#11-889	₹12,396 Volume Pricing	9 In Stock
-	25.00 x 25.00	3.00	VIS-NIR (400-1000nm)	#24-310	₹12,396 Volume Pricing	5 In Stock
25.00	-	3.00	VIS-NIR (400-1000nm)	#84-455	₹12,396 Volume Pricing	20+ In Stock
25.00	-	5.00	VIS-NIR (400-1000nm)	#11-890	₹12,396 Volume Pricing	2 In Stock
25.40	-	3.00	VIS-NIR (400-1000nm)	#15-415	₹12,396 Volume Pricing	6 In Stock
30.00	-	4.00	VIS-NIR (400-1000nm)	#84-456	₹15,477 Volume Pricing	5 In Stock

40.00	-	4.00	VIS-NIR (400-1000nm)	#84-457	₹17,237 Volume Pricing	9 In Stock
50.00	-	1.00	VIS-NIR (400-1000nm)	#36-941	₹20,318 Volume Pricing	8 In Stock
50.00	-	2.00	VIS-NIR (400-1000nm)	#36-946	₹20,318 Volume Pricing	7 In Stock
50.00	-	3.00	VIS-NIR (400-1000nm)	#36-951	₹20,318 Volume Pricing	5 In Stock
50.00	-	5.00	VIS-NIR (400-1000nm)	#84-458	₹20,318 Volume Pricing	15 In Stock
-	50.00 x 50.00	5.00	VIS-NIR (400-1000nm)	#24-318	₹20,318 Volume Pricing	1 In Stock
50.00	-	6.00	VIS-NIR (400-1000nm)	#36-956	₹20,318 Volume Pricing	13 In Stock
50.80	-	5.00	VIS-NIR (400-1000nm)	#15-416	₹20,318 Volume Pricing	4 In Stock
75.00	-	3.00	VIS-NIR (400-1000nm)	#36-961	₹34,841 Volume Pricing	5 In Stock
75.00	-	5.00	VIS-NIR (400-1000nm)	#36-966	₹34,841 Volume Pricing	13 In Stock
100.00	-	5.00	VIS-NIR (400-1000nm)	#22-070	₹57,947 Volume Pricing	1 In Stock
125.00	-	6.00	VIS-NIR (400-1000nm)	#22-071	₹74,450 Volume Pricing	15 In Stock
150.00	-	8.00	VIS-NIR (400-1000nm)	#22-072	₹98,656 Volume Pricing	7 In Stock
5.00	-	1.00	VIS 0° (425-675nm)	#47-837	₹10,636 Volume Pricing	20+ In Stock

10.00	-	1.25	VIS 0° (425-675nm)	#47-196	₹10,269 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	VIS 0° (425-675nm)	#24-298	₹10,416 Volume Pricing	1 In Stock
12.50	-	1.50	VIS 0° (425-675nm)	#47-197	₹10,416 Volume Pricing	20+ In Stock
12.50	-	2.00	VIS 0° (425-675nm)	#68-489	₹10,416 Volume Pricing	10 In Stock
12.70	-	1.50	VIS 0° (425-675nm)	#15-411	₹10,416 Volume Pricing	4 In Stock
15.00	-	2.00	VIS 0° (425-675nm)	#47-198	₹10,856 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS 0° (425-675nm)	#63-205	₹11,443 Volume Pricing	4 In Stock
25.00	-	1.00	VIS 0° (425-675nm)	#11-885	₹12,029 Volume Pricing	1 In Stock
25.00	-	2.00	VIS 0° (425-675nm)	#11-886	₹12,029 Volume Pricing	17 In Stock
25.00	-	3.00	VIS 0° (425-675nm)	#47-199	₹12,029 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	VIS 0° (425-675nm)	#24-306	₹12,029 Volume Pricing	4 In Stock
25.00	-	5.00	VIS 0° (425-675nm)	#11-887	₹12,029 Volume Pricing	5 In Stock
25.40	-	3.00	VIS 0° (425-675nm)	#15-412	₹12,029 Volume Pricing	20+ In Stock
30.00	-	4.00	VIS 0° (425-675nm)	#47-838	₹15,110 Volume Pricing	8 In Stock
40.00	-	4.00	VIS 0° (425-675nm)	#47-839	₹16,797 Volume Pricing	13 In Stock
50.00	-	1.00	VIS 0° (425-675nm)	#36-940	₹19,951 Volume Pricing	10 In Stock
50.00	-	2.00	VIS 0° (425-675nm)	#36-945	₹19,951 Volume Pricing	14 In Stock
50.00	-	3.00	VIS 0° (425-675nm)	#36-950	₹19,951 Volume Pricing	7 In Stock
50.00	-	5.00	VIS 0° (425-675nm)	#47-840	₹19,951 Volume Pricing	20+ In Stock

-	50.00 x 50.00	5.00	VIS 0° (425-675nm)	#24-314	₹19,951 Volume Pricing	2 In Stock
50.00	-	6.00	VIS 0° (425-675nm)	#36-955	₹19,951 Volume Pricing	9 In Stock
50.80	-	5.00	VIS 0° (425-675nm)	#15-413	₹19,951 Volume Pricing	4 In Stock
75.00	-	3.00	VIS 0° (425-675nm)	#36-960	₹34,034 Volume Pricing	2 In Stock
75.00	-	5.00	VIS 0° (425-675nm)	#36-965	₹34,034 Volume Pricing	Contact Us
100.00	-	5.00	VIS 0° (425-675nm)	#22-067	₹56,846 Volume Pricing	10 In Stock
125.00	-	6.00	VIS 0° (425-675nm)	#22-068	₹72,250 Volume Pricing	4 In Stock
150.00	-	8.00	VIS 0° (425-675nm)	#22-069	₹96,822 Volume Pricing	3 In Stock
5.00	-	1.00	YAG-BBAR (500-1100nm)	#13-347	₹11,003 Volume Pricing	15 In Stock
10.00	-	1.25	YAG-BBAR (500-1100nm)	#13-348	₹10,636 Volume Pricing	13 In Stock
-	12.50 x 12.50	1.50	YAG-BBAR (500-1100nm)	#24-303	₹10,856 Volume Pricing	8 In Stock
12.50	-	1.50	YAG-BBAR (500-1100nm)	#13-349	₹10,856 Volume Pricing	1 In Stock
12.50	-	2.00	YAG-BBAR (500-1100nm)	#13-350	₹10,856 Volume Pricing	9 In Stock
12.70	-	1.50	YAG-BBAR (500-1100nm)	#15-784	₹10,856 Volume Pricing	4 In Stock
15.00	-	2.00	YAG-BBAR (500-1100nm)	#13-351	₹11,223 Volume Pricing	1 In Stock
20.00	-	2.00	YAG-BBAR (500-1100nm)	#13-352	₹11,809 Volume Pricing	9 In Stock

25.00	-	1.00	YAG-BBAR (500-1100nm)	#13-353	₹12,396 Volume Pricing	Contact Us
25.00	-	2.00	YAG-BBAR (500-1100nm)	#13-354	₹12,396 Volume Pricing	6 In Stock
-	25.00 x 25.00	3.00	YAG-BBAR (500-1100nm)	#24-311	₹12,396 Volume Pricing	3 In Stock
25.00	-	3.00	YAG-BBAR (500-1100nm)	#13-355	₹12,396 Volume Pricing	3 In Stock
25.00	-	5.00	YAG-BBAR (500-1100nm)	#13-356	₹12,396 Volume Pricing	3 In Stock
25.40	-	3.00	YAG-BBAR (500-1100nm)	#15-785	₹12,396 Volume Pricing	6 In Stock
30.00	-	4.00	YAG-BBAR (500-1100nm)	#13-357	₹15,477 Volume Pricing	8 In Stock
40.00	-	4.00	YAG-BBAR (500-1100nm)	#13-358	₹17,237 Volume Pricing	15 In Stock
50.00	-	1.00	YAG-BBAR (500-1100nm)	#13-359	₹20,318 Volume Pricing	1 In Stock
50.00	-	2.00	YAG-BBAR (500-1100nm)	#13-360	₹20,318 Volume Pricing	Contact Us
50.00	-	3.00	YAG-BBAR (500-1100nm)	#13-361	₹20,318 Volume Pricing	12 In Stock
50.00	-	5.00	YAG-BBAR (500-1100nm)	#13-362	₹20,318 Volume Pricing	14 In Stock
-	50.00 x 50.00	5.00	YAG-BBAR (500-1100nm)	#24-319	₹20,318 Volume Pricing	5 In Stock
50.00	-	6.00	YAG-BBAR (500-1100nm)	#13-363	₹20,318 Volume Pricing	12 In Stock

50.80	-	5.00	YAG-BBAR (500-1100nm)	#15-786	₹20,318 Volume Pricing	4 In Stock
75.00	-	3.00	YAG-BBAR (500-1100nm)	#15-801	₹34,841 Volume Pricing	2 In Stock
75.00	-	5.00	YAG-BBAR (500-1100nm)	#15-802	₹34,841 Volume Pricing	20+ In Stock
5.00	-	1.00	NIR I (600-1050nm)	#84-459	₹10,636 Volume Pricing	4 In Stock
10.00	-	1.25	NIR I (600-1050nm)	#84-460	₹10,269 Volume Pricing	20+ In Stock
12.50	-	1.50	NIR I (600-1050nm)	#84-461	₹10,416 Volume Pricing	7 In Stock
-	12.50 x 12.50	1.50	NIR I (600-1050nm)	#24-299	₹10,416 Volume Pricing	5 In Stock
12.50	-	2.00	NIR I (600-1050nm)	#84-462	₹10,416 Volume Pricing	20+ In Stock
12.70	-	1.50	NIR I (600-1050nm)	#15-417	₹10,416 Volume Pricing	2 In Stock
15.00	-	2.00	NIR I (600-1050nm)	#84-463	₹10,856 Volume Pricing	20+ In Stock
20.00	-	2.00	NIR I (600-1050nm)	#84-464	₹11,443 Volume Pricing	20+ In Stock
25.00	-	1.00	NIR I (600-1050nm)	#11-891	₹12,029 Volume Pricing	15 In Stock
25.00	-	2.00	NIR I (600-1050nm)	#11-892	₹12,029 Volume Pricing	1 In Stock
25.00	-	3.00	NIR I (600-1050nm)	#84-465	₹12,029 Volume Pricing	5 In Stock
25.00	-	5.00	NIR I (600-1050nm)	#11-893	₹12,029 Volume Pricing	1 In Stock
25.40	-	3.00	NIR I (600-1050nm)	#15-418	₹12,029 Volume Pricing	3 In Stock
-	25.00 x 25.00	3.00	NIR I (600-1050nm)	#24-307	₹12,029 Volume Pricing	1 In Stock
30.00	-	4.00	NIR I (600-1050nm)	#84-466	₹15,110 Volume Pricing	10 In Stock

40.00	-	4.00	NIR I (600-1050nm)	#84-467	₹16,797 Volume Pricing	4 In Stock
50.00	-	1.00	NIR I (600-1050nm)	#36-937	₹19,951 Volume Pricing	5 In Stock
50.00	-	2.00	NIR I (600-1050nm)	#36-942	₹19,951 Volume Pricing	14 In Stock
50.00	-	3.00	NIR I (600-1050nm)	#36-947	₹19,951 Volume Pricing	5 In Stock
50.00	-	5.00	NIR I (600-1050nm)	#84-468	₹19,951 Volume Pricing	Contact Us
-	50.00 x 50.00	5.00	NIR I (600-1050nm)	#24-315	₹19,951 Volume Pricing	2 In Stock
50.00	-	6.00	NIR I (600-1050nm)	#36-952	₹19,951 Volume Pricing	20+ In Stock
50.80	-	5.00	NIR I (600-1050nm)	#15-419	₹19,951 Volume Pricing	2 In Stock
75.00	-	3.00	NIR I (600-1050nm)	#36-957	₹34,034 Volume Pricing	1 In Stock
75.00	-	5.00	NIR I (600-1050nm)	#36-962	₹34,034 Volume Pricing	7 In Stock
5.00	-	1.00	NIR II (750-1550nm)	#11-894	₹10,636 Volume Pricing	Contact Us
10.00	-	1.25	NIR II (750-1550nm)	#11-895	₹10,269 Volume Pricing	5 In Stock
12.50	-	1.50	NIR II (750-1550nm)	#11-896	₹10,416 Volume Pricing	1 In Stock
-	12.50 x 12.50	1.50	NIR II (750-1550nm)	#24-300	₹10,416 Volume Pricing	2 In Stock
12.50	-	2.00	NIR II (750-1550nm)	#11-897	₹10,416 Volume Pricing	2 In Stock
12.70	-	1.50	NIR II (750-1550nm)	#15-420	₹10,416 Volume Pricing	1 In Stock
15.00	-	2.00	NIR II (750-1550nm)	#11-898	₹10,856 Volume Pricing	11 In Stock
20.00	-	2.00	NIR II (750-1550nm)	#11-899	₹11,443 Volume Pricing	12 In Stock
25.00	-	1.00	NIR II (750-1550nm)	#11-900	₹12,029 Volume Pricing	17 In Stock

25.00	-	2.00	NIR II (750-1550nm)	#11-901	₹12,029 Volume Pricing	13 In Stock
-	25.00 x 25.00	3.00	NIR II (750-1550nm)	#24-308	₹12,029 Volume Pricing	5 In Stock
25.00	-	3.00	NIR II (750-1550nm)	#11-902	₹12,029 Volume Pricing	16 In Stock
25.00	-	5.00	NIR II (750-1550nm)	#11-903	₹12,029 Volume Pricing	8 In Stock
25.40	-	3.00	NIR II (750-1550nm)	#15-421	₹12,029 Volume Pricing	5 In Stock
30.00	-	4.00	NIR II (750-1550nm)	#11-904	₹15,110 Volume Pricing	5 In Stock
40.00	-	4.00	NIR II (750-1550nm)	#11-905	₹16,797 Volume Pricing	4 In Stock
50.00	-	1.00	NIR II (750-1550nm)	#11-906	₹19,951 Volume Pricing	7 In Stock
50.00	-	2.00	NIR II (750-1550nm)	#11-907	₹19,951 Volume Pricing	12 In Stock
50.00	-	3.00	NIR II (750-1550nm)	#11-908	₹19,951 Volume Pricing	13 In Stock
50.00	-	5.00	NIR II (750-1550nm)	#11-909	₹19,951 Volume Pricing	4 In Stock
-	50.00 x 50.00	5.00	NIR II (750-1550nm)	#24-316	₹19,951 Volume Pricing	6 In Stock
50.00	-	6.00	NIR II (750-1550nm)	#11-910	₹19,951 Volume Pricing	12 In Stock
50.80	-	5.00	NIR II (750-1550nm)	#15-422	₹19,951 Volume Pricing	5 In Stock
75.00	-	3.00	NIR II (750-1550nm)	#11-911	₹34,034 Volume Pricing	20+ In Stock
75.00	-	5.00	NIR II (750-1550nm)	#11-912	₹34,034 Volume Pricing	10 In Stock
100.00	-	5.00	UV-AR (250-425nm)	#29-604	₹57,947 Volume Pricing	Contact Us
100.00	-	5.00	VIS-EXT (350-700nm)	#29-607	₹57,947 Volume Pricing	5 In Stock
100.00	-	5.00	NIR I (600-1050nm)	#29-605	₹56,846 Volume Pricing	1 In Stock

100.00	-	5.00	NIR II (750-1550nm)	#29-606	₹56,846 Volume Pricing	16 In Stock
100.00	-	5.00	YAG-BBAR (500-1100nm)	#29-608	₹57,947 Volume Pricing	Contact Us
100.00	-	10.00	Uncoated	#29-508	₹45,110 Volume Pricing	20+ In Stock
125.00	-	6.00	UV-AR (250-425nm)	#29-609	₹74,450 Volume Pricing	2 In Stock
125.00	-	6.00	VIS-EXT (350-700nm)	#29-612	₹74,450 Volume Pricing	1 In Stock
125.00	-	6.00	NIR I (600-1050nm)	#29-610	₹72,250 Volume Pricing	1 In Stock
125.00	-	6.00	NIR II (750-1550nm)	#29-611	₹72,250 Volume Pricing	5 In Stock
125.00	-	6.00	YAG-BBAR (500-1100nm)	#29-613	₹74,450 Volume Pricing	2 In Stock
125.00	-	12.50	Uncoated	#29-509	₹57,947 Volume Pricing	4 In Stock
150.00	-	8.00	UV-AR (250-425nm)	#29-614	₹98,656 Volume Pricing	1 In Stock
150.00	-	8.00	VIS-EXT (350-700nm)	#29-617	₹98,656 Volume Pricing	1 In Stock
150.00	-	8.00	NIR I (600-1050nm)	#29-615	₹96,822 Volume Pricing	2 In Stock
150.00	-	8.00	NIR II (750-1550nm)	#29-616	₹96,822 Volume Pricing	3 In Stock
150.00	-	8.00	YAG-BBAR (500-1100nm)	#29-618	₹98,656 Volume Pricing	1 In Stock
150.00	-	15.00	Uncoated	#29-510	₹91,688 Volume Pricing	5 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com