

[All Products](#) / [Imaging Lenses](#) / [M12 Lenses \(S-Mount Lenses\)](#)

TECHSPEC® Red Series M12 Lenses




- Up to 1/2", S-Mount Lens
- Up to 1.3 MegaPixels, 5µm Pixel Size Sensors
- Board Camera Lens Optimized Long WD and Infinite Conjugate
- 3.6mm to 8mm Focal Lengths


Common Specifications

General			
Series:	Red Series	IR Cut Filter:	No
Imaging Lens Type:	Standard Lens		
Physical & Mechanical Properties			
Iris Option:	Fixed		
Maximum Diameter (mm):	14	Outer Diameter (mm):	14
Optical Properties			
Wavelength Range (nm):	400 - 700	Working Distance (mm):	400 - ∞
Sensor			
Pixel Size (μm):	5.00		
Threading & Mounting			
Filter Thread:	N/A		
Mount:	S-Mount (M12 x 0.5)		


Technical Information

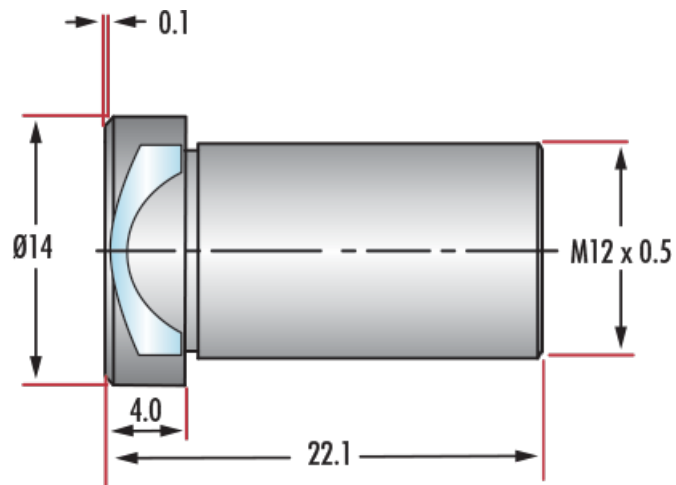


#57-910

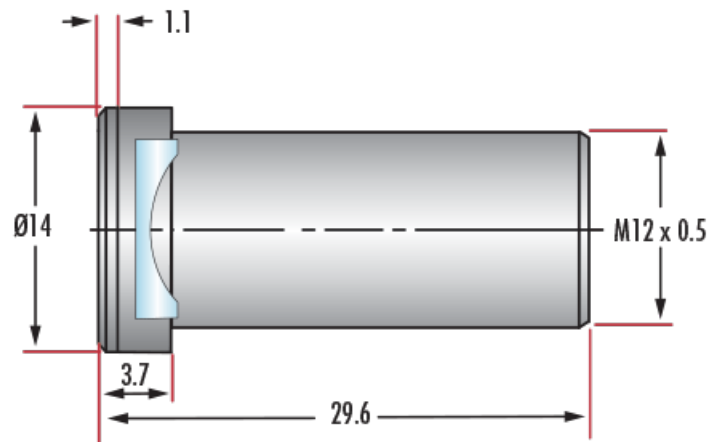

#57-909

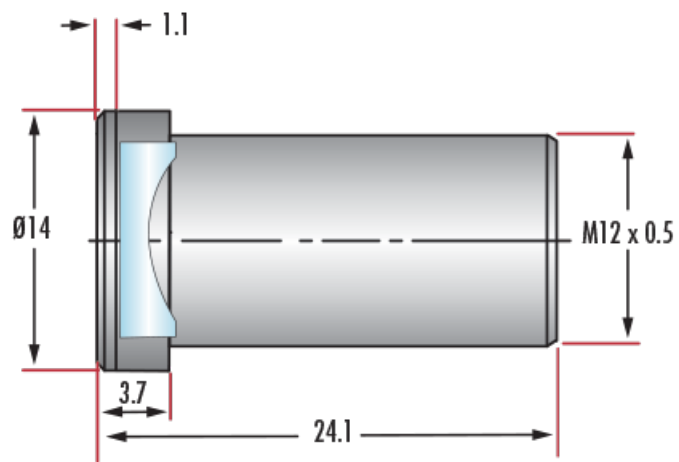

#57-908

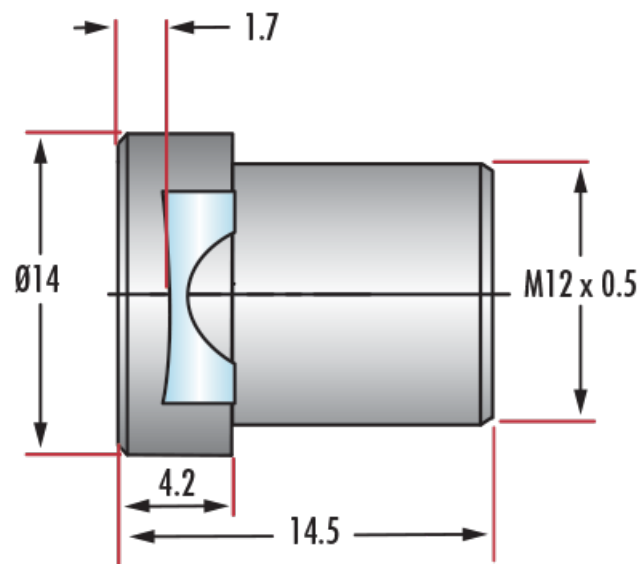

#57-907

Products

FL (mm)	Aperture (f/#)	Max. Sensor Format	WD (mm)	IR Cut Filter	Stock Number	Price	Buy
3.60	f/2.5	1/3.2"	400 - ∞	No	#57-907	₹6,029	Contact Us
4.40	f/1.9	1/3"	400 - ∞	No	#57-908	₹6,029	4 In Stock
6.40	f/1.9	1/3"	400 - ∞	No	#57-909	₹6,029	5 In Stock
7.20	f/1.8	1/3"	400 - ∞	No	#57-910	₹6,029	Contact Us
8.00	f/2.5	1/2"	400 - ∞	No	#69-255	₹6,029	6 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com