

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Aspheric Lenses](#) / [Glass Polished](#)

TECHSPEC® Aspheric Lenses



- Diameters from 10 to 200mm
- Focal Lengths from 7.5 to 300mm
- Broadband AR Coatings Available



Common Specifications

Physical & Mechanical Properties

Centering (arcmin): ≤ 5

Bevel: Protective bevel as needed


Optical Properties

Asphere Figure Error, RMS @ 632.8nm: 1.2λ

Surface Quality: 60-40

Conjugate Distance: Infinite

Technical Information

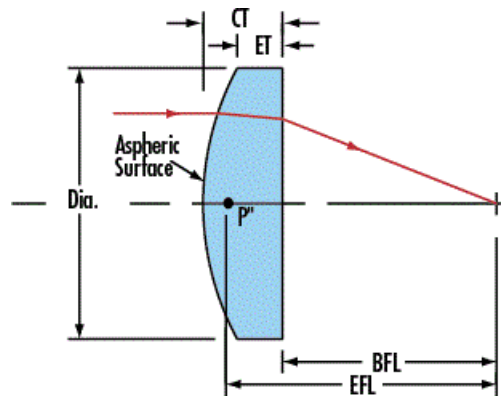

Products

Dia. (mm)	EFL (mm)	NA	Coating	Stock Number	Price	Buy
10.00	10.00	0.50	BBAR (425-675nm)	#69-857	₹17,400 Qty 6+ ₹13,920	10 to 12 days
10.00	10.00	0.50	BBAR (600-1050nm)	#69-861	₹17,400 Qty 6+ ₹13,920	10 to 12 days
10.00	10.00	0.50	Uncoated	#69-853	₹15,660 Qty 6+ ₹12,528	10 to 12 days
10.00	7.50	0.67	BBAR (425-675nm)	#69-856	₹17,400 Qty 6+ ₹13,920	10 to 12 days
10.00	7.50	0.67	BBAR (600-1050nm)	#69-860	₹17,400 Qty 6+ ₹13,920	10 to 12 days
10.00	7.50	0.67	Uncoated	#69-852	₹15,660 Qty 6+ ₹12,528	10 to 12 days
12.50	12.50	0.50	BBAR (425-675nm)	#69-859	₹18,705 Qty 6+ ₹14,964	10 to 12 days
12.50	12.50	0.50	BBAR (600-1050nm)	#69-863	₹18,705 Qty 6+ ₹14,964	10 to 12 days
12.50	12.50	0.50	Uncoated	#69-855	₹16,965 Qty 6+ ₹13,572	10 to 12 days
12.50	9.50	0.66	BBAR (425-675nm)	#69-858	₹18,705 Qty 6+ ₹14,964	10 to 12 days
12.50	9.50	0.66	BBAR (600-1050nm)	#69-862	₹18,705 Qty 6+ ₹14,964	10 to 12 days
12.50	9.50	0.66	Uncoated	#69-854	₹16,965 Qty 6+ ₹13,572	10 to 12 days
15.00	22.50	0.33	BBAR (425-675nm)	#49-100	₹21,315 Qty 6+ ₹17,052	10 to 12 days
15.00	22.50	0.33	BBAR (600-1050nm)	#49-112	₹20,880 Qty 6+ ₹16,704	10 to 12 days
15.00	22.50	0.33	Uncoated	#47-728	₹19,575 Qty 6+ ₹15,660	10 to 12 days
15.00	18.75	0.40	BBAR (425-675nm)	#49-099	₹21,315 Qty 6+ ₹17,052	10 to 12 days

15.00	18.75	0.40	BBAR (600-1050nm)	#49-111	₹20,880 Qty 6+ ₹16,704	Contact Us
15.00	18.75	0.40	Uncoated	#47-727	₹19,575 Qty 6+ ₹15,660	Contact Us
15.00	15.00	0.50	BBAR (425-675nm)	#49-098	₹21,315 Qty 6+ ₹17,052	10 to 12 days
15.00	15.00	0.50	BBAR (600-1050nm)	#49-110	₹20,880 Qty 6+ ₹16,704	10 to 12 days
15.00	15.00	0.50	Uncoated	#47-726	₹19,575 Qty 6+ ₹15,660	10 to 12 days
15.00	11.25	0.66	BBAR (425-675nm)	#49-097	₹21,315 Qty 6+ ₹17,052	10 to 12 days
15.00	11.25	0.66	BBAR (600-1050nm)	#49-109	₹20,880 Qty 6+ ₹16,704	10 to 12 days
15.00	11.25	0.66	Uncoated	#47-725	₹19,575 Qty 6+ ₹15,660	10 to 12 days
15.00	9.00	0.83	BBAR (425-675nm)	#67-250	₹30,450 Qty 6+ ₹24,360	10 to 12 days
15.00	9.00	0.83	BBAR (600-1050nm)	#67-257	₹30,450 Qty 6+ ₹24,360	10 to 12 days
15.00	9.00	0.83	Uncoated	#67-243	₹28,710 Qty 6+ ₹22,968	10 to 12 days
20.00	20.00	0.50	BBAR (425-675nm)	#66-320	₹23,055 Qty 6+ ₹18,444	10 to 12 days
20.00	20.00	0.50	BBAR (600-1050nm)	#66-330	₹23,055 Qty 6+ ₹18,444	10 to 12 days
20.00	20.00	0.50	Uncoated	#66-310	₹21,315 Qty 6+ ₹17,052	10 to 12 days
20.00	15.00	0.66	BBAR (425-675nm)	#66-319	₹23,055 Qty 6+ ₹18,444	10 to 12 days
20.00	15.00	0.66	BBAR (600-1050nm)	#66-329	₹23,055 Qty 6+ ₹18,444	10 to 12 days
20.00	15.00	0.66	Uncoated	#66-309	₹21,315 Qty 6+ ₹17,052	10 to 12 days
20.00	12.50	0.80	BBAR (425-675nm)	#67-251	₹33,060 Qty 6+ ₹26,448	10 to 12 days
20.00	12.50	0.80	BBAR (600-1050nm)	#67-258	₹33,060 Qty 6+ ₹26,448	10 to 12 days

20.00	12.50	0.80	Uncoated	#67-244	₹31,320 Qty 6+ ₹25,056	10 to 12 days
25.00	50.00	0.25	BBAR (425-675nm)	#33-945	₹26,100 Qty 6+ ₹20,880	10 to 12 days
25.00	50.00	0.25	BBAR (600-1050nm)	#33-946	₹26,100 Qty 6+ ₹20,880	Contact Us
25.00	50.00	0.25	Uncoated	#33-944	₹22,620 Qty 6+ ₹18,096	10 to 12 days
25.00	37.50	0.33	BBAR (425-675nm)	#49-104	₹26,100 Qty 6+ ₹20,880	10 to 12 days
25.00	37.50	0.33	BBAR (600-1050nm)	#49-116	₹26,100 Qty 6+ ₹20,880	Contact Us
25.00	37.50	0.33	Uncoated	#47-732	₹22,620 Qty 6+ ₹18,096	10 to 12 days
25.00	31.25	0.40	BBAR (425-675nm)	#49-103	₹26,100 Qty 6+ ₹20,880	10 to 12 days
25.00	31.25	0.40	BBAR (600-1050nm)	#49-115	₹26,100 Qty 6+ ₹20,880	10 to 12 days
25.00	31.25	0.40	Uncoated	#47-731	₹22,620 Qty 6+ ₹18,096	10 to 12 days
25.00	25.00	0.50	BBAR (425-675nm)	#49-102	₹26,100 Qty 6+ ₹20,880	10 to 12 days
25.00	25.00	0.50	BBAR (600-1050nm)	#49-114	₹26,100 Qty 6+ ₹20,880	10 to 12 days
25.00	25.00	0.50	Uncoated	#47-730	₹22,620 Qty 6+ ₹18,096	10 to 12 days
25.00	18.75	0.66	BBAR (425-675nm)	#49-101	₹26,100 Qty 6+ ₹20,880	10 to 12 days
25.00	18.75	0.66	BBAR (600-1050nm)	#49-113	₹26,100 Qty 6+ ₹20,880	10 to 12 days
25.00	18.75	0.66	Uncoated	#47-729	₹22,620 Qty 6+ ₹18,096	10 to 12 days
25.00	15.00	0.83	BBAR (425-675nm)	#67-252	₹37,410 Qty 6+ ₹29,928	10 to 12 days
25.00	15.00	0.83	BBAR (600-1050nm)	#67-259	₹37,410 Qty 6+ ₹29,928	10 to 12 days

25.00	15.00	0.83	Uncoated	#67-245	₹33,930 Qty 6+ ₹27,144	10 to 12 days
30.00	30.00	0.50	BBAR (425-675nm)	#66-322	₹30,450 Qty 6+ ₹24,360	10 to 12 days
30.00	30.00	0.50	BBAR (600-1050nm)	#66-332	₹30,450 Qty 6+ ₹24,360	10 to 12 days
30.00	30.00	0.50	Uncoated	#66-312	₹26,970 Qty 6+ ₹21,576	10 to 12 days
30.00	22.50	0.66	BBAR (425-675nm)	#66-321	₹30,450 Qty 6+ ₹24,360	Contact Us
30.00	22.50	0.66	BBAR (600-1050nm)	#66-331	₹30,450 Qty 6+ ₹24,360	10 to 12 days
30.00	22.50	0.66	Uncoated	#66-311	₹26,970 Qty 6+ ₹21,576	Contact Us
30.00	17.50	0.86	BBAR (425-675nm)	#67-253	₹42,630 Qty 6+ ₹34,104	10 to 12 days
30.00	17.50	0.86	BBAR (600-1050nm)	#67-260	₹41,760 Qty 6+ ₹33,408	10 to 12 days
30.00	17.50	0.86	Uncoated	#67-246	₹38,280 Qty 6+ ₹30,624	10 to 12 days
40.00	40.00	0.50	BBAR (425-675nm)	#66-324	₹41,325 Qty 6+ ₹33,060	10 to 12 days
40.00	40.00	0.50	BBAR (600-1050nm)	#66-334	₹41,325 Qty 6+ ₹33,060	10 to 12 days
40.00	40.00	0.50	Uncoated	#66-314	₹37,845 Qty 6+ ₹30,276	10 to 12 days
40.00	30.00	0.66	BBAR (425-675nm)	#66-323	₹41,325 Qty 6+ ₹33,060	10 to 12 days
40.00	30.00	0.66	BBAR (600-1050nm)	#66-333	₹41,325 Qty 6+ ₹33,060	10 to 12 days
40.00	30.00	0.66	Uncoated	#66-313	₹37,845 Qty 6+ ₹30,276	10 to 12 days
40.00	25.00	0.80	BBAR (425-675nm)	#67-254	₹50,460 Qty 6+ ₹40,368	10 to 12 days
40.00	25.00	0.80	BBAR (600-1050nm)	#67-261	₹51,765 Qty 6+ ₹41,412	10 to 12 days
40.00	25.00	0.80	Uncoated	#67-247	₹46,980 Qty 6+ ₹37,584	10 to 12 days

50.00	50.00	0.50	BBAR (425-675nm)	#66-326	₹47,850 Qty 6+ ₹38,280	10 to 12 days
50.00	50.00	0.50	BBAR (600-1050nm)	#66-336	₹47,850 Qty 6+ ₹38,280	Contact Us
50.00	50.00	0.50	Uncoated	#66-316	₹44,370 Qty 6+ ₹35,496	10 to 12 days
50.00	37.50	0.66	BBAR (425-675nm)	#66-325	₹47,850 Qty 6+ ₹38,280	10 to 12 days
50.00	37.50	0.66	BBAR (600-1050nm)	#66-335	₹47,850 Qty 6+ ₹38,280	10 to 12 days
50.00	37.50	0.66	Uncoated	#66-315	₹44,370 Qty 6+ ₹35,496	10 to 12 days
50.00	30.00	0.83	BBAR (425-675nm)	#67-255	₹67,425 Qty 6+ ₹53,940	10 to 12 days
50.00	30.00	0.83	BBAR (600-1050nm)	#67-262	₹66,990 Qty 6+ ₹53,592	10 to 12 days
50.00	30.00	0.83	Uncoated	#67-248	₹63,510 Qty 6+ ₹50,808	10 to 12 days
75.00	112.50	0.33	Uncoated	#15-000	₹64,380 Qty 6+ ₹51,504	10 to 12 days
75.00	112.50	0.33	BBAR (425-675nm)	#22-704	₹69,600 Qty 6+ ₹55,680	10 to 12 days
75.00	112.50	0.33	BBAR (600-1050nm)	#22-714	₹69,600 Qty 6+ ₹55,680	10 to 12 days
75.00	75.00	0.50	Uncoated	#14-997	₹64,380 Qty 6+ ₹51,504	10 to 12 days
75.00	75.00	0.50	BBAR (425-675nm)	#22-705	₹69,600 Qty 6+ ₹55,680	Contact Us
75.00	75.00	0.50	BBAR (600-1050nm)	#22-715	₹69,600 Qty 6+ ₹55,680	10 to 12 days
75.00	60.00	0.63	Uncoated	#14-994	₹64,380 Qty 6+ ₹51,504	10 to 12 days
75.00	60.00	0.63	BBAR (425-675nm)	#22-706	₹69,600 Qty 6+ ₹55,680	10 to 12 days
75.00	60.00	0.63	BBAR (600-1050nm)	#22-716	₹69,600 Qty 6+ ₹55,680	10 to 12 days

100.00	150.00	0.33	Uncoated	#15-009	₹82,650 Qty 6+ ₹66,120	10 to 12 days
100.00	150.00	0.33	BBAR (425-675nm)	#22-707	₹91,350 Qty 6+ ₹73,080	10 to 12 days
100.00	150.00	0.33	BBAR (600-1050nm)	#22-717	₹91,350 Qty 6+ ₹73,080	10 to 12 days
100.00	100.00	0.50	Uncoated	#15-006	₹82,650 Qty 6+ ₹66,120	10 to 12 days
100.00	100.00	0.50	BBAR (425-675nm)	#22-708	₹91,350 Qty 6+ ₹73,080	10 to 12 days
100.00	100.00	0.50	BBAR (600-1050nm)	#22-718	₹91,350 Qty 6+ ₹73,080	10 to 12 days
100.00	80.00	0.63	Uncoated	#15-003	₹82,650 Qty 6+ ₹66,120	10 to 12 days
100.00	80.00	0.63	BBAR (425-675nm)	#22-709	₹91,350 Qty 6+ ₹73,080	10 to 12 days
100.00	80.00	0.63	BBAR (600-1050nm)	#22-719	₹91,350 Qty 6+ ₹73,080	10 to 12 days
150.00	225.00	0.33	Uncoated	#15-018	₹1,82,700 Qty 6+ ₹1,46,160	10 to 12 days
150.00	225.00	0.33	BBAR (425-675nm)	#22-710	₹1,95,750 Qty 6+ ₹1,56,600	10 to 12 days
150.00	225.00	0.33	BBAR (600-1050nm)	#22-720	₹1,95,750 Qty 6+ ₹1,56,600	10 to 12 days
150.00	150.00	0.50	Uncoated	#15-015	₹1,82,700 Qty 6+ ₹1,46,160	10 to 12 days
150.00	150.00	0.50	BBAR (425-675nm)	#22-711	₹1,95,750 Qty 6+ ₹1,56,600	10 to 12 days
150.00	150.00	0.50	BBAR (600-1050nm)	#22-721	₹1,95,750 Qty 6+ ₹1,56,600	10 to 12 days
150.00	120.00	0.63	Uncoated	#15-012	₹1,82,700 Qty 6+ ₹1,46,160	10 to 12 days
150.00	120.00	0.63	BBAR (425-675nm)	#22-712	₹1,95,750 Qty 6+ ₹1,56,600	10 to 12 days
150.00	120.00	0.63	BBAR (600-1050nm)	#22-722	₹1,95,750 Qty 6+ ₹1,56,600	10 to 12 days

200.00 300.00 0.33 Uncoated

[#15-027](#)

₹3,34,950
Qty 6+ ₹2,67,960

10 to 12 days



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com