

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters



- Ideal for Life Sciences or Chemical Analysis
- Available in UV, VIS, and IR Center Wavelengths
- Feature High Performance Hard Coatings
- Hard Coated OD 4.0 [5nm](#), [25nm](#), and [50nm](#) Bandpass Filters Also Available

Common Specifications

Physical & Mechanical Properties



Construction:	Mounted in Black Anodized Ring	Physical Durability:	Adhesion per MIL-PRF-13830B, Section C.4.5.12 Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11 Cleaning per MIL-C-48497A Section 4.5.4.2
---------------	--------------------------------	----------------------	--


Optical Properties			
Angle of Incidence (°):	0	Optical Density OD (Average):	≥4.0
Full Width-Half Max FWHM (nm):	10.00 ±2.0	Full Width-Half Max FWHM Tolerance (nm):	±2.0
Coating:	Hard Coated	Surface Quality:	80-50

Threading & Mounting	
Mount Thickness (mm):	5.0 ±0.1

Environmental & Durability Factors	
Environmental Durability:	Humidity per MIL-STD-810H, Section 507.6 Temperature per MIL-STD-810H, Section 501.7 and 502.7


Technical Information

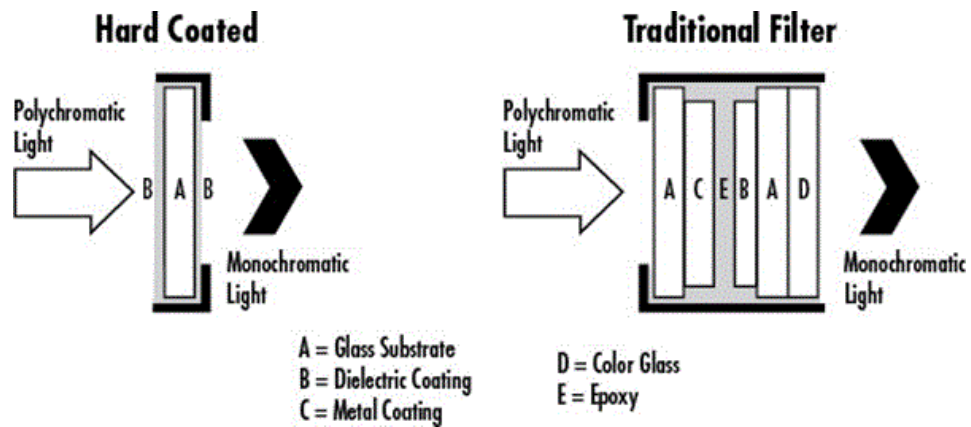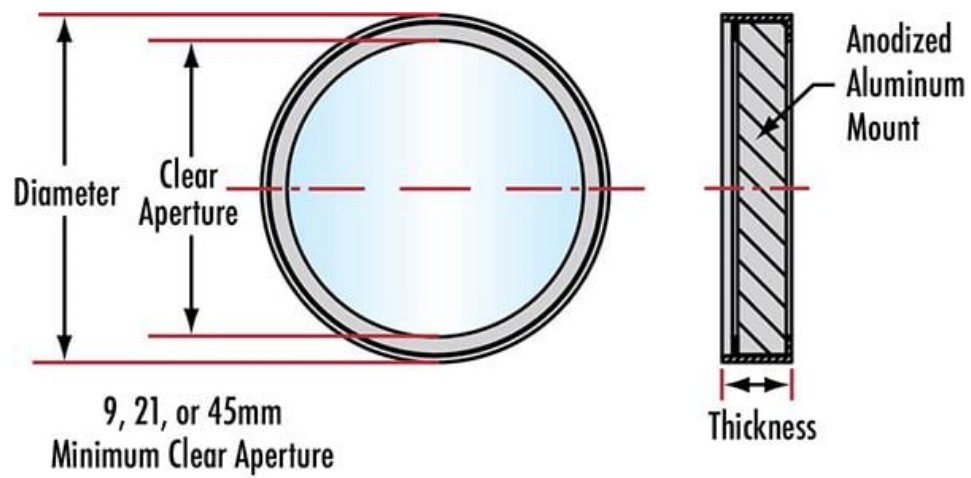

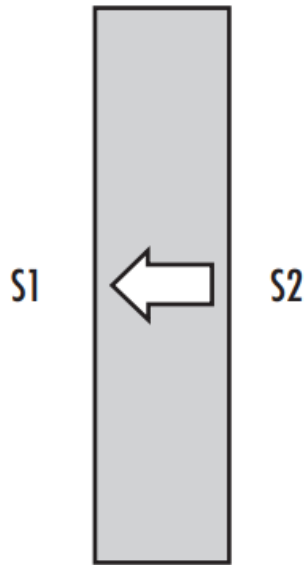


All mounted TECHSPEC® Optical Filters have an arrow on the side of the mount that points to the filter-coated surface for quick reference. Filter oriented such that arrow points to filter coated surface S1. Anti-reflective (AR) coating is applied to S2.


TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters UV

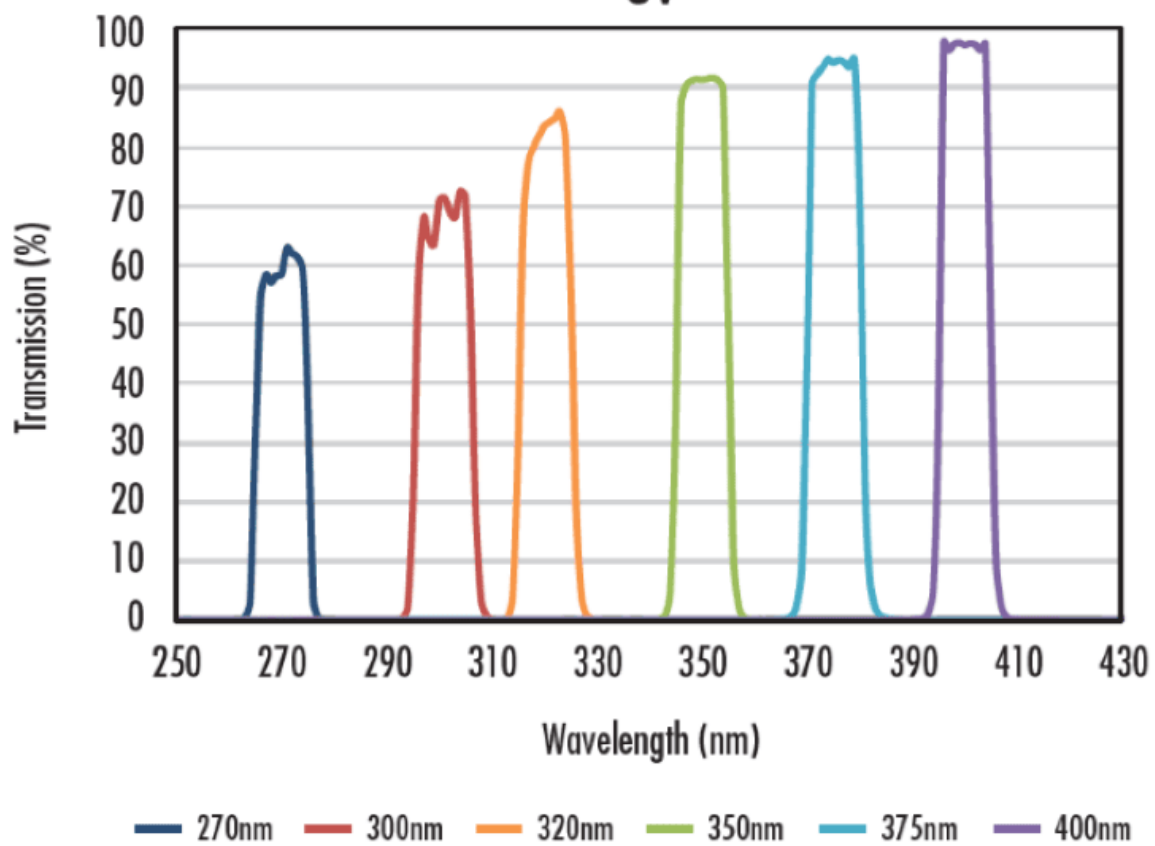

TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters
VIS

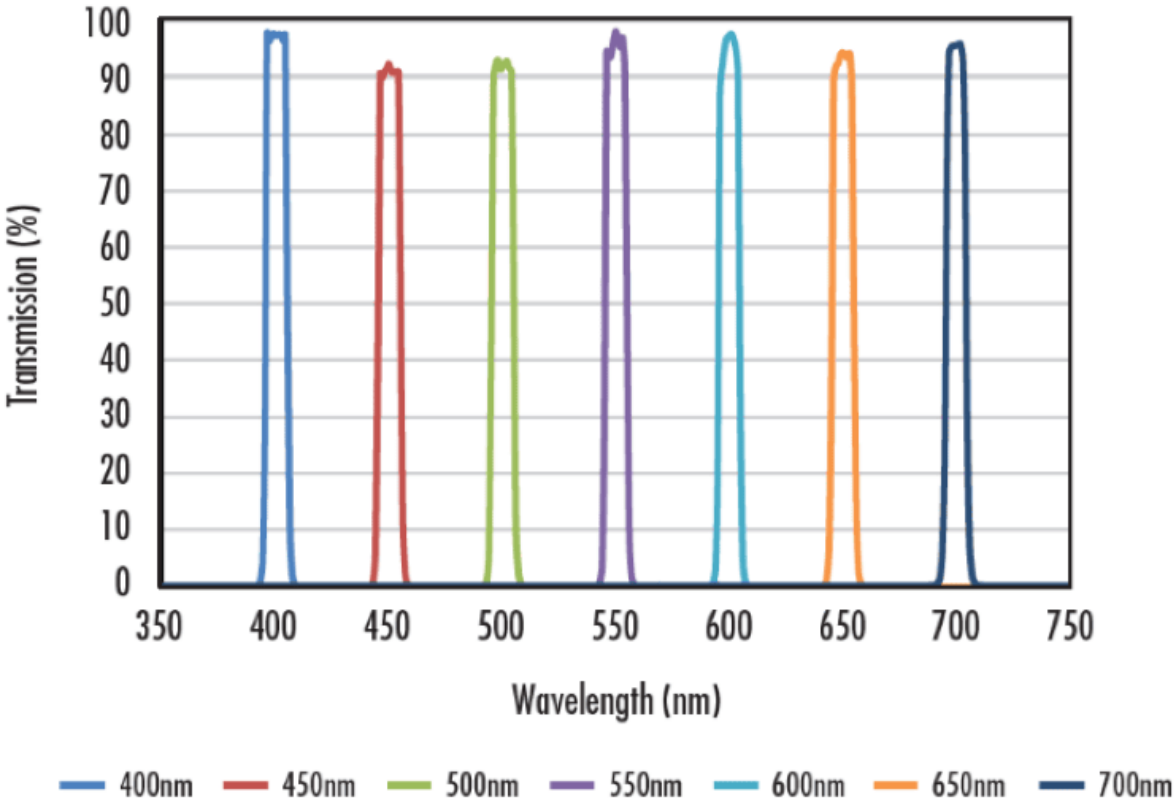

TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters IR

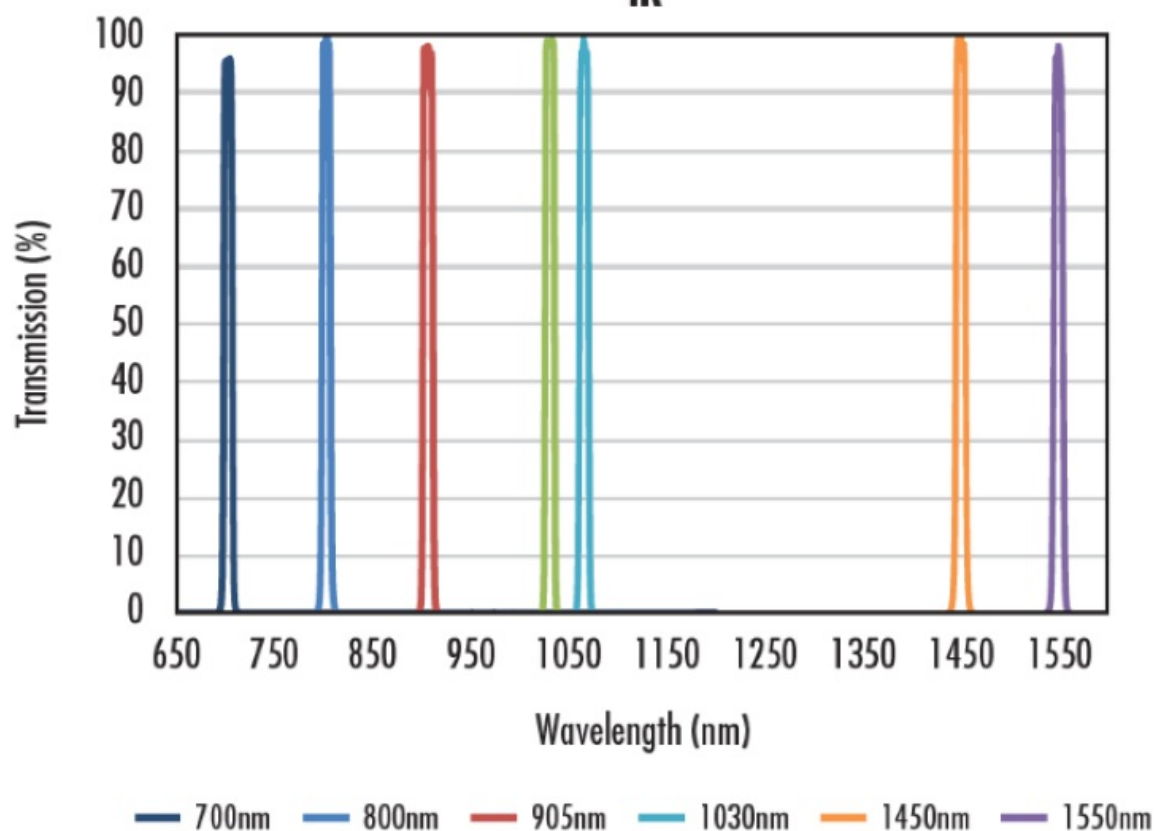

Products

Dia. (mm)	CWL (nm)	FWHM (nm)	Minimum Transmission (%)	Blocking Wavelength Range (nm)	Stock Number	Price	Buy
12.50	250.00	10.00	>50	200 - 650	#35-871	₹16,193 Volume Pricing	6 In Stock
25.00	250.00	10.00	>50	200 - 650	#35-878	₹24,367 Volume Pricing	3 In Stock
50.00	250.00	10.00	>50	200 - 650	#35-885	₹58,232 Volume Pricing	4 In Stock
12.50	254.00	10.00	≥50	200 - 650	#39-305	₹16,193 Volume Pricing	5 In Stock
25.00	254.00	10.00	≥50	200 - 650	#39-312	₹24,367 Volume Pricing	5 In Stock
50.00	254.00	10.00	≥50	200 - 650	#39-319	₹58,232 Volume Pricing	1 In Stock
12.50	260.00	10.00	>50	200 - 650	#35-872	₹16,193 Volume Pricing	5 In Stock
25.00	260.00	10.00	>50	200 - 650	#35-879	₹24,367 Volume Pricing	14 In Stock
12.50	266.00	10.00	≥50	200 - 650	#39-306	₹16,193 Volume Pricing	8 In Stock
25.00	266.00	10.00	≥50	200 - 650	#39-313	₹24,367 Volume Pricing	8 In Stock
50.00	266.00	10.00	≥50	200 - 650	#39-320	₹58,232 Volume Pricing	Contact Us
12.50	270.00	10.00	>60	200 - 650	#35-873	₹16,193 Volume Pricing	20+ In Stock
25.00	270.00	10.00	>60	200 - 650	#35-880	₹24,367 Volume Pricing	1 In Stock
50.00	270.00	10.00	>60	200 - 650	#35-887	₹58,232 Volume Pricing	1 In Stock
12.50	280.00	10.00	>60	200 - 650	#35-874	₹16,193 Volume Pricing	14 In Stock
25.00	280.00	10.00	>60	200 - 650	#35-881	₹24,367 Volume Pricing	14 In Stock
50.00	280.00	10.00	>60	200 - 650	#35-888	₹58,232 Volume Pricing	1 In Stock

12.50	285.00	10.00	>65	200 - 650	#35-875	₹16,193 Volume Pricing	3 In Stock
25.00	285.00	10.00	>65	200 - 650	#35-882	₹24,367 Volume Pricing	20+ In Stock
50.00	285.00	10.00	>65	200 - 650	#35-889	₹58,232 Volume Pricing	1 In Stock
12.50	290.00	10.00	>70	200 - 700	#35-876	₹16,193 Volume Pricing	5 In Stock
25.00	290.00	10.00	>70	200 - 700	#35-883	₹24,367 Volume Pricing	8 In Stock
50.00	290.00	10.00	>70	200 - 700	#35-890	₹58,232 Volume Pricing	5 In Stock
12.50	300.00	10.00	>65	200 - 700	#35-877	₹16,193 Volume Pricing	3 In Stock
25.00	300.00	10.00	>65	200 - 700	#35-884	₹24,367 Volume Pricing	14 In Stock
50.00	300.00	10.00	>65	200 - 700	#35-891	₹58,232 Volume Pricing	1 In Stock
12.50	310.00	10.00	≥70	200 - 1200	#34-972	₹14,714 Volume Pricing	11 In Stock
25.00	310.00	10.00	≥70	200 - 1200	#34-976	₹21,331 Volume Pricing	1 In Stock
50.00	310.00	10.00	≥70	200 - 1200	#34-980	₹50,603 Volume Pricing	5 In Stock
12.50	313.00	10.00	≥75	200 - 1200	#34-973	₹14,714 Volume Pricing	2 In Stock
25.00	313.00	10.00	≥75	200 - 1200	#34-977	₹21,331 Volume Pricing	20+ In Stock
50.00	313.00	10.00	≥75	200 - 1200	#34-981	₹50,603 Volume Pricing	5 In Stock
12.50	320.00	10.00	≥75	200 - 1200	#34-974	₹14,714 Volume Pricing	20+ In Stock
25.00	320.00	10.00	≥75	200 - 1200	#34-978	₹21,331 Volume Pricing	5 In Stock
50.00	320.00	10.00	≥75	200 - 1200	#34-982	₹50,603 Volume Pricing	1 In Stock
12.50	330.00	10.00	≥75	200 - 1200	#34-975	₹14,714 Volume Pricing	3 In Stock
25.00	330.00	10.00	≥75	200 - 1200	#34-979	₹21,331 Volume Pricing	2 In Stock

50.00	330.00	10.00	≥75	200 - 1200	#34-983	₹50,603 Volume Pricing	11 In Stock
12.50	337.00	10.00	≥85	200 - 1200	#65-067	₹14,714 Volume Pricing	10 In Stock
25.00	337.00	10.00	≥85	200 - 1200	#65-128	₹21,331 Volume Pricing	5 In Stock
50.00	337.00	10.00	≥85	200 - 1200	#65-189	₹50,603 Volume Pricing	1 In Stock
12.50	340.00	10.00	≥85	200 - 1200	#65-068	₹14,714 Volume Pricing	20+ In Stock
25.00	340.00	10.00	≥85	200 - 1200	#65-129	₹21,331 Volume Pricing	3 In Stock
50.00	340.00	10.00	≥85	200 - 1200	#65-190	₹50,603 Volume Pricing	1 In Stock
12.50	343.00	10.00	≥85	200 - 1200	#39-307	₹14,714 Volume Pricing	14 In Stock
25.00	343.00	10.00	≥85	200 - 1200	#39-314	₹21,331 Volume Pricing	2 In Stock
50.00	343.00	10.00	≥85	200 - 1200	#39-321	₹50,603 Volume Pricing	1 In Stock
12.50	350.00	10.00	>50	200 - 1200	#39-183	₹14,714 Volume Pricing	5 In Stock
25.00	350.00	10.00	>50	200 - 1200	#39-184	₹21,331 Volume Pricing	2 In Stock
50.00	350.00	10.00	>50	200 - 1200	#39-185	₹50,603 Volume Pricing	3 In Stock
12.50	355.00	10.00	≥85	200 - 1200	#34-490	₹14,714 Volume Pricing	1 In Stock
25.00	355.00	10.00	≥85	200 - 1200	#34-491	₹21,331 Volume Pricing	4 In Stock
50.00	355.00	10.00	≥85	200 - 1200	#34-492	₹50,603 Volume Pricing	8 In Stock
12.50	365.00	10.00	≥85	200 - 1200	#65-069	₹14,714 Volume Pricing	5 In Stock
25.00	365.00	10.00	≥85	200 - 1200	#65-130	₹21,331 Volume Pricing	6 In Stock
50.00	365.00	10.00	≥85	200 - 1200	#65-191	₹50,603 Volume Pricing	3 In Stock
12.50	372.00	10.00	≥85	200 - 1200	#12-147	₹14,714 Volume Pricing	20+ In Stock

25.00	372.00	10.00	≥85	200 - 1200	#12-151	₹21,331 Volume Pricing	20+ In Stock
50.00	372.00	10.00	≥85	200 - 1200	#12-155	₹50,603 Volume Pricing	1 In Stock
12.50	375.00	10.00	≥85	200 - 1200	#86-732	₹14,714 Volume Pricing	10 In Stock
25.00	375.00	10.00	≥85	200 - 1200	#86-736	₹21,331 Volume Pricing	2 In Stock
50.00	375.00	10.00	≥85	200 - 1200	#86-740	₹50,603 Volume Pricing	1 In Stock
12.50	394.00	10.00	≥85	200 - 1200	#65-070	₹14,714 Volume Pricing	20+ In Stock
25.00	394.00	10.00	≥85	200 - 1200	#65-131	₹21,331 Volume Pricing	3 In Stock
50.00	394.00	10.00	≥85	200 - 1200	#65-192	₹50,603 Volume Pricing	6 In Stock
12.50	400.00	10.00	≥85	200 - 1200	#65-071	₹13,390 Volume Pricing	5 In Stock
25.00	400.00	10.00	≥85	200 - 1200	#65-132	₹20,007 Volume Pricing	2 In Stock
50.00	400.00	10.00	≥85	200 - 1200	#65-193	₹48,423 Volume Pricing	5 In Stock
12.50	405.00	10.00	≥85	200 - 1200	#65-072	₹13,390 Volume Pricing	20+ In Stock
25.00	405.00	10.00	≥85	200 - 1200	#65-133	₹20,007 Volume Pricing	20+ In Stock
50.00	405.00	10.00	≥85	200 - 1200	#65-194	₹48,423 Volume Pricing	6 In Stock
12.50	413.00	10.00	≥85	200 - 1200	#34-493	₹13,390 Volume Pricing	10 In Stock
25.00	413.00	10.00	≥85	200 - 1200	#34-494	₹20,007 Volume Pricing	20+ In Stock
50.00	413.00	10.00	≥85	200 - 1200	#34-495	₹48,423 Volume Pricing	8 In Stock
12.50	420.00	10.00	≥85	200 - 1200	#65-075	₹13,390 Volume Pricing	4 In Stock
25.00	420.00	10.00	≥85	200 - 1200	#65-136	₹20,007 Volume Pricing	20+ In Stock
50.00	420.00	10.00	≥85	200 - 1200	#65-197	₹48,423 Volume Pricing	12 In Stock

12.50	422.00	10.00	≥85	200 - 1200	#34-496	₹13,390 Volume Pricing	5 In Stock
25.00	422.00	10.00	≥85	200 - 1200	#34-497	₹20,007 Volume Pricing	5 In Stock
50.00	422.00	10.00	≥85	200 - 1200	#34-498	₹48,423 Volume Pricing	10 In Stock
12.50	430.00	10.00	≥85	200 - 1200	#65-076	₹13,390 Volume Pricing	10 In Stock
25.00	430.00	10.00	≥85	200 - 1200	#65-137	₹20,007 Volume Pricing	4 In Stock
50.00	430.00	10.00	≥85	200 - 1200	#65-198	₹48,423 Volume Pricing	1 In Stock
12.50	436.00	10.00	≥85	200 - 1200	#65-077	₹13,390 Volume Pricing	12 In Stock
25.00	436.00	10.00	≥85	200 - 1200	#65-138	₹20,007 Volume Pricing	2 In Stock
50.00	436.00	10.00	≥85	200 - 1200	#65-199	₹48,423 Volume Pricing	7 In Stock
12.50	440.00	10.00	>85	200 - 1200	#88-567	₹13,390 Volume Pricing	3 In Stock
25.00	440.00	10.00	>85	200 - 1200	#88-570	₹20,007 Volume Pricing	16 In Stock
50.00	440.00	10.00	>85	200 - 1200	#88-573	₹48,423 Volume Pricing	1 In Stock
12.50	442.00	10.00	≥85	200 - 1200	#65-078	₹13,390 Volume Pricing	2 In Stock
25.00	442.00	10.00	≥85	200 - 1200	#65-139	₹20,007 Volume Pricing	3 In Stock
50.00	442.00	10.00	≥85	200 - 1200	#65-200	₹48,423 Volume Pricing	1 In Stock
12.50	445.00	10.00	≥85	200 - 1200	#34-499	₹13,390 Volume Pricing	3 In Stock
25.00	445.00	10.00	≥85	200 - 1200	#34-500	₹20,007 Volume Pricing	2 In Stock
50.00	445.00	10.00	≥85	200 - 1200	#34-501	₹48,423 Volume Pricing	1 In Stock
12.50	450.00	10.00	≥85	200 - 1200	#65-079	₹13,390 Volume Pricing	20+ In Stock
25.00	450.00	10.00	≥85	200 - 1200	#65-140	₹20,007 Volume Pricing	6 In Stock

50.00	450.00	10.00	≥85	200 - 1200	#65-201	₹48,423 Volume Pricing	6 In Stock
12.50	455.00	10.00	≥85	200 - 1200	#65-080	₹13,390 Volume Pricing	20+ In Stock
25.00	455.00	10.00	≥85	200 - 1200	#65-141	₹20,007 Volume Pricing	20+ In Stock
50.00	455.00	10.00	≥85	200 - 1200	#65-202	₹48,423 Volume Pricing	3 In Stock
12.50	458.00	10.00	≥85	200 - 1200	#65-081	₹13,390 Volume Pricing	16 In Stock
25.00	458.00	10.00	≥85	200 - 1200	#65-142	₹20,007 Volume Pricing	1 In Stock
50.00	458.00	10.00	≥85	200 - 1200	#65-203	₹48,423 Volume Pricing	3 In Stock
12.50	460.00	10.00	>85	200 - 1200	#87-886	₹13,390 Volume Pricing	3 In Stock
25.00	460.00	10.00	>85	200 - 1200	#88-010	₹20,007 Volume Pricing	14 In Stock
50.00	460.00	10.00	>85	200 - 1200	#88-016	₹48,423 Volume Pricing	9 In Stock
12.50	467.00	10.00	≥85	200 - 1200	#39-308	₹13,390 Volume Pricing	4 In Stock
25.00	467.00	10.00	≥85	200 - 1200	#39-315	₹20,007 Volume Pricing	20+ In Stock
50.00	467.00	10.00	≥85	200 - 1200	#39-322	₹48,423 Volume Pricing	2 In Stock
12.50	470.00	10.00	≥85	200 - 1200	#65-083	₹13,390 Volume Pricing	20+ In Stock
25.00	470.00	10.00	≥85	200 - 1200	#65-144	₹20,007 Volume Pricing	20+ In Stock
50.00	470.00	10.00	≥85	200 - 1200	#65-205	₹48,423 Volume Pricing	1 In Stock
12.50	473.00	10.00	≥85	200 - 1200	#34-502	₹13,390 Volume Pricing	2 In Stock
25.00	473.00	10.00	≥85	200 - 1200	#34-503	₹20,007 Volume Pricing	5 In Stock
50.00	473.00	10.00	≥85	200 - 1200	#34-504	₹48,423 Volume Pricing	11 In Stock
12.50	480.00	10.00	≥85	200 - 1200	#65-084	₹13,390 Volume Pricing	20+ In Stock

25.00	480.00	10.00	≥85	200 - 1200	#65-145	₹20,007 Volume Pricing	20+ In Stock
50.00	480.00	10.00	≥85	200 - 1200	#65-206	₹48,423 Volume Pricing	1 In Stock
12.50	486.00	10.00	≥85	200 - 1200	#65-085	₹13,390 Volume Pricing	3 In Stock
25.00	486.00	10.00	≥85	200 - 1200	#65-146	₹20,007 Volume Pricing	13 In Stock
50.00	486.00	10.00	≥85	200 - 1200	#65-207	₹48,423 Volume Pricing	5 In Stock
12.50	488.00	10.00	≥85	200 - 1200	#65-086	₹13,390 Volume Pricing	1 In Stock
25.00	488.00	10.00	≥85	200 - 1200	#65-147	₹20,007 Volume Pricing	6 In Stock
50.00	488.00	10.00	≥85	200 - 1200	#65-208	₹48,423 Volume Pricing	5 In Stock
12.50	492.00	10.00	≥85	200 - 1200	#65-087	₹13,390 Volume Pricing	9 In Stock
25.00	492.00	10.00	≥85	200 - 1200	#65-148	₹20,007 Volume Pricing	2 In Stock
50.00	492.00	10.00	≥85	200 - 1200	#65-209	₹48,423 Volume Pricing	6 In Stock
12.50	500.00	10.00	≥85	200 - 1200	#65-088	₹13,390 Volume Pricing	20+ In Stock
25.00	500.00	10.00	≥85	200 - 1200	#65-149	₹20,007 Volume Pricing	20+ In Stock
50.00	500.00	10.00	≥85	200 - 1200	#65-210	₹48,423 Volume Pricing	3 In Stock
12.50	505.00	10.00	≥85	200 - 1200	#34-505	₹13,390 Volume Pricing	7 In Stock
25.00	505.00	10.00	≥85	200 - 1200	#34-506	₹20,007 Volume Pricing	3 In Stock
50.00	505.00	10.00	≥85	200 - 1200	#34-507	₹48,423 Volume Pricing	5 In Stock
12.50	508.00	10.00	≥85	200 - 1200	#65-090	₹13,390 Volume Pricing	20+ In Stock
25.00	508.00	10.00	≥85	200 - 1200	#65-151	₹20,007 Volume Pricing	1 In Stock
12.50	510.00	10.00	≥85	200 - 1200	#65-091	₹13,390 Volume Pricing	20+ In Stock

25.00	510.00	10.00	≥85	200 - 1200	#65-152	₹20,007 Volume Pricing	1 In Stock
50.00	510.00	10.00	≥85	200 - 1200	#65-213	₹48,423 Volume Pricing	1 In Stock
12.50	515.00	10.00	≥85	200 - 1200	#65-092	₹13,390 Volume Pricing	2 In Stock
25.00	515.00	10.00	≥85	200 - 1200	#65-153	₹20,007 Volume Pricing	5 In Stock
50.00	515.00	10.00	≥85	200 - 1200	#65-214	₹48,423 Volume Pricing	Contact Us
12.50	520.00	10.00	≥85	200 - 1200	#65-093	₹13,390 Volume Pricing	20+ In Stock
25.00	520.00	10.00	≥85	200 - 1200	#65-154	₹20,007 Volume Pricing	5 In Stock
50.00	520.00	10.00	≥85	200 - 1200	#65-215	₹48,423 Volume Pricing	4 In Stock
12.50	532.00	10.00	≥85	200 - 1200	#65-094	₹13,390 Volume Pricing	20+ In Stock
25.00	532.00	10.00	≥85	200 - 1200	#65-155	₹20,007 Volume Pricing	1 In Stock
50.00	532.00	10.00	≥85	200 - 1200	#65-216	₹48,423 Volume Pricing	6 In Stock
12.50	535.00	10.00	≥85	200 - 1200	#65-095	₹13,390 Volume Pricing	3 In Stock
25.00	535.00	10.00	≥85	200 - 1200	#65-156	₹20,007 Volume Pricing	8 In Stock
50.00	535.00	10.00	≥85	200 - 1200	#65-217	₹48,423 Volume Pricing	3 In Stock
12.50	540.00	10.00	≥85	200 - 1200	#65-096	₹13,390 Volume Pricing	20+ In Stock
25.00	540.00	10.00	≥85	200 - 1200	#65-157	₹20,007 Volume Pricing	20+ In Stock
50.00	540.00	10.00	≥85	200 - 1200	#65-218	₹48,423 Volume Pricing	8 In Stock
12.50	546.00	10.00	≥85	200 - 1200	#65-097	₹13,390 Volume Pricing	8 In Stock
25.00	546.00	10.00	≥85	200 - 1200	#65-158	₹20,007 Volume Pricing	16 In Stock
50.00	546.00	10.00	≥85	200 - 1200	#65-219	₹48,423 Volume Pricing	5 In Stock

12.50	550.00	10.00	≥85	200 - 1200	#65-098	₹13,390 Volume Pricing	Contact Us
25.00	550.00	10.00	≥85	200 - 1200	#65-159	₹20,007 Volume Pricing	20+ In Stock
50.00	550.00	10.00	≥85	200 - 1200	#65-220	₹48,423 Volume Pricing	4 In Stock
12.50	560.00	10.00	>85	200 - 1200	#87-887	₹13,390 Volume Pricing	20+ In Stock
25.00	560.00	10.00	>85	200 - 1200	#88-011	₹20,007 Volume Pricing	Contact Us
50.00	560.00	10.00	>85	200 - 1200	#88-017	₹48,423 Volume Pricing	2 In Stock
12.50	561.00	10.00	≥85	200 - 1200	#12-148	₹13,390 Volume Pricing	20+ In Stock
25.00	561.00	10.00	≥85	200 - 1200	#12-152	₹20,007 Volume Pricing	3 In Stock
50.00	561.00	10.00	≥85	200 - 1200	#12-156	₹48,423 Volume Pricing	2 In Stock
12.50	568.00	10.00	≥85	200 - 1200	#65-099	₹13,390 Volume Pricing	20+ In Stock
25.00	568.00	10.00	≥85	200 - 1200	#65-160	₹20,007 Volume Pricing	11 In Stock
50.00	568.00	10.00	≥85	200 - 1200	#65-221	₹48,423 Volume Pricing	10 In Stock
12.50	580.00	10.00	≥85	200 - 1200	#65-100	₹13,390 Volume Pricing	17 In Stock
25.00	580.00	10.00	≥85	200 - 1200	#65-161	₹20,007 Volume Pricing	3 In Stock
50.00	580.00	10.00	≥85	200 - 1200	#65-222	₹48,423 Volume Pricing	Contact Us
12.50	589.00	10.00	≥85	200 - 1200	#65-101	₹13,390 Volume Pricing	20+ In Stock
25.00	589.00	10.00	≥85	200 - 1200	#65-162	₹20,007 Volume Pricing	Contact Us
50.00	589.00	10.00	≥85	200 - 1200	#65-223	₹48,423 Volume Pricing	2 In Stock
12.50	594.00	10.00	≥85	200 - 1200	#86-733	₹13,390 Volume Pricing	Contact Us
25.00	594.00	10.00	≥85	200 - 1200	#86-737	₹20,007 Volume Pricing	2 In Stock

50.00	594.00	10.00	≥85	200 - 1200	#86-741	₹48,423 Volume Pricing	1 In Stock
12.50	600.00	10.00	≥85	200 - 1200	#65-102	₹13,390 Volume Pricing	20+ In Stock
25.00	600.00	10.00	≥85	200 - 1200	#65-163	₹20,007 Volume Pricing	20+ In Stock
50.00	600.00	10.00	≥85	200 - 1200	#65-224	₹48,423 Volume Pricing	1 In Stock
12.50	610.00	10.00	≥85	200 - 1200	#65-103	₹13,390 Volume Pricing	15 In Stock
25.00	610.00	10.00	≥85	200 - 1200	#65-164	₹20,007 Volume Pricing	4 In Stock
50.00	610.00	10.00	≥85	200 - 1200	#65-225	₹48,423 Volume Pricing	4 In Stock
12.50	620.00	10.00	≥85	200 - 1200	#65-104	₹13,390 Volume Pricing	20+ In Stock
25.00	620.00	10.00	≥85	200 - 1200	#65-165	₹20,007 Volume Pricing	10 In Stock
50.00	620.00	10.00	≥85	200 - 1200	#65-226	₹48,423 Volume Pricing	15 In Stock
12.50	632.00	10.00	≥85	200 - 1200	#65-105	₹13,390 Volume Pricing	3 In Stock
25.00	632.00	10.00	≥85	200 - 1200	#65-166	₹20,007 Volume Pricing	8 In Stock
50.00	632.00	10.00	≥85	200 - 1200	#65-227	₹48,423 Volume Pricing	Contact Us
12.50	636.00	10.00	≥85	200 - 1200	#65-106	₹13,390 Volume Pricing	4 In Stock
25.00	636.00	10.00	≥85	200 - 1200	#65-167	₹20,007 Volume Pricing	2 In Stock
50.00	636.00	10.00	≥85	200 - 1200	#65-228	₹48,423 Volume Pricing	3 In Stock
12.50	640.00	10.00	≥85	200 - 1200	#65-107	₹13,390 Volume Pricing	20+ In Stock
25.00	640.00	10.00	≥85	200 - 1200	#65-168	₹20,007 Volume Pricing	20+ In Stock
50.00	640.00	10.00	≥85	200 - 1200	#65-229	₹48,423 Volume Pricing	8 In Stock
12.50	647.00	10.00	≥85	200 - 1200	#65-108	₹13,390 Volume Pricing	9 In Stock

25.00	647.00	10.00	≥85	200 - 1200	#65-169	₹20,007 Volume Pricing	10 In Stock
50.00	647.00	10.00	≥85	200 - 1200	#65-230	₹48,423 Volume Pricing	1 In Stock
12.50	650.00	10.00	≥85	200 - 1200	#65-109	₹13,390 Volume Pricing	4 In Stock
25.00	650.00	10.00	≥85	200 - 1200	#65-170	₹20,007 Volume Pricing	20+ In Stock
50.00	650.00	10.00	≥85	200 - 1200	#65-231	₹48,423 Volume Pricing	4 In Stock
12.50	656.00	10.00	≥85	200 - 1200	#65-110	₹13,390 Volume Pricing	20+ In Stock
25.00	656.00	10.00	≥85	200 - 1200	#65-171	₹20,007 Volume Pricing	4 In Stock
50.00	656.00	10.00	≥85	200 - 1200	#65-232	₹48,423 Volume Pricing	3 In Stock
12.50	660.00	10.00	≥85	200 - 1200	#86-086	₹13,390 Volume Pricing	16 In Stock
25.00	660.00	10.00	≥85	200 - 1200	#86-089	₹20,007 Volume Pricing	20+ In Stock
50.00	660.00	10.00	≥85	200 - 1200	#86-092	₹48,423 Volume Pricing	6 In Stock
12.50	671.00	10.00	≥85	200 - 1200	#65-111	₹13,390 Volume Pricing	8 In Stock
25.00	671.00	10.00	≥85	200 - 1200	#65-172	₹20,007 Volume Pricing	6 In Stock
50.00	671.00	10.00	≥85	200 - 1200	#65-233	₹48,423 Volume Pricing	3 In Stock
12.50	676.00	10.00	≥85	200 - 1200	#65-112	₹13,390 Volume Pricing	11 In Stock
25.00	676.00	10.00	≥85	200 - 1200	#65-173	₹20,007 Volume Pricing	5 In Stock
50.00	676.00	10.00	≥85	200 - 1200	#65-234	₹48,423 Volume Pricing	Contact Us
12.50	680.00	10.00	>85	200 - 1200	#88-568	₹13,390 Volume Pricing	2 In Stock
25.00	680.00	10.00	>85	200 - 1200	#88-571	₹20,007 Volume Pricing	2 In Stock
50.00	680.00	10.00	>85	200 - 1200	#88-574	₹48,423 Volume Pricing	1 In Stock

12.50	685.00	10.00	≥85	200 - 1200	#86-734	₹13,390 Volume Pricing	9 In Stock
25.00	685.00	10.00	≥85	200 - 1200	#86-738	₹20,007 Volume Pricing	15 In Stock
50.00	685.00	10.00	≥85	200 - 1200	#86-742	₹48,423 Volume Pricing	5 In Stock
12.50	690.00	10.00	≥85	200 - 1200	#65-113	₹13,390 Volume Pricing	2 In Stock
25.00	690.00	10.00	≥85	200 - 1200	#65-174	₹20,007 Volume Pricing	20+ In Stock
50.00	690.00	10.00	≥85	200 - 1200	#65-235	₹48,423 Volume Pricing	5 In Stock
12.50	694.00	10.00	≥85	200 - 1200	#65-114	₹13,390 Volume Pricing	14 In Stock
25.00	694.00	10.00	≥85	200 - 1200	#65-175	₹20,007 Volume Pricing	4 In Stock
50.00	694.00	10.00	≥85	200 - 1200	#65-236	₹48,423 Volume Pricing	3 In Stock
12.50	700.00	10.00	>85	200 - 1200	#87-888	₹14,714 Volume Pricing	20+ In Stock
25.00	700.00	10.00	>85	200 - 1200	#88-012	₹21,331 Volume Pricing	20+ In Stock
50.00	700.00	10.00	>85	200 - 1200	#88-018	₹50,603 Volume Pricing	7 In Stock
12.50	730.00	10.00	≥85	200 - 1200	#65-115	₹14,714 Volume Pricing	20+ In Stock
25.00	730.00	10.00	≥85	200 - 1200	#65-176	₹21,331 Volume Pricing	4 In Stock
50.00	730.00	10.00	≥85	200 - 1200	#65-237	₹50,603 Volume Pricing	1 In Stock
12.50	750.00	10.00	>85	200 - 1200	#87-889	₹14,714 Volume Pricing	20+ In Stock
25.00	750.00	10.00	>85	200 - 1200	#88-013	₹21,331 Volume Pricing	Contact Us
50.00	750.00	10.00	>85	200 - 1200	#88-019	₹50,603 Volume Pricing	5 In Stock
12.50	752.00	10.00	≥85	200 - 1200	#12-149	₹14,714 Volume Pricing	6 In Stock
25.00	752.00	10.00	≥85	200 - 1200	#12-153	₹21,331 Volume Pricing	16 In Stock

50.00	752.00	10.00	≥85	200 - 1200	#12-157	₹50,603 Volume Pricing	2 In Stock
12.50	766.00	10.00	≥85	200 - 1200	#65-116	₹14,714 Volume Pricing	Contact Us
25.00	766.00	10.00	≥85	200 - 1200	#65-177	₹21,331 Volume Pricing	20+ In Stock
50.00	766.00	10.00	≥85	200 - 1200	#65-238	₹50,603 Volume Pricing	1 In Stock
12.50	770.00	10.00	>85	200 - 1200	#87-890	₹14,714 Volume Pricing	1 In Stock
25.00	770.00	10.00	>85	200 - 1200	#88-014	₹21,331 Volume Pricing	Contact Us
50.00	770.00	10.00	>85	200 - 1200	#88-020	₹50,603 Volume Pricing	3 In Stock
12.50	780.00	10.00	≥85	200 - 1200	#65-117	₹14,714 Volume Pricing	4 In Stock
25.00	780.00	10.00	≥85	200 - 1200	#65-178	₹21,331 Volume Pricing	20+ In Stock
50.00	780.00	10.00	≥85	200 - 1200	#65-239	₹50,603 Volume Pricing	11 In Stock
12.50	785.00	10.00	≥85	200 - 1200	#86-735	₹14,714 Volume Pricing	20+ In Stock
25.00	785.00	10.00	≥85	200 - 1200	#86-739	₹21,331 Volume Pricing	5 In Stock
50.00	785.00	10.00	≥85	200 - 1200	#86-743	₹50,603 Volume Pricing	1 In Stock
12.50	800.00	10.00	≥85	200 - 1200	#65-118	₹14,714 Volume Pricing	3 In Stock
25.00	800.00	10.00	≥85	200 - 1200	#65-179	₹21,331 Volume Pricing	4 In Stock
50.00	800.00	10.00	≥85	200 - 1200	#65-240	₹50,603 Volume Pricing	Contact Us
12.50	808.00	10.00	≥85	200 - 1200	#39-309	₹14,714 Volume Pricing	20+ In Stock
25.00	808.00	10.00	≥85	200 - 1200	#39-316	₹21,331 Volume Pricing	20+ In Stock
50.00	808.00	10.00	≥85	200 - 1200	#39-323	₹50,603 Volume Pricing	13 In Stock
12.50	810.00	10.00	>85	200 - 1200	#87-891	₹14,714 Volume Pricing	Contact Us

25.00	810.00	10.00	>85	200 - 1200	#88-015	₹21,331 Volume Pricing	20+ In Stock
50.00	810.00	10.00	>85	200 - 1200	#88-021	₹50,603 Volume Pricing	Contact Us
12.50	830.00	10.00	≥85	200 - 1200	#65-119	₹14,714 Volume Pricing	20+ In Stock
25.00	830.00	10.00	≥85	200 - 1200	#65-180	₹21,331 Volume Pricing	4 In Stock
50.00	830.00	10.00	≥85	200 - 1200	#65-241	₹50,603 Volume Pricing	9 In Stock
12.50	850.00	10.00	≥85	200 - 1200	#86-087	₹14,714 Volume Pricing	20+ In Stock
25.00	850.00	10.00	≥85	200 - 1200	#86-090	₹21,331 Volume Pricing	20+ In Stock
50.00	850.00	10.00	≥85	200 - 1200	#86-093	₹50,603 Volume Pricing	5 In Stock
12.50	852.00	10.00	≥85	200 - 1200	#65-120	₹14,714 Volume Pricing	20+ In Stock
25.00	852.00	10.00	≥85	200 - 1200	#65-181	₹21,331 Volume Pricing	14 In Stock
50.00	852.00	10.00	≥85	200 - 1200	#65-242	₹50,603 Volume Pricing	5 In Stock
12.50	880.00	10.00	≥85	200 - 1200	#65-122	₹14,714 Volume Pricing	Contact Us
25.00	880.00	10.00	≥85	200 - 1200	#65-183	₹21,331 Volume Pricing	20+ In Stock
50.00	880.00	10.00	≥85	200 - 1200	#65-244	₹50,603 Volume Pricing	1 In Stock
12.50	905.00	10.00	≥85	200 - 1200	#65-123	₹14,714 Volume Pricing	20+ In Stock
25.00	905.00	10.00	≥85	200 - 1200	#65-184	₹21,331 Volume Pricing	20+ In Stock
50.00	905.00	10.00	≥85	200 - 1200	#65-245	₹50,603 Volume Pricing	4 In Stock
12.50	940.00	10.00	≥85	200 - 1200	#65-124	₹14,714 Volume Pricing	20+ In Stock
25.00	940.00	10.00	≥85	200 - 1200	#65-185	₹21,331 Volume Pricing	Contact Us
50.00	940.00	10.00	≥85	200 - 1200	#65-246	₹50,603 Volume Pricing	11 In Stock

12.50	950.00	10.00	>85	200 - 1200	#88-569	₹14,714 Volume Pricing	3 In Stock
25.00	950.00	10.00	>85	200 - 1200	#88-572	₹21,331 Volume Pricing	14 In Stock
50.00	950.00	10.00	>85	200 - 1200	#88-575	₹50,603 Volume Pricing	1 In Stock
12.50	980.00	10.00	≥85	200 - 1200	#65-125	₹14,714 Volume Pricing	20+ In Stock
25.00	980.00	10.00	≥85	200 - 1200	#65-186	₹21,331 Volume Pricing	17 In Stock
50.00	980.00	10.00	≥85	200 - 1200	#65-247	₹50,603 Volume Pricing	1 In Stock
12.50	1,030.00	10.00	≥85	200 - 1200	#39-310	₹14,714 Volume Pricing	3 In Stock
25.00	1,030.00	10.00	≥85	200 - 1200	#39-317	₹21,331 Volume Pricing	5 In Stock
50.00	1,030.00	10.00	≥85	200 - 1200	#39-324	₹50,603 Volume Pricing	20+ In Stock
12.50	1,064.00	10.00	≥85	200 - 1200	#65-126	₹14,714 Volume Pricing	4 In Stock
25.00	1,064.00	10.00	≥85	200 - 1200	#65-187	₹21,331 Volume Pricing	Contact Us
50.00	1,064.00	10.00	≥85	200 - 1200	#65-248	₹50,603 Volume Pricing	2 In Stock
12.50	1,450.00	10.00	≥85	400 - 1800	#39-311	₹17,361 Volume Pricing	1 In Stock
25.00	1,450.00	10.00	≥85	400 - 1800	#39-318	₹26,002 Volume Pricing	2 In Stock
50.00	1,450.00	10.00	≥85	400 - 1800	#39-326	₹61,969 Volume Pricing	Contact Us
12.50	1,550.00	10.00	≥85	200 - 1800	#86-088	₹17,361 Volume Pricing	20+ In Stock
25.00	1,550.00	10.00	≥85	200 - 1800	#86-091	₹26,002 Volume Pricing	9 In Stock
				200 - 1800	#86-094	₹61,969 Volume Pricing	12 In Stock



Edmund
optics | worldwide

Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com