

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

# Traditional Coated 700 – 1650nm Bandpass Interference Filters



- Available in UV, Visible, and IR Center Wavelengths
- 10 – 80nm Bandwidths Available
- Ideal for Biomedical Applications and Instrumentation Integration
- [193-399nm](#), [400-699nm](#), and 700-1650nm CWL Options Available

## Common Specifications




### Physical & Mechanical Properties

|                           |      |               |                                |
|---------------------------|------|---------------|--------------------------------|
| Thickness Tolerance (mm): | ±0.1 | Construction: | Mounted in Black Anodized Ring |
|---------------------------|------|---------------|--------------------------------|

### Optical Properties

|                         |       |          |                    |
|-------------------------|-------|----------|--------------------|
| Angle of Incidence (°): | 0     | Coating: | Traditional Coated |
| Surface Quality:        | 80-50 |          |                    |

Technical Information

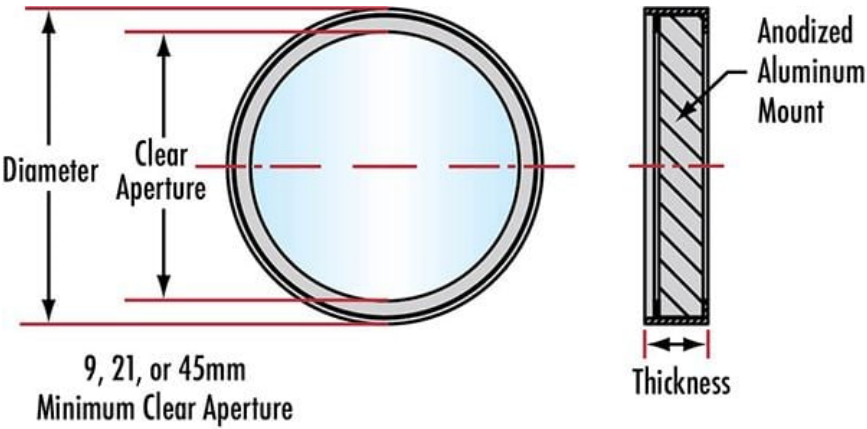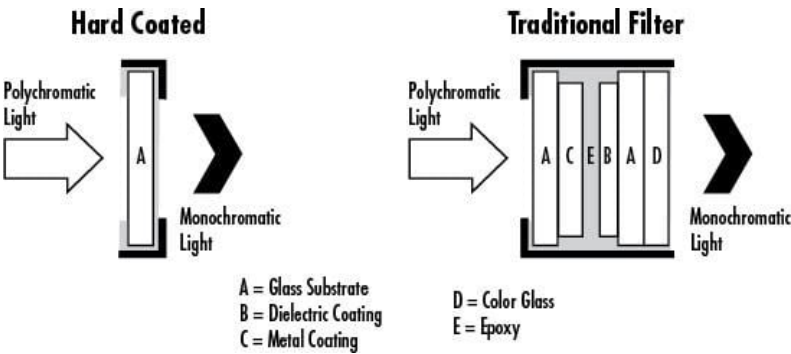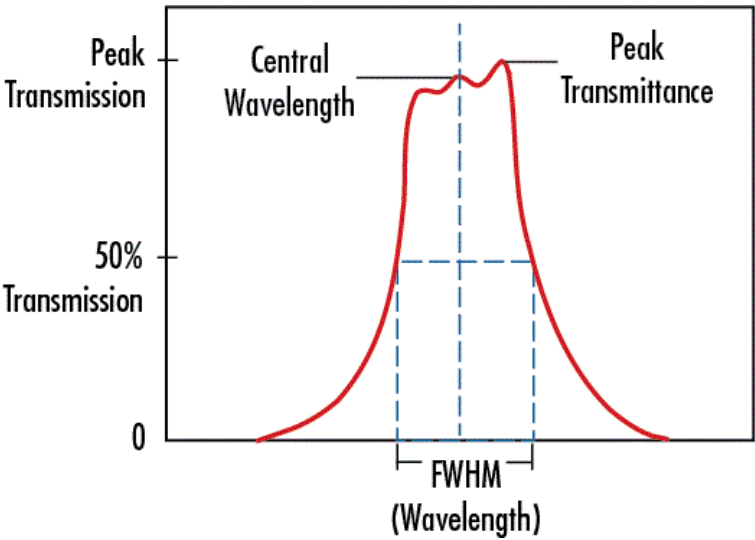

Products

| Dia.<br>(mm) | CWL<br>(nm) | FWHM<br>(nm) | Minimum<br>Transmission<br>(%) | Blocking<br>Wavelength<br>Range<br>(nm) | Dimensions<br>(mm) | Stock<br>Number         | Price                                     | Buy        |
|--------------|-------------|--------------|--------------------------------|-----------------------------------------|--------------------|-------------------------|-------------------------------------------|------------|
| 12.50        | 700.00      | 10.00        | >55                            | 200 - Far IR                            | -                  | <a href="#">#67-771</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00        | 700.00      | 10.00        | >55                            | 200 - Far IR                            | -                  | <a href="#">#67-838</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 50.00        | 700.00      | 10.00        | >55                            | 200 - Far IR                            | -                  | <a href="#">#67-905</a> | ₹36,122<br><a href="#">Volume Pricing</a> | 2 In Stock |
| 12.50        | 700.00      | 80.00        | ≥60                            | 200 - 1200                              | -                  | <a href="#">#65-738</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00        | 700.00      | 80.00        | ≥60                            | 200 - 1200                              | -                  | <a href="#">#65-747</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 50.00        | 700.00      | 80.00        | ≥60                            | 200 - 1200                              | -                  | <a href="#">#87-194</a> | ₹36,122<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 12.50        | 710.00      | 10.00        | >55                            | 200 - Far IR                            | -                  | <a href="#">#67-772</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 4 In Stock |
| 25.00        | 710.00      | 10.00        | >55                            | 200 - Far IR                            | -                  | <a href="#">#67-839</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 4 In Stock |
| 50.00        | 710.00      | 10.00        | >55                            | 200 - Far IR                            | -                  | <a href="#">#67-906</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 12.50        | 720.00      | 10.00        | >55                            | 200 - Far IR                            | -                  | <a href="#">#67-773</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 4 In Stock |
| 25.00        | 720.00      | 10.00        | >55                            | 200 - Far IR                            | -                  | <a href="#">#67-840</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 50.00        | 720.00      | 10.00        | >55                            | 200 - Far IR                            | -                  | <a href="#">#67-907</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 12.50        | 730.00      | 10.00        | ≥50                            | 200 - 1200                              | -                  | <a href="#">#65-661</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00        | 730.00      | 10.00        | ≥50                            | 200 - 1200                              | -                  | <a href="#">#65-721</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 12.50        | 740.00      | 10.00        | >55                            | 200 - Far IR                            | -                  | <a href="#">#67-774</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 4 In Stock |
| 25.00        | 740.00      | 10.00        | >55                            | 200 - Far IR                            | -                  | <a href="#">#67-841</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 2 In Stock |
| 50.00        | 740.00      | 10.00        | >55                            | 200 - Far IR                            | -                  | <a href="#">#67-908</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 12.50        | 750.00      | 10.00        | >50                            | 200 - Far IR                            | -                  | <a href="#">#67-775</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 1 In Stock |
| 25.00        | 750.00      | 10.00        | >50                            | 200 - Far IR                            | -                  | <a href="#">#67-842</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 4 In Stock |

|       |        |       |     |              |   |                         |                                           |              |
|-------|--------|-------|-----|--------------|---|-------------------------|-------------------------------------------|--------------|
| 50.00 | 750.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-909</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 750.00 | 40.00 | >40 | 200 - Far IR | - | <a href="#">#67-776</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 6 In Stock   |
| 25.00 | 750.00 | 40.00 | >40 | 200 - Far IR | - | <a href="#">#67-843</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.00 | 750.00 | 40.00 | >40 | 200 - Far IR | - | <a href="#">#67-910</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 12.50 | 760.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-777</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 6 In Stock   |
| 25.00 | 760.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-844</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 50.00 | 760.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-911</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 766.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-662</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 7 In Stock   |
| 25.00 | 766.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-722</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 12.50 | 770.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-778</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 2 In Stock   |
| 25.00 | 770.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-845</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 50.00 | 770.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-912</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 780.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-663</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| 25.00 | 780.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-723</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 50.00 | 780.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#86-637</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 790.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-779</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| 25.00 | 790.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-846</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 50.00 | 790.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-913</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 795.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-780</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| 25.00 | 795.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-847</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 50.00 | 795.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-914</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 12.50 | 800.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-664</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 3 In Stock   |

|       |        |       |     |              |   |                         |                                           |            |
|-------|--------|-------|-----|--------------|---|-------------------------|-------------------------------------------|------------|
| 25.00 | 800.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-724</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 6 In Stock |
| 12.50 | 800.00 | 40.00 | >50 | 200 - Far IR | - | <a href="#">#67-781</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 2 In Stock |
| 25.00 | 800.00 | 40.00 | >50 | 200 - Far IR | - | <a href="#">#67-848</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 50.00 | 800.00 | 40.00 | >50 | 200 - Far IR | - | <a href="#">#67-915</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 2 In Stock |
| 12.50 | 810.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-782</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00 | 810.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-849</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 4 In Stock |
| 50.00 | 810.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-916</a> | ₹38,691<br><a href="#">Volume Pricing</a> | Contact Us |
| 12.50 | 820.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-783</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 4 In Stock |
| 25.00 | 820.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-850</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 50.00 | 820.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-917</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 12.50 | 830.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-665</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00 | 830.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-725</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 12.50 | 840.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-784</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 3 In Stock |
| 25.00 | 840.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-851</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 50.00 | 840.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-918</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 2 In Stock |
| 12.50 | 850.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-785</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 7 In Stock |
| 25.00 | 850.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-852</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 8 In Stock |
| 50.00 | 850.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-919</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 12.50 | 850.00 | 40.00 | >50 | 200 - Far IR | - | <a href="#">#67-786</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 7 In Stock |
| 25.00 | 850.00 | 40.00 | >50 | 200 - Far IR | - | <a href="#">#67-853</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 50.00 | 850.00 | 40.00 | >50 | 200 - Far IR | - | <a href="#">#67-920</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 12.50 | 852.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-666</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 1 In Stock |

|       |        |       |     |              |   |                         |                                           |            |
|-------|--------|-------|-----|--------------|---|-------------------------|-------------------------------------------|------------|
| 25.00 | 852.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-726</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 4 In Stock |
| 50.00 | 852.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#86-638</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 12.50 | 855.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-667</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 2 In Stock |
| 25.00 | 855.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-727</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 12.50 | 860.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-787</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | Contact Us |
| 25.00 | 860.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-854</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 50.00 | 860.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-921</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 12.50 | 870.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-788</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 7 In Stock |
| 25.00 | 870.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-855</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 50.00 | 870.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-922</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 2 In Stock |
| 12.50 | 880.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-668</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 9 In Stock |
| 25.00 | 880.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-728</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 12.50 | 880.00 | 50.00 | ≥55 | 200 - 1200   | - | <a href="#">#65-739</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 1 In Stock |
| 25.00 | 880.00 | 50.00 | ≥55 | 200 - 1200   | - | <a href="#">#65-748</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 7 In Stock |
| 50.00 | 880.00 | 50.00 | ≥55 | 200 - 1200   | - | <a href="#">#87-195</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 4 In Stock |
| 12.50 | 890.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-789</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 2 In Stock |
| 25.00 | 890.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-856</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 2 In Stock |
| 50.00 | 890.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-923</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 2 In Stock |
| 12.50 | 900.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-790</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 1 In Stock |
| 25.00 | 900.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-857</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 50.00 | 900.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-924</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 12.50 | 900.00 | 40.00 | >50 | 200 - Far IR | - | <a href="#">#67-791</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | Contact Us |

|       |        |       |     |              |   |                         |                                           |              |
|-------|--------|-------|-----|--------------|---|-------------------------|-------------------------------------------|--------------|
| 25.00 | 900.00 | 40.00 | >50 | 200 - Far IR | - | <a href="#">#67-858</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 50.00 | 900.00 | 40.00 | >50 | 200 - Far IR | - | <a href="#">#67-925</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 905.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-669</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| 25.00 | 905.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-729</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 12.50 | 910.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-792</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 12 In Stock  |
| 25.00 | 910.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-859</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 50.00 | 910.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-926</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 920.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-793</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| 25.00 | 920.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-860</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 50.00 | 920.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-927</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 930.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-794</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 1 In Stock   |
| 25.00 | 930.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-861</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 50.00 | 930.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-928</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 940.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-670</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 4 In Stock   |
| 25.00 | 940.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-730</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.00 | 940.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#86-639</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 950.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-795</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 1 In Stock   |
| 25.00 | 950.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-862</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 950.00 | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-929</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 950.00 | 50.00 | ≥55 | 200 - 1200   | - | <a href="#">#65-740</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| 25.00 | 950.00 | 50.00 | ≥55 | 200 - 1200   | - | <a href="#">#65-749</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.00 | 950.00 | 50.00 | ≥55 | 200 - 1200   | - | <a href="#">#87-196</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 2 In Stock   |

|       |          |       |     |              |   |                         |                                           |            |
|-------|----------|-------|-----|--------------|---|-------------------------|-------------------------------------------|------------|
| 12.50 | 960.00   | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-796</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00 | 960.00   | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-863</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 50.00 | 960.00   | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-930</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 12.50 | 970.00   | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-797</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 1 In Stock |
| 25.00 | 970.00   | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-864</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 50.00 | 970.00   | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-931</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 12.50 | 990.00   | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-798</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 1 In Stock |
| 25.00 | 990.00   | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-865</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 50.00 | 990.00   | 10.00 | >50 | 200 - Far IR | - | <a href="#">#67-932</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 12.50 | 1,000.00 | 10.00 | >70 | 200 - 1200   | - | <a href="#">#65-768</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00 | 1,000.00 | 10.00 | >70 | 200 - 1200   | - | <a href="#">#65-782</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 12.50 | 1,050.00 | 10.00 | >70 | 200 - 1200   | - | <a href="#">#65-769</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00 | 1,050.00 | 10.00 | >70 | 200 - 1200   | - | <a href="#">#65-783</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 12.50 | 1,064.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-671</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 2 In Stock |
| 25.00 | 1,064.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#65-731</a> | ₹13,390<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 50.00 | 1,064.00 | 10.00 | ≥50 | 200 - 1200   | - | <a href="#">#87-006</a> | ₹38,691<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 12.50 | 1,100.00 | 10.00 | >70 | 200 - 1200   | - | <a href="#">#65-770</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 3 In Stock |
| 25.00 | 1,100.00 | 10.00 | >70 | 200 - 1200   | - | <a href="#">#65-784</a> | ₹16,349<br><a href="#">Volume Pricing</a> | Contact Us |
| 12.50 | 1,150.00 | 10.00 | >70 | 200 - 1350   | - | <a href="#">#65-771</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 8 In Stock |
| 25.00 | 1,150.00 | 10.00 | >70 | 200 - 1350   | - | <a href="#">#65-785</a> | ₹16,349<br><a href="#">Volume Pricing</a> | 2 In Stock |
| 12.50 | 1,200.00 | 10.00 | >70 | 200 - 1350   | - | <a href="#">#65-772</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 2 In Stock |
| 25.00 | 1,200.00 | 10.00 | >70 | 200 - 1350   | - | <a href="#">#65-786</a> | ₹16,349<br><a href="#">Volume Pricing</a> | 4 In Stock |



|       |          |       |     |            |   |                         |                                           |            |
|-------|----------|-------|-----|------------|---|-------------------------|-------------------------------------------|------------|
| 12.50 | 1,250.00 | 10.00 | >70 | 200 - 1500 | - | <a href="#">#65-773</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00 | 1,250.00 | 10.00 | >70 | 200 - 1500 | - | <a href="#">#65-787</a> | ₹16,349<br><a href="#">Volume Pricing</a> | 6 In Stock |
| 12.50 | 1,300.00 | 12.00 | >70 | 200 - 1500 | - | <a href="#">#65-774</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 7 In Stock |
| 25.00 | 1,300.00 | 12.00 | >70 | 200 - 1500 | - | <a href="#">#65-788</a> | ₹16,349<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 12.50 | 1,350.00 | 12.00 | >70 | 200 - 1500 | - | <a href="#">#65-775</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 7 In Stock |
| 25.00 | 1,350.00 | 12.00 | >70 | 200 - 1500 | - | <a href="#">#65-789</a> | ₹16,349<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 12.50 | 1,400.00 | 12.00 | >70 | 200 - 1800 | - | <a href="#">#65-776</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 8 In Stock |
| 25.00 | 1,400.00 | 12.00 | >70 | 200 - 1800 | - | <a href="#">#65-790</a> | ₹16,349<br><a href="#">Volume Pricing</a> | 2 In Stock |
| 12.50 | 1,450.00 | 12.00 | >70 | 200 - 1800 | - | <a href="#">#65-777</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00 | 1,450.00 | 12.00 | >70 | 200 - 1800 | - | <a href="#">#65-791</a> | ₹16,349<br><a href="#">Volume Pricing</a> | 8 In Stock |
| 12.50 | 1,500.00 | 12.00 | >70 | 200 - 1800 | - | <a href="#">#65-778</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 4 In Stock |
| 25.00 | 1,500.00 | 12.00 | >70 | 200 - 1800 | - | <a href="#">#65-792</a> | ₹16,349<br><a href="#">Volume Pricing</a> | 4 In Stock |
| 12.50 | 1,550.00 | 12.00 | >70 | 200 - 1800 | - | <a href="#">#65-779</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00 | 1,550.00 | 12.00 | >70 | 200 - 1800 | - | <a href="#">#65-793</a> | ₹16,349<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 12.50 | 1,600.00 | 12.00 | >65 | 200 - 1800 | - | <a href="#">#65-780</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00 | 1,600.00 | 12.00 | >65 | 200 - 1800 | - | <a href="#">#65-794</a> | ₹16,349<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 12.50 | 1,650.00 | 12.00 | >65 | 200 - 1800 | - | <a href="#">#65-781</a> | ₹7,240<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 25.00 | 1,650.00 | 12.00 | >65 | 200 - 1800 | - | <a href="#">#65-795</a> | ₹16,349<br><a href="#">Volume Pricing</a> | 5 In Stock |



**Edmund**  
optics | worldwide

Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

[www.edmundoptics.com](http://www.edmundoptics.com)