

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

## TECHSPEC® Fluorescence Bandpass Filters



- Common Wavelengths for Popular Fluorophores
- Excitation Filters and Emission Filters Available
- >93% Transmission
- >OD 6 Blocking, <3% from Edge of Bandwidth
- [Fluorescence Filter Sets](#) and [Pre-Mounted Fluorescence Filter Cube Sets](#) Also Available

### Common Specifications

#### Physical & Mechanical Properties

|                                  |                                                                                                                                                      |                                  |                                |
|----------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------|--------------------------------|
| <b>Thickness Tolerance (mm):</b> | ±0.1                                                                                                                                                 | <b>Construction:</b>             | Mounted in Black Anodized Ring |
| <b>Physical Durability:</b>      | Adhesion per MIL-PRF-13830B, Section C.4.5.12<br>Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11<br>Cleaning per MIL-C-48497A Section 4.5.4.2 | <b>Substrate Thickness (mm):</b> | 2.00 ±0.25                     |

#### Optical Properties

|                                    |                        |                                      |       |
|------------------------------------|------------------------|--------------------------------------|-------|
| <b>Angle of Incidence (°):</b>     | 0 ±5                   | <b>Optical Density OD (Average):</b> | ≥6.0  |
| <b>Coating:</b>                    | Hard Coated            | <b>Surface Quality:</b>              | 60-40 |
| <b>Transmitted Wavefront, RMS:</b> | λ/4 (prior to coating) |                                      |       |


#### Threading & Mounting

|                              |          |
|------------------------------|----------|
| <b>Mount Thickness (mm):</b> | 3.5 ±0.1 |
|------------------------------|----------|

#### Environmental & Durability Factors

|                                  |                                                                                                   |
|----------------------------------|---------------------------------------------------------------------------------------------------|
| <b>Environmental Durability:</b> | Humidity per MIL-STD-810H, Section 507.6<br>Temperature per MIL-STD-810H, Section 501.7 and 502.7 |
|----------------------------------|---------------------------------------------------------------------------------------------------|

Technical Information

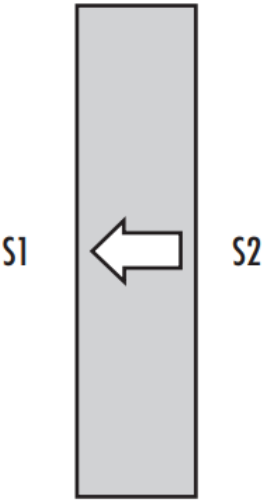

All mounted TECHSPEC® Optical Filters have an arrow on the side of the mount that points to the filter-coated surface for quick reference. Filter oriented such that arrow points to filter coated surface S1. Anti-reflective (AR) coating is applied to S2.

## Products

| Dia.<br>(mm) | CWL<br>(nm) | FWHM<br>(nm) | Average<br>Transmission<br>(%) | Compatible<br>Fluorophore                    | Blocking<br>Wavelength<br>Range<br>(nm) | Stock<br>Number         | Price                                     | Buy          |
|--------------|-------------|--------------|--------------------------------|----------------------------------------------|-----------------------------------------|-------------------------|-------------------------------------------|--------------|
| 12.50        | 340.00      | 29.00        | >75                            | FURA2 Excitation                             | 250 -925                                | <a href="#">#84-076</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00        | 340.00      | 29.00        | >75                            | FURA2 Excitation                             | 250 -925                                | <a href="#">#84-092</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.00        | 340.00      | 29.00        | >75                            | FURA2 Excitation                             | 250 -925                                | <a href="#">#84-108</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50        | 357.00      | 48.00        | >75                            | Tryptophan<br>Emission                       | 250 - 1100                              | <a href="#">#86-973</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 11 In Stock  |
| 25.00        | 357.00      | 48.00        | >75                            | Tryptophan<br>Emission                       | 250 - 1100                              | <a href="#">#86-981</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.00        | 357.00      | 48.00        | >75                            | Tryptophan<br>Emission                       | 250 - 1100                              | <a href="#">#86-989</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50        | 370.00      | 40.00        | >85                            | Sirius Excitation                            | 250 - 1100                              | <a href="#">#86-974</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 25.00        | 370.00      | 40.00        | >85                            | Sirius Excitation                            | 250 - 1100                              | <a href="#">#86-982</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 12 In Stock  |
| 50.00        | 370.00      | 40.00        | >85                            | Sirius Excitation                            | 250 - 1100                              | <a href="#">#86-990</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50        | 377.00      | 54.00        | >85                            | DAPI Excitation                              | 250 - 1100                              | <a href="#">#84-077</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 25.00        | 377.00      | 54.00        | >85                            | DAPI Excitation                              | 250 - 1100                              | <a href="#">#84-093</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 15 In Stock  |
| 50.00        | 377.00      | 54.00        | >85                            | DAPI Excitation                              | 250 - 1100                              | <a href="#">#84-109</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 12.50        | 386.00      | 27.00        | >90                            | DAPI Excitation                              | 250 - 1100                              | <a href="#">#33-320</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00        | 386.00      | 27.00        | >90                            | DAPI Excitation                              | 250 - 1100                              | <a href="#">#33-321</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 50.00        | 386.00      | 27.00        | >90                            | DAPI Excitation                              | 250 - 1100                              | <a href="#">#33-322</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 12.50        | 387.00      | 15.00        | >90                            | DAPI Excitation /<br>BFP & GFP<br>Excitation | 250 -1050                               | <a href="#">#84-078</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00        | 387.00      | 15.00        | >90                            | DAPI Excitation /<br>BFP & GFP<br>Excitation | 250 -1050                               | <a href="#">#84-094</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 50.00        | 387.00      | 15.00        | >90                            | DAPI Excitation /<br>BFP & GFP<br>Excitation | 250 -1050                               | <a href="#">#84-110</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |

|       |        |       |     |                                          |            |                         |                                           |              |
|-------|--------|-------|-----|------------------------------------------|------------|-------------------------|-------------------------------------------|--------------|
| 12.50 | 390.00 | 45.00 | >90 | 405nm Laser<br>Excitation                | 250 - 1100 | <a href="#">#86-337</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00 | 390.00 | 45.00 | >90 | 405nm Laser<br>Excitation                | 250 - 1100 | <a href="#">#86-348</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 390.00 | 45.00 | >90 | 405nm Laser<br>Excitation                | 250 - 1100 | <a href="#">#86-359</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 435.00 | 48.00 | >93 | Qdot® Excitation                         | 250 - 1100 | <a href="#">#86-338</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 25.00 | 435.00 | 48.00 | >93 | Qdot® Excitation                         | 250 - 1100 | <a href="#">#86-349</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.00 | 435.00 | 48.00 | >93 | Qdot® Excitation                         | 250 - 1100 | <a href="#">#86-360</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 12 In Stock  |
| 12.50 | 438.00 | 28.00 | >93 | CFP Excitation                           | 250 - 1100 | <a href="#">#67-012</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 25.00 | 438.00 | 28.00 | >93 | CFP Excitation                           | 250 - 1100 | <a href="#">#67-026</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 50.00 | 438.00 | 28.00 | >93 | CFP Excitation                           | 250 - 1100 | <a href="#">#67-040</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 440.00 | 46.00 | >93 | Sirius Emission                          | 250 - 1100 | <a href="#">#86-339</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 25.00 | 440.00 | 46.00 | >93 | Sirius Emission                          | 250 - 1100 | <a href="#">#86-350</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 50.00 | 440.00 | 46.00 | >93 | Sirius Emission                          | 250 - 1100 | <a href="#">#86-361</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 447.00 | 65.00 | >93 | DAPI Emission /<br>BFP & GFP<br>Emission | 250 - 1100 | <a href="#">#84-079</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 25.00 | 447.00 | 65.00 | >93 | DAPI Emission /<br>BFP & GFP<br>Emission | 250 - 1100 | <a href="#">#84-095</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 50.00 | 447.00 | 65.00 | >93 | DAPI Emission /<br>BFP & GFP<br>Emission | 250 - 1100 | <a href="#">#84-111</a> | ₹68,975<br><a href="#">Volume Pricing</a> | Contact Us   |
| 12.50 | 448.00 | 25.00 | >93 | 442nm Laser<br>Excitation                | 250 - 1100 | <a href="#">#86-975</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 25.00 | 448.00 | 25.00 | >93 | 442nm Laser<br>Excitation                | 250 - 1100 | <a href="#">#86-983</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 50.00 | 448.00 | 25.00 | >93 | 442nm Laser<br>Excitation                | 250 - 1100 | <a href="#">#86-991</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 452.00 | 51.00 | >93 | DiA Excitation                           | 250 - 1100 | <a href="#">#86-340</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 11 In Stock  |
| 25.00 | 452.00 | 51.00 | >93 | DiA Excitation                           | 250 - 1100 | <a href="#">#86-351</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 16 In Stock  |
| 50.00 | 452.00 | 51.00 | >93 | DiA Excitation                           | 250 - 1100 | <a href="#">#86-362</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 3 In Stock   |

|       |        |       |     |                                   |            |                         |                                           |              |
|-------|--------|-------|-----|-----------------------------------|------------|-------------------------|-------------------------------------------|--------------|
| 12.50 | 466.00 | 45.00 | >93 | GFP Excitation                    | 250 - 1100 | <a href="#">#86-341</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 25.00 | 466.00 | 45.00 | >93 | GFP Excitation                    | 250 - 1100 | <a href="#">#86-352</a> | ₹25,457<br><a href="#">Volume Pricing</a> | Contact Us   |
| 50.00 | 466.00 | 45.00 | >93 | GFP Excitation                    | 250 - 1100 | <a href="#">#86-363</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 472.00 | 35.00 | >93 | GFP Excitation                    | 250 - 1100 | <a href="#">#67-013</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 472.00 | 35.00 | >93 | GFP Excitation                    | 250 - 1100 | <a href="#">#67-027</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 15 In Stock  |
| 50.00 | 472.00 | 35.00 | >93 | GFP Excitation                    | 250 - 1100 | <a href="#">#67-041</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 475.00 | 56.00 | >93 | FITC Excitation                   | 250 - 1100 | <a href="#">#86-342</a> | ₹20,241<br><a href="#">Volume Pricing</a> | Contact Us   |
| 25.00 | 475.00 | 56.00 | >93 | FITC Excitation                   | 250 - 1100 | <a href="#">#86-353</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 475.00 | 56.00 | >93 | FITC Excitation                   | 250 - 1100 | <a href="#">#86-364</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 482.50 | 36.00 | >93 | FITC Excitation /<br>CFP Emission | 250 - 1100 | <a href="#">#67-014</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 482.50 | 36.00 | >93 | FITC Excitation /<br>CFP Emission | 250 - 1100 | <a href="#">#67-028</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 10 In Stock  |
| 50.00 | 482.50 | 36.00 | >93 | FITC Excitation /<br>CFP Emission | 250 - 1100 | <a href="#">#67-042</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 12.50 | 494.00 | 25.00 | >93 | SpectrumGreen™<br>Excitation      | 300 - 1150 | <a href="#">#84-080</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 494.00 | 25.00 | >93 | SpectrumGreen™<br>Excitation      | 300 - 1150 | <a href="#">#84-096</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 13 In Stock  |
| 50.00 | 494.00 | 25.00 | >93 | SpectrumGreen™<br>Excitation      | 300 - 1150 | <a href="#">#84-112</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 12.50 | 500.00 | 29.00 | >93 | YFP Excitation                    | 250 - 1100 | <a href="#">#67-015</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00 | 500.00 | 29.00 | >93 | YFP Excitation                    | 250 - 1100 | <a href="#">#67-029</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.00 | 500.00 | 29.00 | >93 | YFP Excitation                    | 250 - 1100 | <a href="#">#67-043</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 510.00 | 25.00 | >93 | Cy2 Emission /<br>Cy3 Excitation  | 250 - 1100 | <a href="#">#87-734</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 510.00 | 25.00 | >93 | Cy2 Emission /<br>Cy3 Excitation  | 250 - 1100 | <a href="#">#87-748</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 50.00 | 510.00 | 25.00 | >93 | Cy2 Emission /<br>Cy3 Excitation  | 250 - 1100 | <a href="#">#87-762</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 12.50 | 510.00 | 89.00 | >93 | FURA2 Emission                    | 250 - 1100 | <a href="#">#84-081</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 11 In Stock  |

|       |        |       |     |                                          |            |                         |                                           |              |
|-------|--------|-------|-----|------------------------------------------|------------|-------------------------|-------------------------------------------|--------------|
| 25.00 | 510.00 | 89.00 | >93 | FURA2 Emission                           | 250 - 1100 | <a href="#">#84-097</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 50.00 | 510.00 | 89.00 | >93 | FURA2 Emission                           | 250 - 1100 | <a href="#">#84-113</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 512.00 | 30.00 | >93 | Fluorescein Emission                     | 250 - 1100 | <a href="#">#33-323</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 25.00 | 512.00 | 30.00 | >93 | Fluorescein Emission                     | 250 - 1100 | <a href="#">#33-324</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 512.00 | 30.00 | >93 | Fluorescein Emission                     | 250 - 1100 | <a href="#">#33-325</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 12.50 | 520.00 | 41.00 | >93 | GFP Emission                             | 250 -1025  | <a href="#">#67-016</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 520.00 | 41.00 | >93 | GFP Emission                             | 250 -1025  | <a href="#">#67-030</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 520.00 | 41.00 | >93 | GFP Emission                             | 250 -1025  | <a href="#">#67-044</a> | ₹68,975<br><a href="#">Volume Pricing</a> | Contact Us   |
| 12.50 | 520.00 | 77.00 | >93 | Alexa Fluor® 488 Emission / GFP Emission | 250 -1200  | <a href="#">#87-735</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 25.00 | 520.00 | 77.00 | >93 | Alexa Fluor® 488 Emission / GFP Emission | 250 -1200  | <a href="#">#87-749</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 520.00 | 77.00 | >93 | Alexa Fluor® 488 Emission / GFP Emission | 250 -1200  | <a href="#">#87-763</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 12.50 | 525.00 | 18.00 | >93 | Qdot® 525 Emission                       | 250 - 1100 | <a href="#">#86-343</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00 | 525.00 | 18.00 | >93 | Qdot® 525 Emission                       | 250 - 1100 | <a href="#">#86-354</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 50.00 | 525.00 | 18.00 | >93 | Qdot® 525 Emission                       | 250 - 1100 | <a href="#">#86-365</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 525.00 | 51.00 | >93 | GPF/FITC Emission                        | 250 - 1100 | <a href="#">#86-976</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 25.00 | 525.00 | 51.00 | >93 | GPF/FITC Emission                        | 250 - 1100 | <a href="#">#86-984</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 13 In Stock  |
| 50.00 | 525.00 | 51.00 | >93 | GPF/FITC Emission                        | 250 - 1100 | <a href="#">#86-992</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 12.50 | 527.00 | 22.00 | >93 | SpectrumGreen™ Emission                  | 250 - 1100 | <a href="#">#84-082</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 25.00 | 527.00 | 22.00 | >93 | SpectrumGreen™ Emission                  | 250 - 1100 | <a href="#">#84-098</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 50.00 | 527.00 | 22.00 | >93 | SpectrumGreen™ Emission                  | 250 - 1100 | <a href="#">#84-114</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 4 In Stock   |

|       |        |       |     |                                                                 |            |                         |                                           |              |
|-------|--------|-------|-----|-----------------------------------------------------------------|------------|-------------------------|-------------------------------------------|--------------|
| 12.50 | 530.00 | 62.00 | >93 | Alexa Fluor® 532<br>Excitation /<br>Thiazole Orange<br>Emission | 250 - 1100 | <a href="#">#87-736</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 25.00 | 530.00 | 62.00 | >93 | Alexa Fluor® 532<br>Excitation /<br>Thiazole Orange<br>Emission | 250 - 1100 | <a href="#">#87-750</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 50.00 | 530.00 | 62.00 | >93 | Alexa Fluor® 532<br>Excitation /<br>Thiazole Orange<br>Emission | 250 - 1100 | <a href="#">#87-764</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 534.00 | 25.00 | >93 | SpectrumGold™<br>Excitation                                     | 250 - 1100 | <a href="#">#84-083</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 534.00 | 25.00 | >93 | SpectrumGold™<br>Excitation                                     | 250 - 1100 | <a href="#">#84-099</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 17 In Stock  |
| 50.00 | 534.00 | 25.00 | >93 | SpectrumGold™<br>Excitation                                     | 250 - 1100 | <a href="#">#84-115</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 12.50 | 534.50 | 48.00 | >93 | Cy3 Excitation /<br>FITC Emission                               | 250 - 1100 | <a href="#">#67-017</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 534.50 | 48.00 | >93 | Cy3 Excitation /<br>FITC Emission                               | 250 - 1100 | <a href="#">#67-031</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 17 In Stock  |
| 50.00 | 534.50 | 48.00 | >93 | Cy3 Excitation /<br>FITC Emission                               | 250 - 1100 | <a href="#">#67-045</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 540.00 | 56.00 | >93 | FITC Emission                                                   | 250 - 1100 | <a href="#">#86-344</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 16 In Stock  |
| 25.00 | 540.00 | 56.00 | >93 | FITC Emission                                                   | 250 - 1100 | <a href="#">#86-355</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 14 In Stock  |
| 50.00 | 540.00 | 56.00 | >93 | FITC Emission                                                   | 250 - 1100 | <a href="#">#86-366</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 543.00 | 27.00 | >93 | YFP Emission /<br>TRITC Excitation                              | 250 - 1100 | <a href="#">#67-018</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 25.00 | 543.00 | 27.00 | >93 | YFP Emission /<br>TRITC Excitation                              | 250 - 1100 | <a href="#">#67-032</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 543.00 | 27.00 | >93 | YFP Emission /<br>TRITC Excitation                              | 250 - 1100 | <a href="#">#67-046</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 12.50 | 549.00 | 21.00 | >93 | Alexa Fluor® 532<br>Emission /<br>DyLight™<br>Excitation        | 250 - 1100 | <a href="#">#87-737</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 25.00 | 549.00 | 21.00 | >93 | Alexa Fluor® 532<br>Emission /<br>DyLight™<br>Excitation        | 250 - 1100 | <a href="#">#87-751</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 2 In Stock   |

|       |        |        |     |                                                          |            |                         |                                           |              |
|-------|--------|--------|-----|----------------------------------------------------------|------------|-------------------------|-------------------------------------------|--------------|
| 50.00 | 549.00 | 21.00  | >93 | Alexa Fluor® 532<br>Emission /<br>DyLight™<br>Excitation | 250 - 1100 | <a href="#">#87-765</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 550.00 | 100.00 | >93 | Broadband Green<br>Fluorescence                          | 250 - 1100 | <a href="#">#33-329</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 550.00 | 100.00 | >93 | Broadband Green<br>Fluorescence                          | 250 - 1100 | <a href="#">#33-330</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 50.00 | 550.00 | 100.00 | >93 | Broadband Green<br>Fluorescence                          | 250 - 1100 | <a href="#">#33-331</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 12.50 | 560.00 | 32.00  | >93 | 561nm Laser<br>Emission                                  | 250 - 1100 | <a href="#">#86-977</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 25.00 | 560.00 | 32.00  | >93 | 561nm Laser<br>Emission                                  | 250 - 1100 | <a href="#">#86-985</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 50.00 | 560.00 | 32.00  | >93 | 561nm Laser<br>Emission                                  | 250 - 1100 | <a href="#">#86-993</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 561.00 | 21.00  | >93 | Keima Red<br>Excitation                                  | 250 - 1100 | <a href="#">#86-978</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 25.00 | 561.00 | 21.00  | >93 | Keima Red<br>Excitation                                  | 250 - 1100 | <a href="#">#86-986</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 10 In Stock  |
| 50.00 | 561.00 | 21.00  | >93 | Keima Red<br>Excitation                                  | 250 - 1100 | <a href="#">#86-994</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 562.00 | 46.00  | >93 | Texas Red<br>Excitation /<br>mCherry Excitation          | 250 -1000  | <a href="#">#67-019</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 10 In Stock  |
| 25.00 | 562.00 | 46.00  | >93 | Texas Red<br>Excitation /<br>mCherry Excitation          | 250 -1000  | <a href="#">#67-033</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 16 In Stock  |
| 50.00 | 562.00 | 46.00  | >93 | Texas Red<br>Excitation /<br>mCherry Excitation          | 250 -1000  | <a href="#">#67-047</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 572.00 | 33.00  | >93 | SpectrumGold™<br>Emission                                | 250 -1120  | <a href="#">#84-084</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 572.00 | 33.00  | >93 | SpectrumGold™<br>Emission                                | 250 -1120  | <a href="#">#84-100</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 50.00 | 572.00 | 33.00  | >93 | SpectrumGold™<br>Emission                                | 250 -1120  | <a href="#">#84-116</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 575.00 | 35.00  | >93 | Alexa Fluor® 568<br>Excitation                           | 250 - 1100 | <a href="#">#33-332</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 25.00 | 575.00 | 35.00  | >93 | Alexa Fluor® 568<br>Excitation                           | 250 - 1100 | <a href="#">#33-333</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.00 | 575.00 | 35.00  | >93 | Alexa Fluor® 568<br>Excitation                           | 250 - 1100 | <a href="#">#33-334</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 2 In Stock   |

|       |        |       |     |                                                             |            |                         |                                           |              |
|-------|--------|-------|-----|-------------------------------------------------------------|------------|-------------------------|-------------------------------------------|--------------|
| 12.50 | 578.00 | 22.00 | >93 | Alexa Fluor® 568<br>Excitation / Cy3.5<br>Emission          | 250 - 1100 | <a href="#">#87-738</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00 | 578.00 | 22.00 | >93 | Alexa Fluor® 568<br>Excitation / Cy3.5<br>Emission          | 250 - 1100 | <a href="#">#87-752</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 50.00 | 578.00 | 22.00 | >93 | Alexa Fluor® 568<br>Excitation / Cy3.5<br>Emission          | 250 - 1100 | <a href="#">#87-766</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 12.50 | 585.00 | 40.00 | >93 | -                                                           | 250 -1100  | <a href="#">#33-906</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00 | 585.00 | 40.00 | >93 | -                                                           | 250 -1100  | <a href="#">#33-907</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.00 | 585.00 | 40.00 | >93 | -                                                           | 250 -1100  | <a href="#">#33-908</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 586.00 | 26.00 | >93 | SpectrumOrange™<br>Emission /<br>SpectrumRed™<br>Excitation | 250 -1120  | <a href="#">#84-085</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 586.00 | 26.00 | >93 | SpectrumOrange™<br>Emission /<br>SpectrumRed™<br>Excitation | 250 -1120  | <a href="#">#84-101</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 50.00 | 586.00 | 26.00 | >93 | SpectrumOrange™<br>Emission /<br>SpectrumRed™<br>Excitation | 250 -1120  | <a href="#">#84-117</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 12.50 | 591.50 | 49.00 | >93 | Cy3 Emission /<br>TRITC Emission                            | 250 - 1100 | <a href="#">#67-020</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 591.50 | 49.00 | >93 | Cy3 Emission /<br>TRITC Emission                            | 250 - 1100 | <a href="#">#67-034</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 10 In Stock  |
| 50.00 | 591.50 | 49.00 | >93 | Cy3 Emission /<br>TRITC Emission                            | 250 - 1100 | <a href="#">#67-048</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 12.50 | 605.00 | 22.00 | >93 | Qdot® 605<br>Emission                                       | 250 - 1100 | <a href="#">#86-345</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 605.00 | 22.00 | >93 | Qdot® 605<br>Emission                                       | 250 - 1100 | <a href="#">#86-356</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 50.00 | 605.00 | 22.00 | >93 | Qdot® 605<br>Emission                                       | 250 - 1100 | <a href="#">#86-367</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 12.50 | 607.00 | 42.00 | >93 | GFP Emission /<br>RFP Emission                              | 250 -1000  | <a href="#">#84-086</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 13 In Stock  |
| 25.00 | 607.00 | 42.00 | >93 | GFP Emission /<br>RFP Emission                              | 250 -1000  | <a href="#">#84-102</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.00 | 607.00 | 42.00 | >93 | GFP Emission /<br>RFP Emission                              | 250 -1000  | <a href="#">#84-118</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 3 In Stock   |

|       |        |       |     |                                                 |            |                         |                                           |              |
|-------|--------|-------|-----|-------------------------------------------------|------------|-------------------------|-------------------------------------------|--------------|
| 12.50 | 615.00 | 26.00 | >93 | Alexa Fluor® 594<br>Emission / Cy3<br>Emission  | 250 - 1100 | <a href="#">#87-739</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 615.00 | 26.00 | >93 | Alexa Fluor® 594<br>Emission / Cy3™<br>Emission | 250 - 1100 | <a href="#">#87-753</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 50.00 | 615.00 | 26.00 | >93 | Alexa Fluor® 594<br>Emission / Cy3™<br>Emission | 250 - 1100 | <a href="#">#87-767</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 12.50 | 620.00 | 60.00 | >93 | -                                               | 250 - 1100 | <a href="#">#33-909</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00 | 620.00 | 60.00 | >93 | -                                               | 250 - 1100 | <a href="#">#33-910</a> | ₹25,457<br><a href="#">Volume Pricing</a> | Contact Us   |
| 50.00 | 620.00 | 60.00 | >93 | -                                               | 250 - 1100 | <a href="#">#33-911</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 12.50 | 623.00 | 30.00 | >93 | Cy5 Excitation /<br>Texas Red®<br>Emission      | 250 - 1100 | <a href="#">#87-740</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 623.00 | 30.00 | >93 | Cy5 Excitation /<br>Texas Red®<br>Emission      | 250 - 1100 | <a href="#">#87-754</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.00 | 623.00 | 30.00 | >93 | Cy5 Excitation /<br>Texas Red®<br>Emission      | 250 - 1100 | <a href="#">#87-768</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 12.50 | 624.00 | 46.00 | >93 | Texas Red<br>Emission / Cy5<br>Excitation       | 250 -1000  | <a href="#">#67-021</a> | ₹20,241<br><a href="#">Volume Pricing</a> | Contact Us   |
| 25.00 | 624.00 | 46.00 | >93 | Texas Red<br>Emission / Cy5<br>Excitation       | 250 -1000  | <a href="#">#67-035</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 624.00 | 46.00 | >93 | Texas Red<br>Emission / Cy5<br>Excitation       | 250 -1000  | <a href="#">#67-049</a> | ₹68,975<br><a href="#">Volume Pricing</a> | Contact Us   |
| 12.50 | 625.00 | 25.00 | >93 | Qdot® 625<br>Emission                           | 250 - 1100 | <a href="#">#86-346</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 12 In Stock  |
| 25.00 | 625.00 | 25.00 | >93 | Qdot® 625<br>Emission                           | 250 - 1100 | <a href="#">#86-357</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 50.00 | 625.00 | 25.00 | >93 | Qdot® 625<br>Emission                           | 250 - 1100 | <a href="#">#86-368</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 628.00 | 38.00 | >93 | SpectrumRed™<br>Emission / Cy5<br>Excitation    | 250 - 1100 | <a href="#">#84-087</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 628.00 | 38.00 | >93 | SpectrumRed™<br>Emission / Cy5<br>Excitation    | 250 - 1100 | <a href="#">#84-103</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 50.00 | 628.00 | 38.00 | >93 | SpectrumRed™<br>Emission / Cy5<br>Excitation    | 250 - 1100 | <a href="#">#84-119</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 2 In Stock   |

|       |        |       |     |                                                                  |            |                         |                                           |              |
|-------|--------|-------|-----|------------------------------------------------------------------|------------|-------------------------|-------------------------------------------|--------------|
| 12.50 | 631.00 | 28.00 | >93 | Alexa Fluor® 633<br>Excitation                                   | 250 - 1100 | <a href="#">#33-326</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 25.00 | 631.00 | 28.00 | >93 | Alexa Fluor® 633<br>Excitation                                   | 250 - 1100 | <a href="#">#33-327</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.00 | 631.00 | 28.00 | >93 | Alexa Fluor® 633<br>Excitation                                   | 250 - 1100 | <a href="#">#33-328</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 12.50 | 640.00 | 20.00 | >93 | 635nm Laser<br>Excitation                                        | 250 - 1100 | <a href="#">#86-979</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 25.00 | 640.00 | 20.00 | >93 | 635nm Laser<br>Excitation                                        | 250 - 1100 | <a href="#">#86-987</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 50.00 | 640.00 | 20.00 | >93 | 635nm Laser<br>Excitation                                        | 250 - 1100 | <a href="#">#86-995</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 640.50 | 81.00 | >93 | mCherry Emission                                                 | 250 - 1100 | <a href="#">#67-022</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 640.50 | 81.00 | >93 | mcherry Emission                                                 | 250 - 1100 | <a href="#">#67-036</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 11 In Stock  |
| 50.00 | 640.50 | 81.00 | >93 | mCherry Emission                                                 | 250 - 1100 | <a href="#">#67-050</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 648.00 | 20.00 | >93 | FITC Emission                                                    | 250 - 1100 | <a href="#">#33-335</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 25.00 | 648.00 | 20.00 | >93 | FITC Emission                                                    | 250 - 1100 | <a href="#">#33-336</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 50.00 | 648.00 | 20.00 | >93 | FITC Emission                                                    | 250 - 1100 | <a href="#">#33-337</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 655.00 | 24.00 | >93 | Qdot® 655<br>Emission                                            | 250 - 1100 | <a href="#">#86-347</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 655.00 | 24.00 | >93 | Qdot® 655<br>Emission                                            | 250 - 1100 | <a href="#">#86-358</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 50.00 | 655.00 | 24.00 | >93 | Qdot® 655<br>Emission                                            | 250 - 1100 | <a href="#">#86-369</a> | ₹68,975<br><a href="#">Volume Pricing</a> | Contact Us   |
| 12.50 | 655.00 | 47.00 | >93 | Cy5.5 Excitation                                                 | 250 - 1100 | <a href="#">#67-023</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 13 In Stock  |
| 25.00 | 655.00 | 47.00 | >93 | Cy5.5 Excitation                                                 | 250 - 1100 | <a href="#">#67-037</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 50.00 | 655.00 | 47.00 | >93 | Cy5.5 Excitation                                                 | 250 - 1100 | <a href="#">#67-051</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 661.00 | 26.00 | >93 | Alexa Fluor®647<br>Excitation / TO-<br>PRO®-3 Iodide<br>Emission | 250 - 1100 | <a href="#">#87-741</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 661.00 | 26.00 | >93 | Alexa Fluor®647<br>Excitation / TO-<br>PRO®-3 Iodide<br>Emission | 250 - 1100 | <a href="#">#87-755</a> | ₹25,457<br><a href="#">Volume Pricing</a> | Contact Us   |

|       |        |       |     |                                                                  |            |                         |                                           |              |
|-------|--------|-------|-----|------------------------------------------------------------------|------------|-------------------------|-------------------------------------------|--------------|
| 50.00 | 661.00 | 26.00 | >93 | Alexa Fluor®647<br>Excitation / TO-<br>PRO®-3 Iodide<br>Emission | 250 - 1100 | <a href="#">#87-769</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 11 In Stock  |
| 12.50 | 676.00 | 36.00 | >93 | Cy5 Emission                                                     | 250 - 1100 | <a href="#">#86-980</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 25.00 | 676.00 | 36.00 | >93 | Cy5 Emission                                                     | 250 - 1100 | <a href="#">#86-988</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 50.00 | 676.00 | 36.00 | >93 | Cy5 Emission                                                     | 250 - 1100 | <a href="#">#86-996</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 12.50 | 692.00 | 47.00 | >93 | Cy5 Emission                                                     | 250 - 1100 | <a href="#">#67-024</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 692.00 | 47.00 | >93 | Cy5 Emission                                                     | 250 - 1100 | <a href="#">#67-038</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 692.00 | 47.00 | >93 | Cy5 Emission                                                     | 250 - 1100 | <a href="#">#67-052</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 12.50 | 697.00 | 91.00 | >93 | Alexa Fluor® 680<br>Emission / Cy5.5™<br>Emission                | 250 - 1100 | <a href="#">#87-743</a> | ₹20,241<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 25.00 | 697.00 | 91.00 | >93 | Alexa Fluor® 680<br>Emission / Cy5.5™<br>Emission                | 250 - 1100 | <a href="#">#87-757</a> | ₹25,457<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 50.00 | 697.00 | 91.00 | >93 | Alexa Fluor® 680<br>Emission / Cy5.5™<br>Emission                | 250 - 1100 | <a href="#">#87-771</a> | ₹68,975<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 12.50 | 710.00 | 47.00 | >93 | Cy7 Excitation                                                   | 250 - 1100 | <a href="#">#84-088</a> | ₹21,175<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 25.00 | 710.00 | 47.00 | >93 | Cy7 Excitation                                                   | 250 - 1100 | <a href="#">#84-104</a> | ₹26,313<br><a href="#">Volume Pricing</a> | 11 In Stock  |
| 50.00 | 710.00 | 47.00 | >93 | Cy7 Excitation                                                   | 250 - 1100 | <a href="#">#84-120</a> | ₹70,688<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 716.00 | 47.00 | >93 | Cy5 Emission                                                     | 250 - 1100 | <a href="#">#67-025</a> | ₹21,175<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 716.00 | 47.00 | >93 | Cy5 Emission                                                     | 250 - 1100 | <a href="#">#67-039</a> | ₹26,313<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 50.00 | 716.00 | 47.00 | >93 | Cy5 Emission                                                     | 250 - 1100 | <a href="#">#67-053</a> | ₹70,688<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 12.50 | 732.00 | 76.00 | >93 | Cy7 Excitation /<br>DY-732 Excitation                            | 250 - 1100 | <a href="#">#87-744</a> | ₹21,175<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 25.00 | 732.00 | 76.00 | >93 | Cy7 Excitation /<br>DY-732 Excitation                            | 250 - 1100 | <a href="#">#87-758</a> | ₹26,313<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 732.00 | 76.00 | >93 | Cy7 Excitation /<br>DY-732 Excitation                            | 250 - 1100 | <a href="#">#87-772</a> | ₹70,688<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 12.50 | 769.00 | 48.00 | >93 | ICG-A Excitation                                                 | 250 -1150  | <a href="#">#84-089</a> | ₹21,175<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 25.00 | 769.00 | 48.00 | >93 | ICG-A Excitation                                                 | 250 -1150  | <a href="#">#84-105</a> | ₹26,313<br><a href="#">Volume Pricing</a> | 20+ In Stock |

|                                                                                  |                                     |                  |            |                                                          |                                           |                         |                                           |              |
|----------------------------------------------------------------------------------|-------------------------------------|------------------|------------|----------------------------------------------------------|-------------------------------------------|-------------------------|-------------------------------------------|--------------|
| 50.00                                                                            | 769.00                              | 48.00            | >93        | ICG-A Excitation                                         | 250 -1150                                 | <a href="#">#84-121</a> | ₹70,688<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 12.50                                                                            | 775.00                              | 54.00            | >93        | Cy7 Emission                                             | 250 - 1100                                | <a href="#">#84-090</a> | ₹21,175<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00                                                                            | 775.00                              | 54.00            | >93        | Cy7 Excitation                                           | 250 - 1100                                | <a href="#">#84-106</a> | ₹26,313<br><a href="#">Volume Pricing</a> | 12 In Stock  |
| 50.00                                                                            | 775.00                              | 54.00            | >93        | Cy7 Excitation                                           | 250 - 1100                                | <a href="#">#84-122</a> | ₹70,688<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 12.50                                                                            | 785.00                              | 71.00            | >93        | Alexa Fluor® 790<br>Excitation / Irdye<br>800RS Emission | 250 - 1100                                | <a href="#">#87-745</a> | ₹21,175<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00                                                                            | 785.00                              | 71.00            | >93        | Alexa Fluor® 790<br>Excitation / Irdye<br>800RS Emission | 250 - 1100                                | <a href="#">#87-759</a> | ₹26,313<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00                                                                            | 785.00                              | 71.00            | >93        | Alexa Fluor® 790<br>Excitation / Irdye<br>800RS Emission | 250 - 1100                                | <a href="#">#87-773</a> | ₹70,688<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 12.50                                                                            | 832.00                              | 45.00            | >93        | ICG-A Excitation                                         | 250 - 1100                                | <a href="#">#84-091</a> | ₹21,175<br><a href="#">Volume Pricing</a> | 20+ In Stock |
|  | <b>Edmund</b><br>optics   worldwide | ICG-A Excitation | 250 - 1100 | <a href="#">#84-107</a>                                  | ₹26,313<br><a href="#">Volume Pricing</a> | 9 In Stock              |                                           |              |

Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 6, Indiranagar, Bengaluru, Karnataka, India 560038  
 Phone: 1-800-363-1992 : [www.edmundoptics.com](http://www.edmundoptics.com)