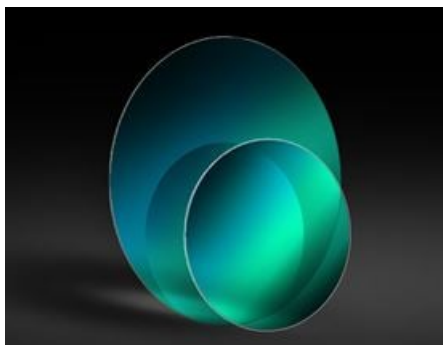


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [Visible Windows](#)
TECHSPEC® Ultra-Thin N-BK7 Windows See More by [SCHOTT Optical Components](#)


- Ultra-Thin 0.20mm Thickness
- Precision N-BK7 Substrate
- Extremely Lightweight

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Edges:	Fine Ground
Knoop Hardness (kg/mm²):	610.00	Parallelism (arcsec):	<30
Poisson's Ratio:	0.21	Young's Modulus (GPa):	82

Optical Properties

Abbe Number (v_d):	64.17	Index of Refraction (n_d):	1.516
Substrate:	N-BK7	Transmitted Wavefront, P-V:	$\lambda/2$

Material Properties

Density (g/cm³):	2.51
------------------------------------	------

Technical Information

Products

Dia. (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
5.00	0.20	Uncoated	#66-184	₹6,858 Volume Pricing	20+ In Stock
10.00	0.20	Uncoated	#66-185	₹6,858 Volume Pricing	20+ In Stock
12.50	0.20	Uncoated	#66-186	₹6,858 Volume Pricing	20+ In Stock
20.00	0.20	Uncoated	#66-187	₹6,858 Volume Pricing	20+ In Stock
25.00	0.20	Uncoated	#66-188	₹8,215 Volume Pricing	20+ In Stock
30.00	0.20	Uncoated	#66-189	₹9,902 Volume Pricing	20+ In Stock
40.00	0.20	Uncoated	#66-190	₹10,489 Volume Pricing	20+ In Stock
50.00	0.20	Uncoated	#66-191	₹13,130 Volume Pricing	20+ In Stock
5.00	0.20	MgF ₂ (400-700nm)	#66-192	₹7,628 Volume Pricing	20+ In Stock
10.00	0.20	MgF ₂ (400-700nm)	#66-193	₹7,628 Volume Pricing	20+ In Stock
12.50	0.20	MgF ₂ (400-700nm)	#66-194	₹7,628 Volume Pricing	20+ In Stock
20.00	0.20	MgF ₂ (400-700nm)	#66-195	₹7,628 Volume Pricing	15 In Stock
25.00	0.20	MgF ₂ (400-700nm)	#66-196	₹8,949 Volume Pricing	20+ In Stock
30.00	0.20	MgF ₂ (400-700nm)	#66-197	₹11,076 Volume Pricing	20+ In Stock
40.00	0.20	MgF ₂ (400-700nm)	#66-198	₹11,663 Volume Pricing	20+ In Stock
50.00	0.20	MgF ₂ (400-700nm)	#66-199	₹14,303 Volume Pricing	7 In Stock
5.00	0.20	VIS 0° (425-675nm)	#83-099	₹8,362 Volume Pricing	20+ In Stock

10.00	0.20	VIS 0° (425-675nm)	#83-100	₹8,362 Volume Pricing	11 In Stock
12.50	0.20	VIS 0° (425-675nm)	#83-101	₹8,362 Volume Pricing	20+ In Stock
20.00	0.20	VIS 0° (425-675nm)	#83-102	₹8,362 Volume Pricing	20+ In Stock
25.00	0.20	VIS 0° (425-675nm)	#83-103	₹9,756 Volume Pricing	20+ In Stock
30.00	0.20	VIS 0° (425-675nm)	#83-104	₹11,809 Volume Pricing	20+ In Stock
40.00	0.20	VIS 0° (425-675nm)	#83-105	₹12,396 Volume Pricing	20+ In Stock
50.00	0.20	VIS 0° (425-675nm)	#83-106	₹15,037 Volume Pricing	20+ In Stock
5.00	0.20	VIS-NIR (400-1000nm)	#22-036	₹8,362 Volume Pricing	15 In Stock
10.00	0.20	VIS-NIR (400-1000nm)	#22-037	₹8,362 Volume Pricing	9 In Stock
12.50	0.20	VIS-NIR (400-1000nm)	#22-038	₹8,362 Volume Pricing	12 In Stock
20.00	0.20	VIS-NIR (400-1000nm)	#22-039	₹8,362 Volume Pricing	4 In Stock
25.00	0.20	VIS-NIR (400-1000nm)	#22-040	₹9,756 Volume Pricing	10 In Stock
30.00	0.20	VIS-NIR (400-1000nm)	#22-041	₹11,809 Volume Pricing	3 In Stock
40.00	0.20	VIS-NIR (400-1000nm)	#22-042	₹12,396 Volume Pricing	4 In Stock
50.00	0.20	VIS-NIR (400-1000nm)	#22-043	₹15,037 Volume Pricing	Contact Us
5.00	0.20	NIR I (600-1050nm)	#22-044	₹8,362 Volume Pricing	12 In Stock
10.00	0.20	NIR I (600-1050nm)	#22-045	₹8,362 Volume Pricing	2 In Stock
12.50	0.20	NIR I (600-1050nm)	#22-046	₹8,362 Volume Pricing	9 In Stock
20.00	0.20	NIR I (600-1050nm)	#22-047	₹8,362 Volume Pricing	5 In Stock

25.00	0.20	NIR I (600-1050nm)	#22-048	₹9,756 Volume Pricing	8 In Stock
30.00	0.20	NIR I (600-1050nm)	#22-049	₹11,809 Volume Pricing	5 In Stock
40.00	0.20	NIR I (600-1050nm)	#22-050	₹12,396 Volume Pricing	4 In Stock
50.00	0.20	NIR I (600-1050nm)	#22-051	₹15,037 Volume Pricing	10 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com