


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)

TECHSPEC® Zinc Sulfide Multispectral Windows

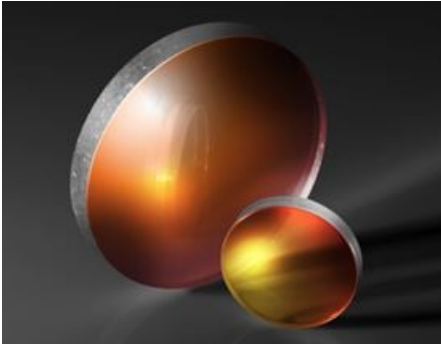


- Multispectral Grade Zinc Sulfide Substrate
- Low Absorption and Low Scatter from 0.4 - 12 μ m
- Available Uncoated or 3 - 12 μ m Broadband AR Coated Option



Common Specifications

Physical & Mechanical Properties			
Bevel:	Protective as needed	Clear Aperture (%):	90.00
Edges:	Fine Ground	Knoop Hardness (kg/mm ²):	210.00
Parallelism (arcmin):	<1	Poisson's Ratio:	0.27
Young's Modulus (GPa):	74.5		
Optical Properties			
Index of Refraction (n _d):	2.371		
Substrate:	Zinc Sulfide Multispectral	Surface Flatness (P-V):	λ/10 @ 10.6μm
Surface Quality:	60-40		
Material Properties			
Coefficient of Thermal Expansion CTE (10 ⁻⁶ /°C):		6.8	
Density (g/cm ³):		4.08	

Technical Information

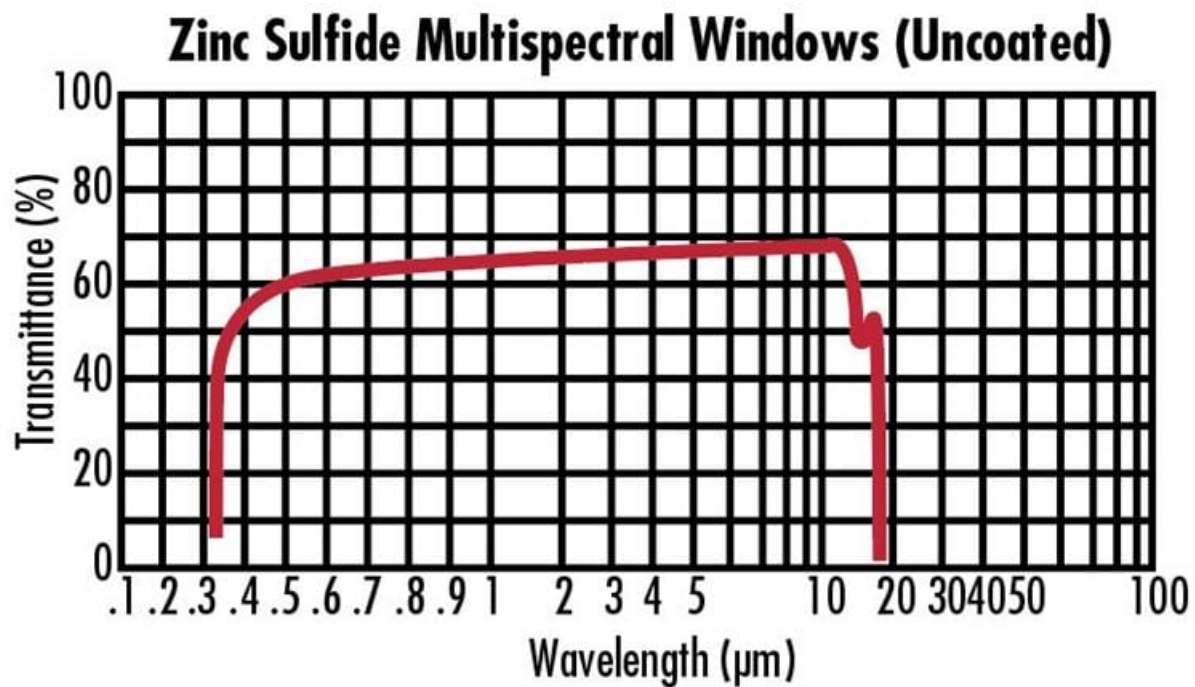

Products

Dia. (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
12.50	2.00	BBAR (3000-12000nm)	#64-144	₹22,078 Volume Pricing	2 In Stock
25.00	3.00	BBAR (3000-12000nm)	#64-145	₹31,320 Volume Pricing	20+ In Stock
40.00	4.00	BBAR (3000-12000nm)	#64-146	₹48,044 Volume Pricing	5 In Stock
50.00	3.00	BBAR (3000-12000nm)	#64-147	₹62,714 Volume Pricing	Contact Us
12.50	2.00	Uncoated	#66-200	₹14,523 Volume Pricing	17 In Stock
25.00	3.00	Uncoated	#66-201	₹21,125 Volume Pricing	Contact Us
25.40	3.00	Uncoated	#19-653	₹21,125 Volume Pricing	Contact Us
40.00	4.00	Uncoated	#66-202	₹36,088 Volume Pricing	20+ In Stock
50.00	3.00	Uncoated	#66-203	₹48,044 Volume Pricing	12 In Stock
50.80	3.00	Uncoated	#19-655	₹48,044 Volume Pricing	10 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com