

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® NIR II Coated Plano-Convex (PCX) Lenses



- AR Coated to Provide <0.7% Reflectance per Surface for 750 - 1550nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [VIS-EXT](#), and [YAG-BBAR](#)

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed
--------	----------------------



Optical Properties

Coating:	NIR II (750-1550nm)
----------	---------------------

Focal Length Tolerance (%)	±1
----------------------------	----

Wavelength Range (nm)	750 - 1550
-----------------------	------------

Technical Information

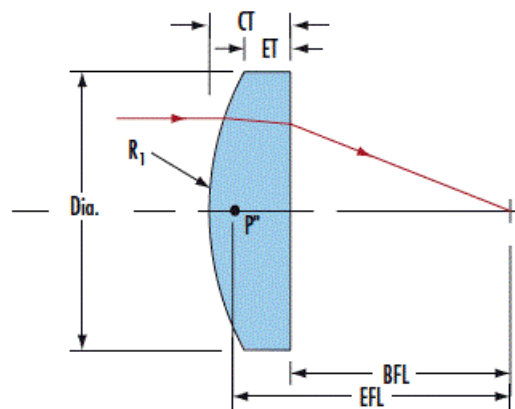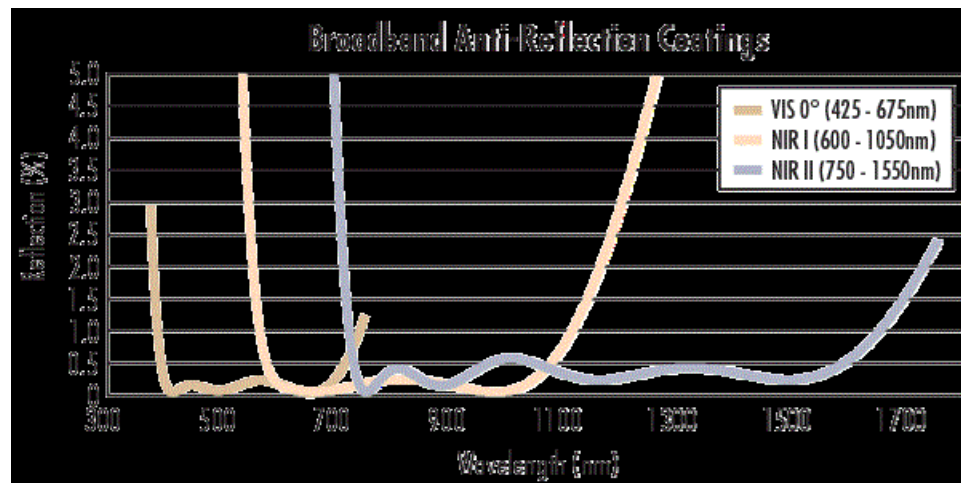

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	NIR II (750-1550nm)	N-LASF9	#67-423	₹6,228 Volume Pricing	Contact Us
1.00	1.00	0.57	NIR II (750-1550nm)	N-LASF9	#67-424	₹6,228 Volume Pricing	2 In Stock
1.00	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-425	₹6,228 Volume Pricing	7 In Stock
1.00	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-426	₹6,228 Volume Pricing	20+ In Stock
1.50	1.00	0.57	NIR II (750-1550nm)	N-LASF9	#67-427	₹6,228 Volume Pricing	20+ In Stock
1.50	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-428	₹6,228 Volume Pricing	9 In Stock
1.50	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-429	₹6,228 Volume Pricing	9 In Stock
2.00	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-430	₹6,150 Volume Pricing	20+ In Stock
2.00	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-431	₹6,150 Volume Pricing	9 In Stock
2.00	3.00	2.57	NIR II (750-1550nm)	N-LASF9	#67-432	₹6,150 Volume Pricing	14 In Stock
2.00	4.00	3.57	NIR II (750-1550nm)	N-LASF9	#67-433	₹6,150 Volume Pricing	12 In Stock
2.00	4.00	3.46	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-256	₹8,096 Volume Pricing	5 In Stock

2.00	6.00	5.45	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-264	₹7,668 Volume Pricing	5 In Stock
2.50	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-434	₹6,150 Volume Pricing	20+ In Stock
2.50	2.50	2.07	NIR II (750-1550nm)	N-LASF9	#67-435	₹6,150 Volume Pricing	7 In Stock
2.50	3.00	2.57	NIR II (750-1550nm)	N-LASF9	#67-436	₹6,150 Volume Pricing	Contact Us
2.50	4.00	3.57	NIR II (750-1550nm)	N-LASF9	#67-437	₹6,150 Volume Pricing	Contact Us
2.50	5.00	4.57	NIR II (750-1550nm)	N-LASF9	#67-438	₹6,150 Volume Pricing	Contact Us
3.00	3.00	1.88	NIR II (750-1550nm)	N-SF11	#67-439	₹5,177 Volume Pricing	13 In Stock
3.00	4.50	3.50	NIR II (750-1550nm)	N-LASF44	#67-440	₹5,177 Volume Pricing	20+ In Stock
3.00	6.00	4.81	NIR II (750-1550nm)	N-BK7	#67-441	₹4,788 Volume Pricing	20+ In Stock
3.00	6.00	5.01	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-272	₹8,096 Volume Pricing	5 In Stock
3.00	7.50	6.51	NIR II (750-1550nm)	N-BK7	#67-442	₹4,788 Volume Pricing	15 In Stock
3.00	9.00	8.01	NIR II (750-1550nm)	N-BK7	#67-443	₹4,788 Volume Pricing	7 In Stock
3.00	9.00	8.11	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-281	₹7,668 Volume Pricing	5 In Stock
3.00	12.00	11.29	NIR II (750-1550nm)	N-BK7	#67-444	₹4,788 Volume Pricing	10 In Stock

3.00	15.00	14.22	NIR II (750-1550nm)	N-BK7	#67-445	₹4,788 Volume Pricing	1 In Stock
4.00	4.00	3.06	NIR II (750-1550nm)	N-LASF44	#67-446	₹4,982 Volume Pricing	10 In Stock
4.00	6.00	4.51	NIR II (750-1550nm)	N-BK7	#67-447	₹4,982 Volume Pricing	20+ In Stock
4.00	8.00	7.17	NIR II (750-1550nm)	N-BAF10	#67-448	₹4,671 Volume Pricing	13 In Stock
4.00	8.00	6.91	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-289	₹9,653 Volume Pricing	5 In Stock
4.00	10.00	8.96	NIR II (750-1550nm)	N-BK7	#67-449	₹4,671 Volume Pricing	16 In Stock
4.00	12.00	11	NIR II (750-1550nm)	N-BK7	#67-450	₹4,671 Volume Pricing	1 In Stock
4.00	12.00	11.04	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-297	₹9,264 Volume Pricing	5 In Stock
4.50	4.50	3.05	NIR II (750-1550nm)	N-LASF44	#67-451	₹4,982 Volume Pricing	17 In Stock
4.50	9.00	7.41	NIR II (750-1550nm)	N-BK7	#67-452	₹4,671 Volume Pricing	2 In Stock
5.00	5.00	3.96	NIR II (750-1550nm)	N-LASF44	#67-453	₹3,756 Volume Pricing	20+ In Stock
5.00	7.50	6.43	NIR II (750-1550nm)	N-SF11	#67-454	₹3,717 Volume Pricing	10 In Stock
5.00	10.00	8.91	NIR II (750-1550nm)	N-BK7	#67-455	₹3,717 Volume Pricing	3 In Stock
5.00	12.00	10.83	NIR II (750-1550nm)	N-BK7	#67-456	₹3,717 Volume Pricing	9 In Stock

5.00	15.00	13.94	NIR II (750-1550nm)	N-BK7	#67-457	₹3,717 Volume Pricing	3 In Stock
5.00	20.00	19.02	NIR II (750-1550nm)	N-BK7	#67-458	₹3,717 Volume Pricing	3 In Stock
5.00	25.00	23.95	NIR II (750-1550nm)	N-BK7	#87-921	₹3,717 Volume Pricing	5 In Stock
5.00	30.00	28.95	NIR II (750-1550nm)	N-BK7	#87-922	₹3,717 Volume Pricing	20+ In Stock
6.00	6.00	4.60	NIR II (750-1550nm)	N-SF11	#67-459	₹3,114 Volume Pricing	7 In Stock
6.00	7.50	6.10	NIR II (750-1550nm)	N-SF11	#67-460	₹3,075 Volume Pricing	20+ In Stock
6.00	9.00	7.95	NIR II (750-1550nm)	N-SF5	#67-461	₹3,075 Volume Pricing	20+ In Stock
6.00	10.00	8.82	NIR II (750-1550nm)	N-BK7	#38-386	₹3,075 Volume Pricing	Contact Us
6.00	12.00	10.94	NIR II (750-1550nm)	N-BK7	#67-462	₹2,997 Volume Pricing	20+ In Stock
6.00	15.00	13.68	NIR II (750-1550nm)	N-BK7	#67-463	₹2,997 Volume Pricing	7 In Stock
6.00	18.00	17.07	NIR II (750-1550nm)	N-BK7	#67-464	₹2,997 Volume Pricing	8 In Stock
6.00	20.00	19.04	NIR II (750-1550nm)	N-BK7	#38-387	₹2,997 Volume Pricing	Contact Us
6.00	21.00	20.06	NIR II (750-1550nm)	N-BK7	#67-465	₹2,997 Volume Pricing	9 In Stock
6.00	24.00	23.01	NIR II (750-1550nm)	N-BK7	#67-466	₹2,997 Volume Pricing	15 In Stock

6.00	25.00	24.04	NIR II (750-1550nm)	N-BK7	#38-388	₹2,997 Volume Pricing	Contact Us
6.00	30.00	29.14	NIR II (750-1550nm)	N-BK7	#67-467	₹2,997 Volume Pricing	20+ In Stock
6.00	36.00	34.95	NIR II (750-1550nm)	N-BK7	#67-468	₹2,997 Volume Pricing	7 In Stock
6.00	48.00	46.95	NIR II (750-1550nm)	N-BK7	#67-469	₹2,997 Volume Pricing	17 In Stock
6.00	60.00	58.95	NIR II (750-1550nm)	N-BK7	#67-470	₹2,997 Volume Pricing	20+ In Stock
6.00	72.00	70.97	NIR II (750-1550nm)	N-BK7	#67-471	₹2,997 Volume Pricing	5 In Stock
7.00	7.00	5.50	NIR II (750-1550nm)	N-SF11	#71-296	₹3,114 Volume Pricing	3 In Stock
7.00	10.00	8.10	NIR II (750-1550nm)	N-BK7	#71-303	₹3,075 Volume Pricing	3 In Stock
7.00	12.00	10.30	NIR II (750-1550nm)	N-BK7	#71-310	₹3,075 Volume Pricing	5 In Stock
8.00	8.00	6.40	NIR II (750-1550nm)	N-SF11	#71-317	₹3,114 Volume Pricing	5 In Stock
8.00	10.00	7.60	NIR II (750-1550nm)	N-BK7	#71-324	₹3,075 Volume Pricing	9 In Stock
8.00	12.00	10.00	NIR II (750-1550nm)	N-BK7	#71-331	₹3,075 Volume Pricing	5 In Stock
9.00	9.00	7.32	NIR II (750-1550nm)	N-SF11	#67-472	₹3,153 Volume Pricing	17 In Stock
9.00	10.00	8.49	NIR II (750-1550nm)	N-SF11	#38-389	₹3,153 Volume Pricing	20+ In Stock

9.00	12.00	10.60	NIR II (750-1550nm)	N-SF11	#67-473	₹3,153 Volume Pricing	20+ In Stock
9.00	13.50	11.94	NIR II (750-1550nm)	N-SF5	#67-474	₹3,153 Volume Pricing	1 In Stock
9.00	15.00	13.02	NIR II (750-1550nm)	N-BK7	#67-475	₹3,153 Volume Pricing	20+ In Stock
9.00	18.00	16.41	NIR II (750-1550nm)	N-BK7	#67-476	₹3,075 Volume Pricing	9 In Stock
9.00	20.00	18.55	NIR II (750-1550nm)	N-BK7	#38-390	₹3,075 Volume Pricing	6 In Stock
9.00	22.00	20.73	NIR II (750-1550nm)	N-BK7	#67-477	₹3,075 Volume Pricing	3 In Stock
9.00	25.00	23.68	NIR II (750-1550nm)	N-BK7	#38-391	₹3,075 Volume Pricing	20+ In Stock
9.00	27.00	25.34	NIR II (750-1550nm)	N-BK7	#67-478	₹3,075 Volume Pricing	20+ In Stock
9.00	36.00	34.48	NIR II (750-1550nm)	N-BK7	#67-479	₹3,075 Volume Pricing	7 In Stock
9.00	45.00	43.98	NIR II (750-1550nm)	N-BK7	#67-480	₹3,075 Volume Pricing	13 In Stock
9.00	54.00	52.69	NIR II (750-1550nm)	N-BK7	#67-481	₹3,075 Volume Pricing	7 In Stock
9.00	72.00	70.68	NIR II (750-1550nm)	N-BK7	#67-482	₹3,075 Volume Pricing	14 In Stock
9.00	90.00	88.68	NIR II (750-1550nm)	N-BK7	#67-483	₹3,075 Volume Pricing	2 In Stock
10.00	10.00	8.18	NIR II (750-1550nm)	N-SF11	#67-484	₹3,153 Volume Pricing	20+ In Stock

10.00	12.50	10.99	NIR II (750-1550nm)	N-SF11	#38-392	₹3,153 Volume Pricing	3 In Stock
10.00	15.00	13.32	NIR II (750-1550nm)	N-SF11	#67-485	₹3,153 Volume Pricing	4 In Stock
10.00	17.50	15.66	NIR II (750-1550nm)	N-BK7	#38-393	₹3,075 Volume Pricing	5 In Stock
10.00	20.00	18.03	NIR II (750-1550nm)	N-BK7	#67-486	₹3,075 Volume Pricing	20+ In Stock
10.00	25.00	23.02	NIR II (750-1550nm)	N-BK7	#67-487	₹3,075 Volume Pricing	Contact Us
10.00	30.00	28.01	NIR II (750-1550nm)	N-BK7	#67-488	₹3,075 Volume Pricing	Contact Us
10.00	40.00	38.02	NIR II (750-1550nm)	N-BK7	#67-489	₹3,075 Volume Pricing	7 In Stock
10.00	50.00	48.02	NIR II (750-1550nm)	N-BK7	#67-490	₹3,075 Volume Pricing	20+ In Stock
10.00	75.00	73.02	NIR II (750-1550nm)	N-BK7	#67-491	₹3,075 Volume Pricing	Contact Us
10.00	100.00	98.02	NIR II (750-1550nm)	N-BK7	#67-492	₹3,075 Volume Pricing	15 In Stock
12.00	12.00	9.76	NIR II (750-1550nm)	N-SF11	#67-493	₹3,425 Volume Pricing	20+ In Stock
12.00	15.00	12.03	NIR II (750-1550nm)	N-BK7	#67-494	₹3,425 Volume Pricing	14 In Stock
12.00	18.00	16.22	NIR II (750-1550nm)	N-SF5	#67-495	₹3,425 Volume Pricing	1 In Stock
12.00	20.00	17.69	NIR II (750-1550nm)	N-BK7	#67-496	₹3,425 Volume Pricing	5 In Stock

12.00	24.00	22.15	NIR II (750-1550nm)	N-BK7	#67-497	₹3,348 Volume Pricing	1 In Stock
12.00	25.00	23.22	NIR II (750-1550nm)	N-BK7	#38-394	₹3,348 Volume Pricing	7 In Stock
12.00	30.00	28.02	NIR II (750-1550nm)	N-BK7	#67-498	₹3,348 Volume Pricing	20+ In Stock
12.00	36.00	34.02	NIR II (750-1550nm)	N-BK7	#33-357	₹3,348 Volume Pricing	20+ In Stock
12.00	42.00	40.22	NIR II (750-1550nm)	N-BK7	#67-500	₹3,348 Volume Pricing	20+ In Stock
12.00	48.00	46.36	NIR II (750-1550nm)	N-BK7	#67-501	₹3,348 Volume Pricing	20+ In Stock
12.00	50.00	48.75	NIR II (750-1550nm)	N-BK7	#38-395	₹3,348 Volume Pricing	7 In Stock
12.00	54.00	52.02	NIR II (750-1550nm)	N-BK7	#67-502	₹3,348 Volume Pricing	Contact Us
12.00	60.00	58.37	NIR II (750-1550nm)	N-BK7	#67-503	₹3,348 Volume Pricing	20+ In Stock
12.00	72.00	70.42	NIR II (750-1550nm)	N-BK7	#67-504	₹3,348 Volume Pricing	6 In Stock
12.00	84.00	82.39	NIR II (750-1550nm)	N-BK7	#67-505	₹3,348 Volume Pricing	14 In Stock
12.00	100.00	98.35	NIR II (750-1550nm)	N-BK7	#67-506	₹3,348 Volume Pricing	14 In Stock
12.50	12.50	10.40	NIR II (750-1550nm)	N-SF11	#38-397	₹3,348 Volume Pricing	15 In Stock
12.50	15.00	13.26	NIR II (750-1550nm)	N-SF11	#38-398	₹3,348 Volume Pricing	4 In Stock

12.50	17.50	15.00	NIR II (750-1550nm)	N-BK7	#38-399	₹3,348 Volume Pricing	1 In Stock
12.50	20.00	17.69	NIR II (750-1550nm)	N-BK7	#38-400	₹3,348 Volume Pricing	6 In Stock
12.50	25.00	22.96	NIR II (750-1550nm)	N-BK7	#38-401	₹3,270 Volume Pricing	1 In Stock
12.50	30.00	28.22	NIR II (750-1550nm)	N-BK7	#38-402	₹3,270 Volume Pricing	2 In Stock
12.50	35.00	33.42	NIR II (750-1550nm)	N-BK7	#38-403	₹3,270 Volume Pricing	3 In Stock
12.50	40.00	38.55	NIR II (750-1550nm)	N-BK7	#38-404	₹3,270 Volume Pricing	20+ In Stock
12.50	45.00	43.68	NIR II (750-1550nm)	N-BK7	#38-405	₹3,270 Volume Pricing	6 In Stock
12.50	50.00	48.68	NIR II (750-1550nm)	N-BK7	#38-406	₹3,270 Volume Pricing	5 In Stock
12.50	75.00	73.88	NIR II (750-1550nm)	N-BK7	#38-407	₹3,270 Volume Pricing	14 In Stock
12.50	100.00	98.95	NIR II (750-1550nm)	N-BK7	#38-408	₹3,270 Volume Pricing	8 In Stock
12.70	12.70	10.46	NIR II (750-1550nm)	N-SF11	#67-507	₹3,348 Volume Pricing	20+ In Stock
12.70	15.00	11.53	NIR II (750-1550nm)	N-BK7	#67-508	₹3,348 Volume Pricing	Contact Us
12.70	19.10	16.46	NIR II (750-1550nm)	N-BK7	#67-509	₹3,348 Volume Pricing	14 In Stock
12.70	20.00	17.49	NIR II (750-1550nm)	N-BK7	#38-409	₹3,348 Volume Pricing	Contact Us

12.70	25.40	23.43	NIR II (750-1550nm)	N-BK7	#67-510	₹3,270 Volume Pricing	20+ In Stock
12.70	30.00	28.22	NIR II (750-1550nm)	N-BK7	#38-410	₹3,270 Volume Pricing	7 In Stock
12.70	31.80	29.81	NIR II (750-1550nm)	N-BK7	#67-511	₹3,270 Volume Pricing	7 In Stock
12.70	38.10	36.12	NIR II (750-1550nm)	N-BK7	#67-512	₹3,270 Volume Pricing	5 In Stock
12.70	40.00	38.48	NIR II (750-1550nm)	N-BK7	#38-411	₹3,270 Volume Pricing	1 In Stock
12.70	44.50	42.69	NIR II (750-1550nm)	N-BK7	#67-513	₹3,270 Volume Pricing	1 In Stock
12.70	50.80	49.15	NIR II (750-1550nm)	N-BK7	#67-514	₹3,270 Volume Pricing	Contact Us
12.70	100.00	98.88	NIR II (750-1550nm)	N-BK7	#38-412	₹3,270 Volume Pricing	9 In Stock
15.00	15.00	11.71	NIR II (750-1550nm)	N-SF5	#67-515	₹3,425 Volume Pricing	20+ In Stock
15.00	18.00	15.61	NIR II (750-1550nm)	N-SF5	#67-516	₹3,425 Volume Pricing	Contact Us
15.00	20.00	17.74	NIR II (750-1550nm)	N-SF5	#67-517	₹3,425 Volume Pricing	5 In Stock
15.00	22.50	20.50	NIR II (750-1550nm)	N-SF5	#67-518	₹3,425 Volume Pricing	14 In Stock
15.00	25.00	22.50	NIR II (750-1550nm)	N-BK7	#38-413	₹3,348 Volume Pricing	1 In Stock
15.00	30.00	27.90	NIR II (750-1550nm)	N-BK7	#67-519	₹3,348 Volume Pricing	7 In Stock

15.00	40.00	38.02	NIR II (750-1550nm)	N-BK7	#67-520	₹3,348 Volume Pricing	20+ In Stock
15.00	45.00	43.35	NIR II (750-1550nm)	N-BK7	#67-521	₹3,348 Volume Pricing	17 In Stock
15.00	50.00	48.35	NIR II (750-1550nm)	N-BK7	#38-414	₹3,348 Volume Pricing	2 In Stock
15.00	60.00	58.65	NIR II (750-1550nm)	N-BK7	#67-522	₹3,348 Volume Pricing	5 In Stock
15.00	75.00	73.79	NIR II (750-1550nm)	N-BK7	#67-523	₹3,348 Volume Pricing	10 In Stock
15.00	100.00	98.02	NIR II (750-1550nm)	N-BK7	#67-524	₹3,348 Volume Pricing	2 In Stock
15.00	200.00	197.89	NIR II (750-1550nm)	N-BK7	#14-378	₹3,348 Volume Pricing	5 In Stock
15.00	250.00	248.02	NIR II (750-1550nm)	N-BK7	#14-386	₹3,348 Volume Pricing	Contact Us
18.00	18.00	15.20	NIR II (750-1550nm)	N-SF11	#67-525	₹3,464 Volume Pricing	12 In Stock
18.00	20.00	17.59	NIR II (750-1550nm)	N-SF11	#38-415	₹3,425 Volume Pricing	2 In Stock
18.00	22.50	20.26	NIR II (750-1550nm)	N-SF11	#67-526	₹3,425 Volume Pricing	4 In Stock
18.00	25.00	21.51	NIR II (750-1550nm)	N-BK7	#38-416	₹3,425 Volume Pricing	1 In Stock
18.00	27.00	24.73	NIR II (750-1550nm)	N-SF5	#67-527	₹3,425 Volume Pricing	20+ In Stock
18.00	30.00	27.10	NIR II (750-1550nm)	N-BK7	#38-419	₹3,309 Volume Pricing	5 In Stock

18.00	36.00	33.65	NIR II (750-1550nm)	N-BK7	#67-528	₹3,309 Volume Pricing	Contact Us
18.00	50.00	48.09	NIR II (750-1550nm)	N-BK7	#38-420	₹3,309 Volume Pricing	3 In Stock
18.00	54.00	52.02	NIR II (750-1550nm)	N-BK7	#67-529	₹3,309 Volume Pricing	20+ In Stock
18.00	72.00	70.05	NIR II (750-1550nm)	N-BK7	#67-530	₹3,309 Volume Pricing	20+ In Stock
20.00	20.00	17.42	NIR II (750-1550nm)	N-SF11	#67-531	₹3,503 Volume Pricing	Contact Us
20.00	25.00	22.76	NIR II (750-1550nm)	N-SF11	#67-532	₹3,464 Volume Pricing	14 In Stock
20.00	30.00	27.30	NIR II (750-1550nm)	N-BAF10	#67-533	₹3,464 Volume Pricing	6 In Stock
20.00	35.00	32.04	NIR II (750-1550nm)	N-BK7	#67-534	₹3,464 Volume Pricing	Contact Us
20.00	40.00	36.77	NIR II (750-1550nm)	N-BK7	#67-535	₹3,348 Volume Pricing	17 In Stock
20.00	50.00	47.87	NIR II (750-1550nm)	N-BK7	#67-536	₹3,348 Volume Pricing	20+ In Stock
20.00	60.00	57.03	NIR II (750-1550nm)	N-BK7	#67-537	₹3,348 Volume Pricing	2 In Stock
20.00	70.00	68.03	NIR II (750-1550nm)	N-BK7	#67-538	₹3,348 Volume Pricing	2 In Stock
20.00	80.00	78.45	NIR II (750-1550nm)	N-BK7	#67-539	₹3,348 Volume Pricing	10 In Stock
20.00	100.00	97.13	NIR II (750-1550nm)	N-BK7	#67-540	₹3,348 Volume Pricing	9 In Stock

20.00	150.00	148.02	NIR II (750-1550nm)	N-BK7	#67-541	₹3,348 Volume Pricing	4 In Stock
25.00	25.00	20.22	NIR II (750-1550nm)	N-SF5	#67-542	₹3,503 Volume Pricing	20+ In Stock
25.00	30.00	24.69	NIR II (750-1550nm)	N-BK7	#67-543	₹3,503 Volume Pricing	20+ In Stock
25.00	35.00	30.42	NIR II (750-1550nm)	N-BK7	#67-544	₹3,503 Volume Pricing	13 In Stock
25.00	40.00	36.31	NIR II (750-1550nm)	N-BK7	#67-545	₹3,503 Volume Pricing	20+ In Stock
25.00	50.00	46.75	NIR II (750-1550nm)	N-BK7	#67-546	₹3,348 Volume Pricing	20+ In Stock
25.00	60.00	56.90	NIR II (750-1550nm)	N-BK7	#67-547	₹3,348 Volume Pricing	20+ In Stock
25.00	75.00	72.00	NIR II (750-1550nm)	N-BK7	#67-548	₹3,348 Volume Pricing	10 In Stock
25.00	85.00	82.17	NIR II (750-1550nm)	N-BK7	#67-549	₹3,348 Volume Pricing	7 In Stock
25.00	100.00	97.17	NIR II (750-1550nm)	N-BK7	#67-550	₹3,348 Volume Pricing	20+ In Stock
25.00	125.00	122.70	NIR II (750-1550nm)	N-BK7	#67-551	₹3,348 Volume Pricing	4 In Stock
25.00	150.00	147.81	NIR II (750-1550nm)	N-BK7	#67-552	₹3,348 Volume Pricing	20+ In Stock
25.00	175.00	172.85	NIR II (750-1550nm)	N-BK7	#67-553	₹3,348 Volume Pricing	6 In Stock
25.00	200.00	197.89	NIR II (750-1550nm)	N-BK7	#33-363	₹3,348 Volume Pricing	10 In Stock

25.00	250.00	248.02	NIR II (750-1550nm)	N-BK7	#67-555	₹3,348 Volume Pricing	4 In Stock
25.00	300.00	298.02	NIR II (750-1550nm)	N-BK7	#67-556	₹3,348 Volume Pricing	Contact Us
25.00	400.00	397.89	NIR II (750-1550nm)	N-BK7	#33-369	₹3,348 Volume Pricing	8 In Stock
25.00	500.00	497.89	NIR II (750-1550nm)	N-BK7	#67-558	₹3,348 Volume Pricing	4 In Stock
25.00	750.00	747.89	NIR II (750-1550nm)	N-BK7	#67-559	₹3,348 Volume Pricing	12 In Stock
25.40	25.40	21.48	NIR II (750-1550nm)	N-SF11	#67-560	₹3,503 Volume Pricing	5 In Stock
25.40	35.00	30.46	NIR II (750-1550nm)	N-BK7	#38-421	₹3,503 Volume Pricing	2 In Stock
25.40	38.10	33.48	NIR II (750-1550nm)	N-BK7	#67-561	₹3,503 Volume Pricing	Contact Us
25.40	40.00	36.11	NIR II (750-1550nm)	N-BK7	#38-422	₹3,503 Volume Pricing	15 In Stock
25.40	50.80	47.5	NIR II (750-1550nm)	N-BK7	#67-562	₹3,348 Volume Pricing	7 In Stock
25.40	63.50	60.37	NIR II (750-1550nm)	N-BK7	#67-563	₹3,348 Volume Pricing	5 In Stock
25.40	75.00	72.69	NIR II (750-1550nm)	N-BK7	#38-424	₹3,348 Volume Pricing	6 In Stock
25.40	76.20	73.56	NIR II (750-1550nm)	N-BK7	#67-564	₹3,348 Volume Pricing	7 In Stock
25.40	88.90	86.26	NIR II (750-1550nm)	N-BK7	#67-565	₹3,348 Volume Pricing	5 In Stock

25.40	100.00	98.02	NIR II (750-1550nm)	N-BK7	#38-425	₹3,348 Volume Pricing	5 In Stock
25.40	101.60	98.97	NIR II (750-1550nm)	N-BK7	#67-566	₹3,348 Volume Pricing	8 In Stock
25.40	125.00	123.02	NIR II (750-1550nm)	N-BK7	#38-431	₹3,348 Volume Pricing	Contact Us
25.40	150.00	148.02	NIR II (750-1550nm)	N-BK7	#38-432	₹3,348 Volume Pricing	5 In Stock
30.00	30.00	26.13	NIR II (750-1550nm)	N-SF11	#67-567	₹4,321 Volume Pricing	20+ In Stock
30.00	40.00	37.20	NIR II (750-1550nm)	N-SF11	#67-568	₹4,165 Volume Pricing	3 In Stock
30.00	50.00	46.17	NIR II (750-1550nm)	N-SF5	#67-569	₹4,165 Volume Pricing	13 In Stock
30.00	60.00	56.03	NIR II (750-1550nm)	N-BK7	#67-570	₹4,048 Volume Pricing	7 In Stock
30.00	75.00	70.95	NIR II (750-1550nm)	N-BK7	#67-571	₹4,048 Volume Pricing	6 In Stock
30.00	100.00	96.01	NIR II (750-1550nm)	N-BK7	#67-572	₹4,048 Volume Pricing	Contact Us
30.00	120.00	116.04	NIR II (750-1550nm)	N-BK7	#67-573	₹4,048 Volume Pricing	20+ In Stock
35.00	35.00	30.52	NIR II (750-1550nm)	N-SF11	#38-433	₹4,437 Volume Pricing	11 In Stock
35.00	50.00	44.40	NIR II (750-1550nm)	N-BK7	#38-434	₹4,321 Volume Pricing	3 In Stock
35.00	70.00	66.04	NIR II (750-1550nm)	N-BK7	#38-435	₹4,321 Volume Pricing	1 In Stock

35.00	100.00	97.03	NIR II (750-1550nm)	N-BK7	#38-436	₹4,321 Volume Pricing	12 In Stock
40.00	40.00	35.13	NIR II (750-1550nm)	N-SF11	#67-574	₹4,827 Volume Pricing	9 In Stock
40.00	60.00	53.9	NIR II (750-1550nm)	N-BK7	#67-575	₹4,827 Volume Pricing	1 In Stock
40.00	80.00	74.73	NIR II (750-1550nm)	N-BK7	#33-387	₹4,749 Volume Pricing	5 In Stock
40.00	100.00	95.39	NIR II (750-1550nm)	N-BK7	#33-375	₹4,749 Volume Pricing	5 In Stock
40.00	200.00	196.7	NIR II (750-1550nm)	N-BK7	#33-381	₹4,749 Volume Pricing	9 In Stock
40.00	300.00	296.7	NIR II (750-1550nm)	N-BK7	#67-579	₹4,749 Volume Pricing	Contact Us
40.00	400.00	396.7	NIR II (750-1550nm)	N-BK7	#67-580	₹4,749 Volume Pricing	Contact Us
50.00	50.00	43.28	NIR II (750-1550nm)	N-SF11	#67-581	₹5,216 Volume Pricing	3 In Stock
50.00	75.00	67.75	NIR II (750-1550nm)	N-BK7	#67-582	₹5,060 Volume Pricing	20+ In Stock
50.00	100.00	93.41	NIR II (750-1550nm)	N-BK7	#67-583	₹4,866 Volume Pricing	2 In Stock
50.00	125.00	117.479	NIR II (750-1550nm)	N-BK7	#67-584	₹4,866 Volume Pricing	4 In Stock
50.00	150.00	144.07	NIR II (750-1550nm)	N-BK7	#67-585	₹4,866 Volume Pricing	16 In Stock
50.00	175.00	169.05	NIR II (750-1550nm)	N-BK7	#67-586	₹4,866 Volume Pricing	5 In Stock

50.00	200.00	196.66	NIR II (750-1550nm)	N-BK7	#67-587	₹4,866 Volume Pricing	2 In Stock
50.00	250.00	246.74	NIR II (750-1550nm)	N-BK7	#67-588	₹4,866 Volume Pricing	5 In Stock
50.00	500.00	496.70	NIR II (750-1550nm)	N-BK7	#67-589	₹4,866 Volume Pricing	1 In Stock
50.80	50.81	44.08	NIR II (750-1550nm)	N-SF11	#71-338	₹5,216 Volume Pricing	3 In Stock
50.80	76.20	68.95	NIR II (750-1550nm)	N-BK7	#71-345	₹5,060 Volume Pricing	2 In Stock
75.00	75.00	53.49	NIR II (750-1550nm)	N-BK7	#86-921	₹10,121 Volume Pricing	3 In Stock
75.00	100.00	87.57	NIR II (750-1550nm)	N-BK7	#71-858	₹9,965 Volume Pricing	4 In Stock
75.00	100.00	85.61	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-305	₹50,992 Volume Pricing	2 In Stock
75.00	125.00	112.66	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-313	₹49,435 Volume Pricing	1 In Stock
75.00	125.00	115.99	NIR II (750-1550nm)	N-BK7	#71-859	₹9,965 Volume Pricing	5 In Stock
75.00	150.00	142.45	NIR II (750-1550nm)	N-BK7	#86-922	₹9,965 Volume Pricing	4 In Stock
75.00	150.00	136.31	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-321	₹47,878 Volume Pricing	1 In Stock
75.00	175.00	168.68	NIR II (750-1550nm)	N-BK7	#71-860	₹9,965 Volume Pricing	3 In Stock
75.00	200.00	194.24	NIR II (750-1550nm)	N-BK7	#86-923	₹9,965 Volume Pricing	4 In Stock

75.00	200.00	187.18	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-329	₹46,321 Volume Pricing	1 In Stock
75.00	250.00	244.73	NIR II (750-1550nm)	N-BK7	#86-924	₹9,965 Volume Pricing	3 In Stock
75.00	300.00	294.4	NIR II (750-1550nm)	N-BK7	#71-861	₹9,965 Volume Pricing	11 In Stock
75.00	400.00	394.4	NIR II (750-1550nm)	N-BK7	#71-862	₹9,965 Volume Pricing	5 In Stock
75.00	500.00	494.73	NIR II (750-1550nm)	N-BK7	#86-925	₹9,965 Volume Pricing	5 In Stock
75.00	750.00	745.35	NIR II (750-1550nm)	N-BK7	#71-863	₹9,965 Volume Pricing	6 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com