


[All Products](#) / [Testing and Detection](#) / [Detectors](#)

DUV Photodiodes

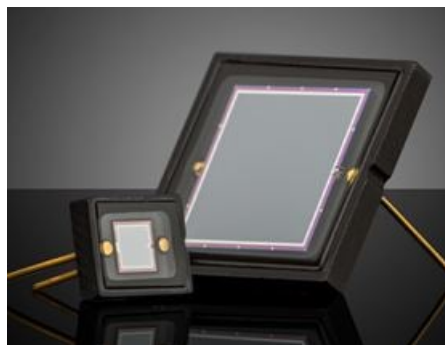

- Excellent UV Sensitivity
- High Shunt Resistance
- Low Capacitance

Common Specifications

Electrical

Responsivity @ 633nm (AW):	0.34	Responsivity @ 200nm (AW):	0.12
Maximum Reverse Voltage (V):	5.00		

Environmental & Durability Factors

Operating Temperature (°C):	-20 to +60
-----------------------------	------------

Technical Information

Products

Active Area (mm ²)	Size of Active Area (mm)	Connector	Stock Number	Price	Buy
5.7	2.4 x 2.4	TO-5	#84-981	₹7,920 Volume Pricing	Contact Us
13.0	3.6 x 3.6	TO-5	#84-983	₹8,865 Volume Pricing	Contact Us
34.0	5.8 x 5.8	TO-8	#84-984	₹10,260 Volume Pricing	2 In Stock
5.7	2.4 x 2.4	Ceramic	#84-982	₹8,865 Volume Pricing	1 In Stock
34.0	5.8 x 5.8	Ceramic	#84-985	₹11,250 Volume Pricing	2 In Stock
100.0	10.0 x 10.0	Ceramic	#84-986	₹19,620 Volume Pricing	3 In Stock
5.7	2.4 x 2.4	TO-5	#84-596	₹9,360 Volume Pricing	4 In Stock
34.0	5.8 x 5.8	TO-8	#84-599	₹11,340 Volume Pricing	5 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com