

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Broadband Dielectric Mirrors](#)

TECHSPEC® Broadband Dielectric Coated Right Angle Mirrors



- Greater Than 98% Reflection Over Broad Wavelength Ranges
- High Reflectivity for all Polarization States
- Reflect Light at 90°
- [Standard Metal Coated Right Angle Mirrors](#) Also Available

Common Specifications

Physical & Mechanical Properties

Dimensional Tolerance (mm):	±0.1	Clear Aperture (%):	90
Optical Properties			
Substrate:	N-BK7	Surface Quality:	40-20
Coating Type:	Dielectric	Angle Tolerance (arcmin):	±2
Power (fringes) @ 632.8nm:	1.25	Irregularity (fringes) @ 632.8nm:	0.50

Technical Information

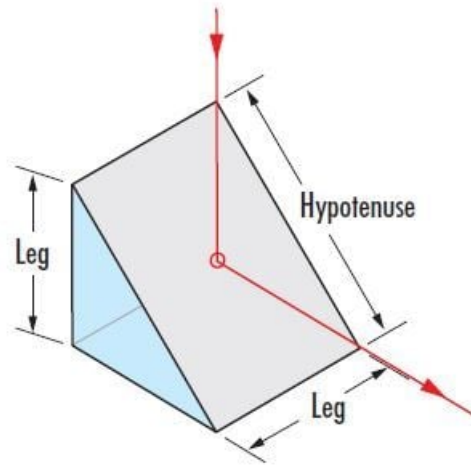


Image above shows light reflecting off the coated hypotenuse.

Products

Wavelength Range (nm)	Length of Legs (mm)	Length of Hypotenuse (mm)	Stock Number	Price	Buy
320 - 450	5.00	7.10	#15-593	₹11,210 Volume Pricing	13 In Stock
320 - 450	10.00	14.10	#15-594	₹12,145 Volume Pricing	2 In Stock
320 - 450	12.50	17.70	#15-595	₹12,534 Volume Pricing	2 In Stock
320 - 450	15.00	21.20	#15-596	₹14,013 Volume Pricing	9 In Stock
320 - 450	20.00	28.30	#15-597	₹15,648 Volume Pricing	Contact Us
320 - 450	25.00	35.40	#15-598	₹18,606 Volume Pricing	9 In Stock
320 - 450	30.00	42.40	#15-599	₹23,744 Volume Pricing	3 In Stock
320 - 450	35.00	49.50	#15-600	₹25,535 Volume Pricing	2 In Stock
320 - 450	40.00	56.60	#15-601	₹28,960 Volume Pricing	1 In Stock
320 - 450	50.00	70.70	#15-602	₹33,008 Volume Pricing	3 In Stock
400 - 750	5.00	7.10	#87-386	₹9,186 Volume Pricing	14 In Stock
400 - 750	10.00	14.10	#87-387	₹10,121 Volume Pricing	20+ In Stock
400 - 750	12.50	17.70	#87-388	₹10,510 Volume Pricing	5 In Stock
400 - 750	15.00	21.20	#87-389	₹11,600 Volume Pricing	14 In Stock
400 - 750	20.00	28.30	#87-390	₹12,923 Volume Pricing	Contact Us
400 - 750	25.00	35.40	#87-391	₹15,804 Volume Pricing	20+ In Stock
400 - 750	30.00	42.40	#87-392	₹20,241 Volume Pricing	20+ In Stock

400 - 750	35.00	49.50	#87-393	₹22,109 Volume Pricing	20+ In Stock
400 - 750	40.00	56.60	#87-394	₹24,678 Volume Pricing	1 In Stock
400 - 750	50.00	70.70	#87-395	₹28,337 Volume Pricing	Contact Us
750 - 1100	5.00	7.10	#87-396	₹9,186 Volume Pricing	12 In Stock
750 - 1100	10.00	14.10	#87-397	₹10,121 Volume Pricing	5 In Stock
750 - 1100	12.50	17.70	#87-398	₹10,510 Volume Pricing	17 In Stock
750 - 1100	15.00	21.20	#87-399	₹11,600 Volume Pricing	9 In Stock
750 - 1100	20.00	28.30	#87-400	₹12,923 Volume Pricing	20+ In Stock
750 - 1100	25.00	35.40	#87-401	₹15,804 Volume Pricing	5 In Stock
750 - 1100	30.00	42.40	#87-402	₹20,241 Volume Pricing	5 In Stock
750 - 1100	35.00	49.50	#87-403	₹22,109 Volume Pricing	7 In Stock
750 - 1100	40.00	56.60	#87-404	₹24,678 Volume Pricing	9 In Stock
750 - 1100	50.00	70.70	#87-405	₹28,337 Volume Pricing	2 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com