

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Achromatic Lenses](#)

## TECHSPEC® C-Mount Achromatic Pairs



- C-Mount Designs for Easy Integration into Imaging Applications
- Feature Integrated Iris for Increased Control of Light Throughput
- Ideal for Relay or Projection Applications

### Common Specifications


#### Physical & Mechanical Properties

|                      |          |                        |       |
|----------------------|----------|------------------------|-------|
| Aperture (mm):       | 0.8 - 20 | Housing Diameter (mm): | 38.00 |
| Housing Length (mm): | 45.9     |                        |       |

#### Optical Properties

|                        |                    |                        |                                    |
|------------------------|--------------------|------------------------|------------------------------------|
| Surface Quality:       | 40-20              |                        |                                    |
| Coating:               | VIS 0° (425-675nm) | Coating Specification: | $R_{avg} \leq 0.4\% @ 425 - 675nm$ |
| Wavelength Range (nm): | 425 - 675          |                        |                                    |

## Technical Information

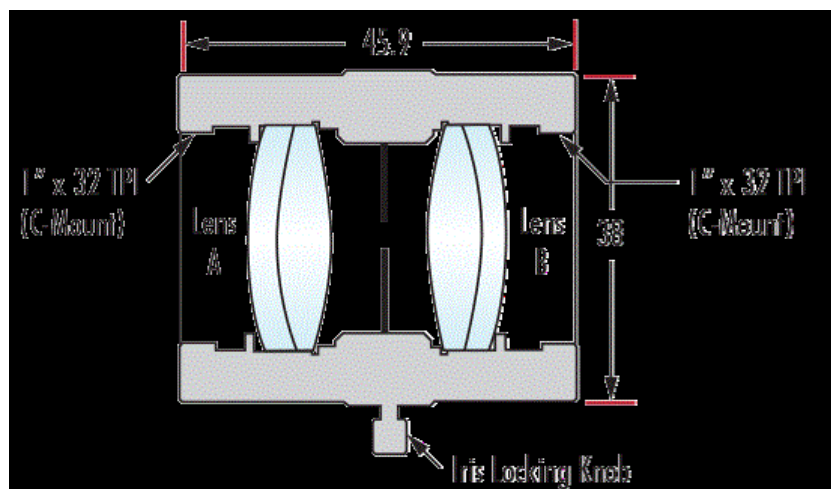

## Products

| Coating               | EFL<br>A<br>(mm) | EFL<br>B<br>(mm) | Housing<br>Diameter<br>(mm) | Magnification | Object<br>Distance<br>(mm) | Stock<br>Number         | Price                                     | Buy         |
|-----------------------|------------------|------------------|-----------------------------|---------------|----------------------------|-------------------------|-------------------------------------------|-------------|
| VIS 0°<br>(425-675nm) | 30.0             | 30.0             | 38.00                       | 1:1           | 15.00                      | <a href="#">#87-185</a> | ₹29,972<br><a href="#">Volume Pricing</a> | Contact Us  |
| VIS 0°<br>(425-675nm) | 30.0             | 60.0             | 38.00                       | 1:2           | 15.00                      | <a href="#">#87-186</a> | ₹29,972<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| VIS 0°<br>(425-675nm) | 30.0             | 100.0            | 38.00                       | 1:3.33        | 15.00                      | <a href="#">#87-187</a> | ₹29,972<br><a href="#">Volume Pricing</a> | 16 In Stock |
| VIS 0°<br>(425-675nm) | 50.0             | 50.0             | 38.00                       | 1:1           | 35.00                      | <a href="#">#87-188</a> | ₹29,972<br><a href="#">Volume Pricing</a> | Contact Us  |
| VIS 0°<br>(425-675nm) | 50.0             | 100.0            | 38.00                       | 1:2           | 35.00                      | <a href="#">#87-189</a> | ₹29,972<br><a href="#">Volume Pricing</a> | Contact Us  |
| VIS 0°<br>(425-675nm) | 75.0             | 75.0             | 38.00                       | 1:1           | 60.00                      | <a href="#">#87-190</a> | ₹29,972<br><a href="#">Volume Pricing</a> | Contact Us  |
| VIS 0°<br>(425-675nm) | 75.0             | 150.0            | 38.00                       | 1:2           | 60.00                      | <a href="#">#87-191</a> | ₹29,972<br><a href="#">Volume Pricing</a> | Contact Us  |
| VIS 0°<br>(425-675nm) | 100.0            | 100.0            | 38.00                       | 1:1           | 85.00                      | <a href="#">#87-192</a> | ₹29,972<br><a href="#">Volume Pricing</a> | 1 In Stock  |



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

[www.edmundoptics.com](http://www.edmundoptics.com)