


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Cylinder Lenses](#) / [Acyylinder Lenses](#)

TECHSPEC® Acylinder Lenses

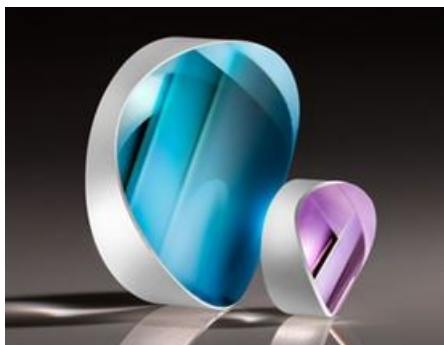

- Diffraction Limited Design
- Ideal for Creating Thin Line Profiles of Monochromatic Light Sources
- Focus Light in Single Dimension

Common Specifications

Physical & Mechanical Properties

Center Thickness
 Tolerance (mm): ± 0.1

Clear Aperture (%): 90.00

Optical Properties


Substrate: [N-SF5](#)

Focal Length
 Specification
 Wavelength (nm): 587.6

Surface Accuracy, RMS
 (μm): 1.0

Surface Quality: 60-40

Technical Information

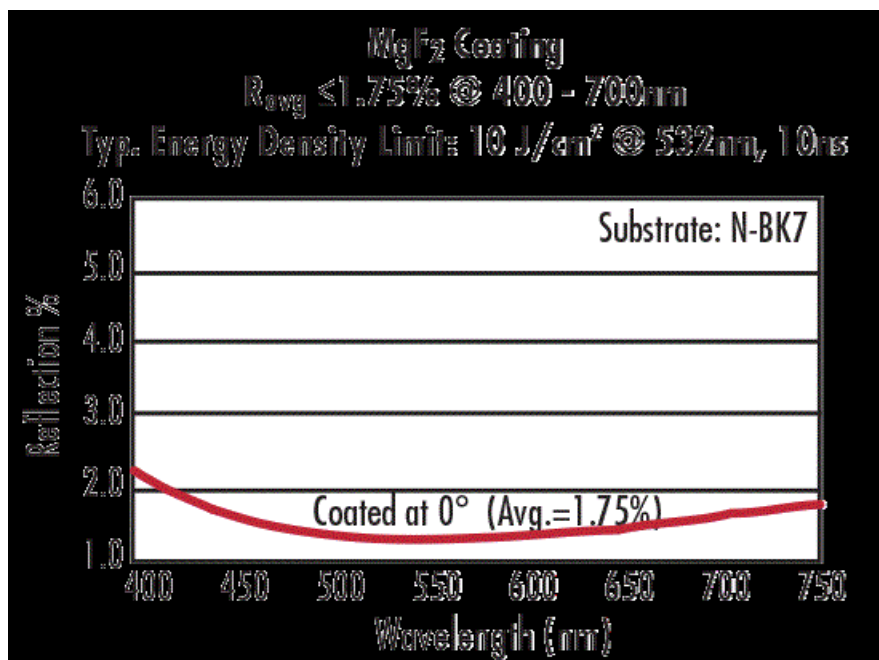

Products

Dia. (mm)	EFL (mm)	Substrate	Coating	Stock Number	Price	Buy
12.50	10.00	N-SF5	Uncoated	#86-030	₹48,656 Volume Pricing	20+ In Stock
12.50	10.00	N-SF5	MgF ₂ (400-700nm)	#86-034	₹50,603 Volume Pricing	3 In Stock
12.50	12.50	N-SF5	Uncoated	#86-031	₹48,656 Volume Pricing	17 In Stock
12.50	12.50	N-SF5	MgF ₂ (400-700nm)	#86-035	₹50,603 Volume Pricing	3 In Stock
25.00	20.00	N-SF5	Uncoated	#86-032	₹66,951 Volume Pricing	Contact Us
25.00	20.00	N-SF5	MgF ₂ (400-700nm)	#86-036	₹69,287 Volume Pricing	Contact Us
25.00	25.00	N-SF5	Uncoated	#86-033	₹66,951 Volume Pricing	10 In Stock
25.00	25.00	N-SF5	MgF ₂ (400-700nm)	#86-037	₹69,287 Volume Pricing	4 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038
Phone: 1-800-363-1992 :
www.edmundoptics.com