

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Machine Vision Filters](#) / [Color Filters](#)

TECHSPEC® High Performance Mounted Machine Vision Filters



- Optimized for Use with Popular LEDs
- Multiple Mounting Sizes and Threads Available to Ease System Compatibility
- Extremely High and Flat Transmission Profiles Provide Even Illumination

Common Specifications

Physical & Mechanical Properties

Construction:	Mounted in Black Anodized Ring	Substrate Thickness (mm):	1.75 ±0.10
Physical Durability:	Adhesion per MIL-PRF-13830B, Section C.4.5.12 Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11 Cleaning per MIL-C-48497A Section 4.5.4.2		


Optical Properties



Coating:	Hard Coated
Optical Density OD (Average):	≥3.0

Environmental & Durability Factors

Environmental Durability:	Humidity per MIL-STD-810H, Section 507.6 Temperature per MIL-STD-810H, Section 501.7 and 502.7
----------------------------------	---

Technical Information

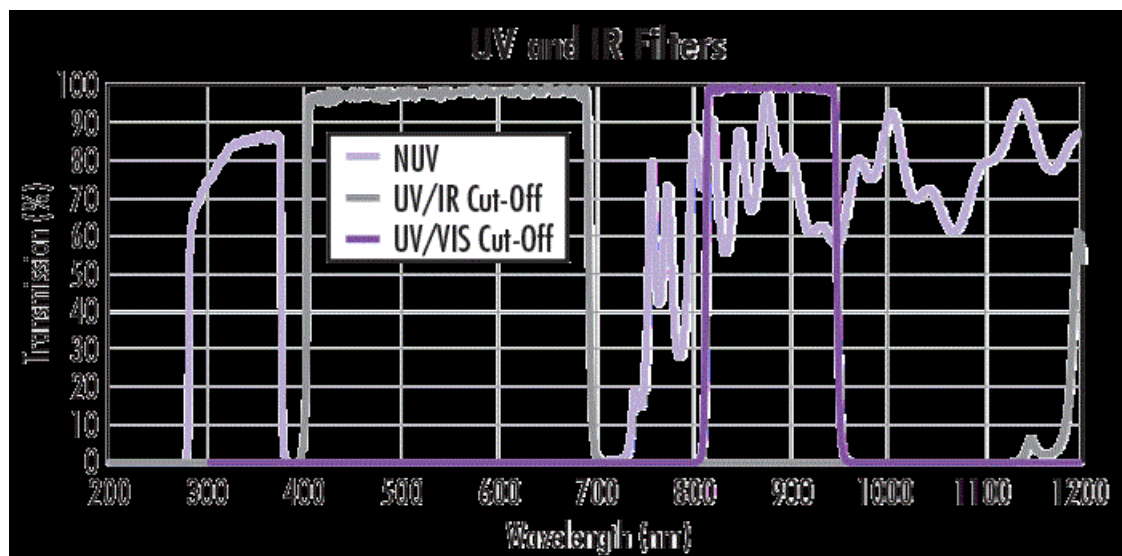

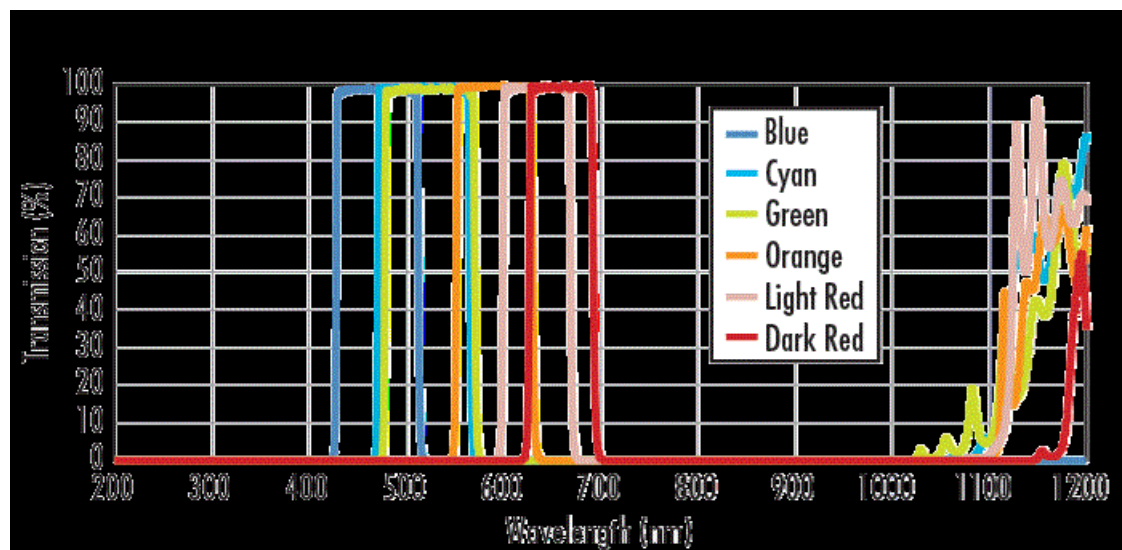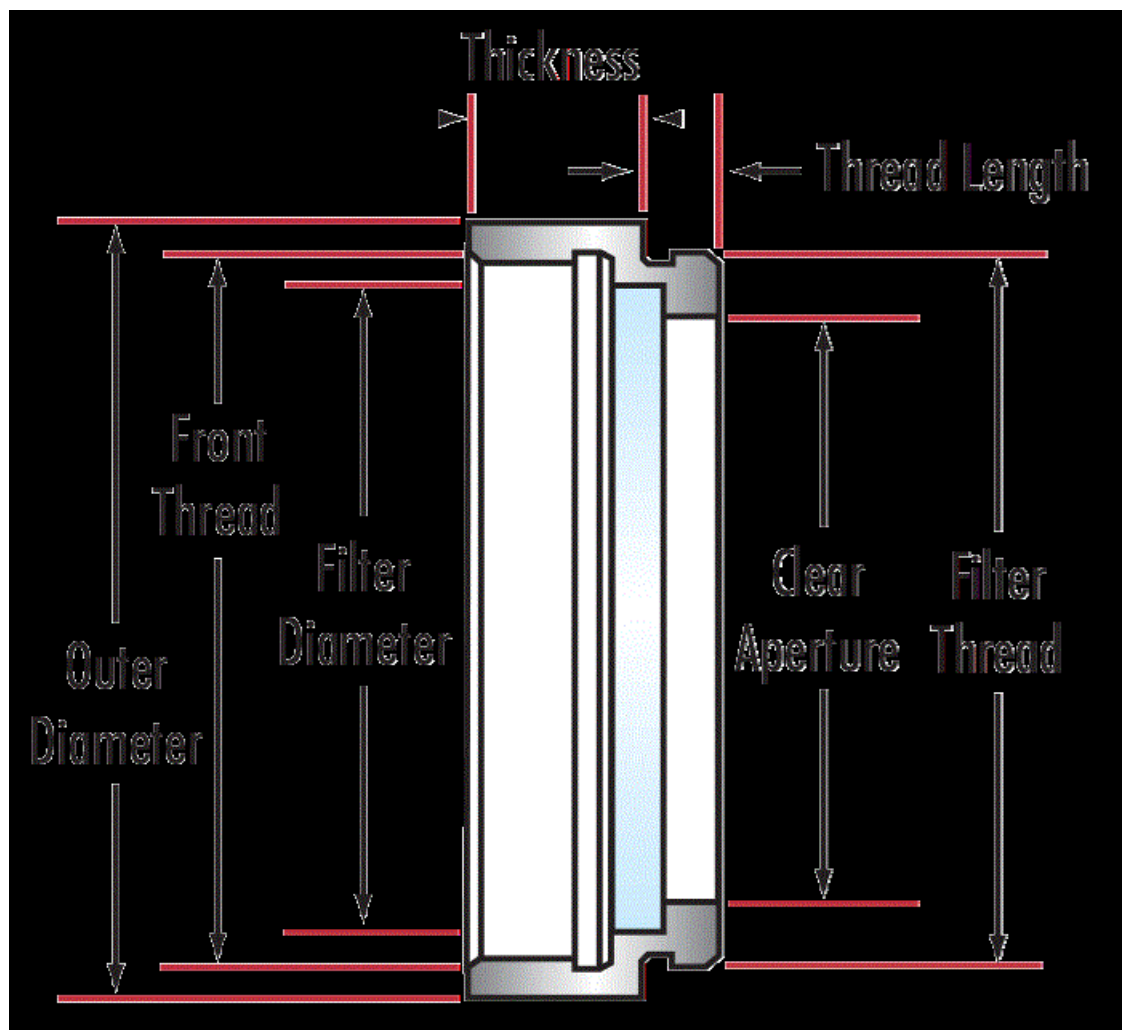

Color Machine Vision Filters

Products

Filter Thread	Color	CWL (nm)	FWHM (nm)	Stock Number	Price	Buy
M25.5 x 0.50	Light Red	633.00	70.00	#89-814	₹13,702 Volume Pricing	5 In Stock
M25.5 x 0.50	Dark Red	660.00	66.00	#89-824	₹13,702 Volume Pricing	7 In Stock
M25.5 x 0.50	Green	525.00	92.00	#89-784	₹14,636 Volume Pricing	5 In Stock
M25.5 x 0.50	Blue	470.00	85.00	#89-764	₹13,702 Volume Pricing	Contact Us
M25.5 x 0.50	IR	880.00	135.00	#89-834	₹13,702 Volume Pricing	1 In Stock
M25.5 x 0.50	VIS	548.00	290.00	#89-794	₹13,702 Volume Pricing	5 In Stock
M30.5 x 0.50	Light Red	633.00	70.00	#89-815	₹14,636 Volume Pricing	5 In Stock
M30.5 x 0.50	Dark Red	660.00	66.00	#89-825	₹14,636 Volume Pricing	1 In Stock
M30.5 x 0.50	Green	525.00	92.00	#89-785	₹14,636 Volume Pricing	4 In Stock
M30.5 x 0.50	Blue	470.00	85.00	#89-765	₹14,636 Volume Pricing	3 In Stock
M30.5 x 0.50	IR	880.00	135.00	#89-835	₹14,636 Volume Pricing	2 In Stock
M30.5 x 0.50	VIS	548.00	290.00	#89-795	₹14,636 Volume Pricing	Contact Us
M40.5 x 0.50	Light Red	633.00	70.00	#89-818	₹18,295 Volume Pricing	2 In Stock
M40.5 x 0.50	Dark Red	660.00	66.00	#89-828	₹18,295 Volume Pricing	2 In Stock
M40.5 x 0.50	Green	525.00	92.00	#89-788	₹18,295 Volume Pricing	4 In Stock
M40.5 x 0.50	Blue	470.00	85.00	#89-768	₹18,295 Volume Pricing	4 In Stock
M40.5 x 0.50	IR	880.00	135.00	#89-838	₹18,295 Volume Pricing	3 In Stock

M40.5 x 0.50	VIS	548.00	290.00	#89-798	₹18,295 Volume Pricing	8 In Stock
M43 x 0.75	Light Red	633.00	70.00	#89-819	₹19,229 Volume Pricing	4 In Stock
M43 x 0.75	Dark Red	660.00	66.00	#89-829	₹19,229 Volume Pricing	3 In Stock
M43 x 0.75	Green	525.00	92.00	#89-789	₹19,229 Volume Pricing	2 In Stock
M43 x 0.75	Blue	470.00	85.00	#89-769	₹19,229 Volume Pricing	4 In Stock
M43 x 0.75	IR	880.00	135.00	#89-839	₹19,229 Volume Pricing	1 In Stock
M43 x 0.75	VIS	548.00	290.00	#89-799	₹19,229 Volume Pricing	4 In Stock
M62 x 0.75	Light Red	633.00	70.00	#89-822	₹31,919 Volume Pricing	3 In Stock
M62 x 0.75	Dark Red	660.00	66.00	#89-832	₹31,919 Volume Pricing	3 In Stock
M62 x 0.75	Green	525.00	92.00	#89-792	₹31,919 Volume Pricing	2 In Stock
M62 x 0.75	Blue	470.00	85.00	#89-772	₹31,919 Volume Pricing	2 In Stock
M62 x 0.75	IR	880.00	135.00	#89-842	₹31,919 Volume Pricing	1 In Stock
M62 x 0.75	VIS	548.00	290.00	#89-802	₹31,919 Volume Pricing	4 In Stock
M22.5 x 0.50	NUV	325.00	106.00	#89-753	₹13,235 Volume Pricing	1 In Stock
M34 x 0.50	NUV	325.00	106.00	#89-756	₹15,492 Volume Pricing	3 In Stock
M35.5 x 0.50	NUV	325.00	106.00	#89-757	₹16,426 Volume Pricing	2 In Stock
M46 x 0.75	NUV	325.00	106.00	#89-760	₹21,954 Volume Pricing	3 In Stock
M55 x 0.75	NUV	325.00	106.00	#89-761	₹24,601 Volume Pricing	Contact Us
M22.5 x 0.50	Cyan	518.00	95.00	#89-773	₹13,235 Volume Pricing	1 In Stock
M34 x 0.50	Cyan	518.00	95.00	#89-776	₹15,492 Volume Pricing	Contact Us

M35.5 x 0.50	Cyan	518.00	95.00	#89-777	₹16,426 Volume Pricing	3 In Stock
M46 x 0.75	Cyan	518.00	95.00	#89-780	₹21,954 Volume Pricing	1 In Stock
M55 x 0.75	Cyan	518.00	95.00	#89-781	₹24,601 Volume Pricing	Contact Us
M22.5 x 0.50	Orange	590.00	78.00	#89-803	₹13,235 Volume Pricing	2 In Stock
M34 x 0.50	Orange	590.00	78.00	#89-806	₹15,570 Volume Pricing	Contact Us
M35.5 x 0.50	Orange	590.00	78.00	#89-807	₹16,426 Volume Pricing	2 In Stock
M46 x 0.75	Orange	590.00	78.00	#89-810	₹21,954 Volume Pricing	Contact Us
M55 x 0.75	Orange	590.00	78.00	#89-811	₹24,601 Volume Pricing	1 In Stock
M25.5 x 0.50	NUV	325.00	106.00	#89-754	₹13,702 Volume Pricing	3 In Stock
M30.5 x 0.50	NUV	325.00	106.00	#89-755	₹14,636 Volume Pricing	Contact Us
M40.5 x 0.50	NUV	325.00	106.00	#89-758	₹18,295 Volume Pricing	Contact Us
M43 x 0.75	NUV	325.00	106.00	#89-759	₹19,229 Volume Pricing	4 In Stock
M62 x 0.75	NUV	325.00	106.00	#89-762	₹31,919 Volume Pricing	2 In Stock
M22.5 x 0.50	Blue	470.00	85.00	#89-763	₹13,235 Volume Pricing	7 In Stock
M34 x 0.50	Blue	470.00	85.00	#89-766	₹15,492 Volume Pricing	4 In Stock
M35.5 x 0.50	Blue	470.00	85.00	#89-767	₹16,426 Volume Pricing	3 In Stock
M46 x 0.75	Blue	470.00	85.00	#89-770	₹21,954 Volume Pricing	2 In Stock
M55 x 0.75	Blue	470.00	85.00	#89-771	₹24,601 Volume Pricing	3 In Stock
M25.5 x 0.50	Cyan	518.00	95.00	#89-774	₹13,702 Volume Pricing	3 In Stock
M30.5 x 0.50	Cyan	518.00	95.00	#89-775	₹14,636 Volume Pricing	1 In Stock

M40.5 x 0.50	Cyan	518.00	95.00	#89-778	₹18,295 Volume Pricing	2 In Stock
M43 x 0.75	Cyan	518.00	95.00	#89-779	₹19,229 Volume Pricing	4 In Stock
M62 x 0.75	Cyan	518.00	95.00	#89-782	₹31,919 Volume Pricing	1 In Stock
M22.5 x 0.50	Green	525.00	92.00	#89-783	₹13,235 Volume Pricing	1 In Stock
M34 x 0.50	Green	525.00	92.00	#89-786	₹15,492 Volume Pricing	11 In Stock
M35.5 x 0.50	Green	525.00	92.00	#89-787	₹16,426 Volume Pricing	2 In Stock
M46 x 0.75	Green	525.00	92.00	#89-790	₹21,954 Volume Pricing	2 In Stock
M55 x 0.75	Green	525.00	92.00	#89-791	₹24,601 Volume Pricing	2 In Stock
M22.5 x 0.50	VIS	548.00	290.00	#89-793	₹13,235 Volume Pricing	3 In Stock
M34 x 0.50	VIS	548.00	290.00	#89-796	₹15,492 Volume Pricing	20+ In Stock
M35.5 x 0.50	VIS	548.00	290.00	#89-797	₹16,426 Volume Pricing	6 In Stock
M46 x 0.75	VIS	548.00	290.00	#89-800	₹21,954 Volume Pricing	5 In Stock
M55 x 0.75	VIS	548.00	290.00	#89-801	₹24,601 Volume Pricing	5 In Stock
M25.5 x 0.50	Orange	590.00	78.00	#89-804	₹13,702 Volume Pricing	4 In Stock
M30.5 x 0.50	Orange	590.00	78.00	#89-805	₹14,636 Volume Pricing	3 In Stock
M40.5 x 0.50	Orange	590.00	78.00	#89-808	₹18,295 Volume Pricing	Contact Us
M43 x 0.75	Orange	590.00	78.00	#89-809	₹19,229 Volume Pricing	3 In Stock
M62 x 0.75	Orange	590.00	78.00	#89-812	₹31,919 Volume Pricing	3 In Stock
M22.5 x 0.50	Light Red	633.00	70.00	#89-813	₹13,235 Volume Pricing	5 In Stock
M34 x 0.50	Light Red	633.00	70.00	#89-816	₹15,492 Volume Pricing	3 In Stock

M35.5 x 0.50	Light Red	633.00	70.00	#89-817	₹16,426 Volume Pricing	2 In Stock
M46 x 0.75	Light Red	633.00	70.00	#89-820	₹21,954 Volume Pricing	2 In Stock
M55 x 0.75	Light Red	633.00	70.00	#89-821	₹24,601 Volume Pricing	3 In Stock
M22.5 x 0.50	Dark Red	660.00	66.00	#89-823	₹13,235 Volume Pricing	2 In Stock
M34 x 0.50	Dark Red	660.00	66.00	#89-826	₹15,492 Volume Pricing	7 In Stock
M35.5 x 0.50	Dark Red	660.00	66.00	#89-827	₹16,426 Volume Pricing	3 In Stock
M46 x 0.75	Dark Red	660.00	66.00	#89-830	₹21,954 Volume Pricing	3 In Stock
M55 x 0.75	Dark Red	660.00	66.00	#89-831	₹24,601 Volume Pricing	Contact Us
M22.5 x 0.50	IR	880.00	135.00	#89-833	₹13,235 Volume Pricing	3 In Stock
M34 x 0.50	IR	880.00	135.00	#89-836	₹15,492 Volume Pricing	2 In Stock
M35.5 x 0.50	IR	880.00	135.00	#89-837	₹16,426 Volume Pricing	8 In Stock
M46 x 0.75	IR	880.00	135.00	#89-840	₹21,954 Volume Pricing	3 In Stock
M55 x 0.75	IR	880.00	135.00	#89-841	₹24,601 Volume Pricing	4 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com