

[All Products](#) / [Imaging Lenses](#) / [Fixed Focal Length Lenses](#)**TECHSPEC® Cx Series Fixed Focal Length Lenses**

- Up to 2/3", C-Mount Lens
- Up to 7.5 MegaPixels, 2.8 μ m Pixel Size Sensors
- Flexible (Cx) Version of our C Series Lenses with Interchangeable Apertures, Filters and Liquid Lens
- 12mm to 50mm Focal Length

Common Specifications

General

Series: Cx Series

Physical & Mechanical Properties

Iris Option: Fixed

Maximum Rear Protrusion (mm): 0

Optical Properties

Maximum Image Circle (mm): 11.00

Aperture (f#): Accessory Dependent

Coating: 425 - 675nm BBAR

Coating Specification: 425 - 675nm BBAR

Sensor

Maximum Sensor Format: 2/3"

Pixel Size (μm): 2.74

Threading & Mounting

Filter Thread: M25.5 x 0.50 (Male)


Filter Thread Adapter: [#89-941 \(Required\)](#)

Mount: C-Mount

Environmental & Durability Factors

Storage Temperature (°C): [-20 to +60](#)

Technical Information

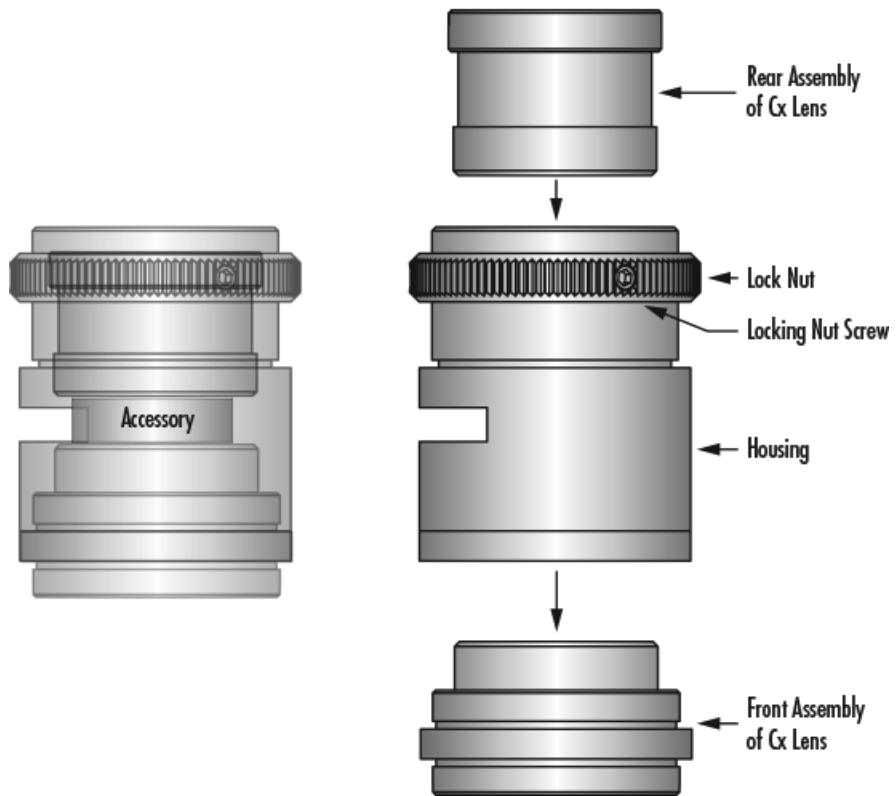

Cx Lens Assembly Diagram

Products

FL (mm)	Max. Sensor Format	Aperture (f/#)	WD (mm)	Mount	Stock Number	Price	Buy
12.00	2/3"	Accessory Dependent	100 - ∞	C- Mount	#33-562	₹15,921	20+ In Stock
16.00	2/3"	Accessory Dependent	100 - ∞	C- Mount	#33-563	₹15,921	6 In Stock
25.00	2/3"	Accessory Dependent	150 - ∞	C- Mount	#33-564	₹15,921	Contact Us
35.00	2/3"	Accessory Dependent	225 - ∞	C- Mount	#33-565	₹15,921	20+ In Stock
50.00	2/3"	Accessory Dependent	300 - 1,675	C- Mount	#33-566	₹21,402	1 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com