

[All Products](#) / [Lasers](#) / [Laser Sources](#) / [Life Science Lasers](#)

Low Cost Turnkey Lasers



- Multiple Colors and Wavelengths Available
- Ideal for Microscopy Applications
- TE Cooled



Common Specifications

General


Type of Laser: Diode

Laser Class - CDRH: IIIb

Electrical

Power Stability (%): <2% RMS over 4 hours

Technical Information

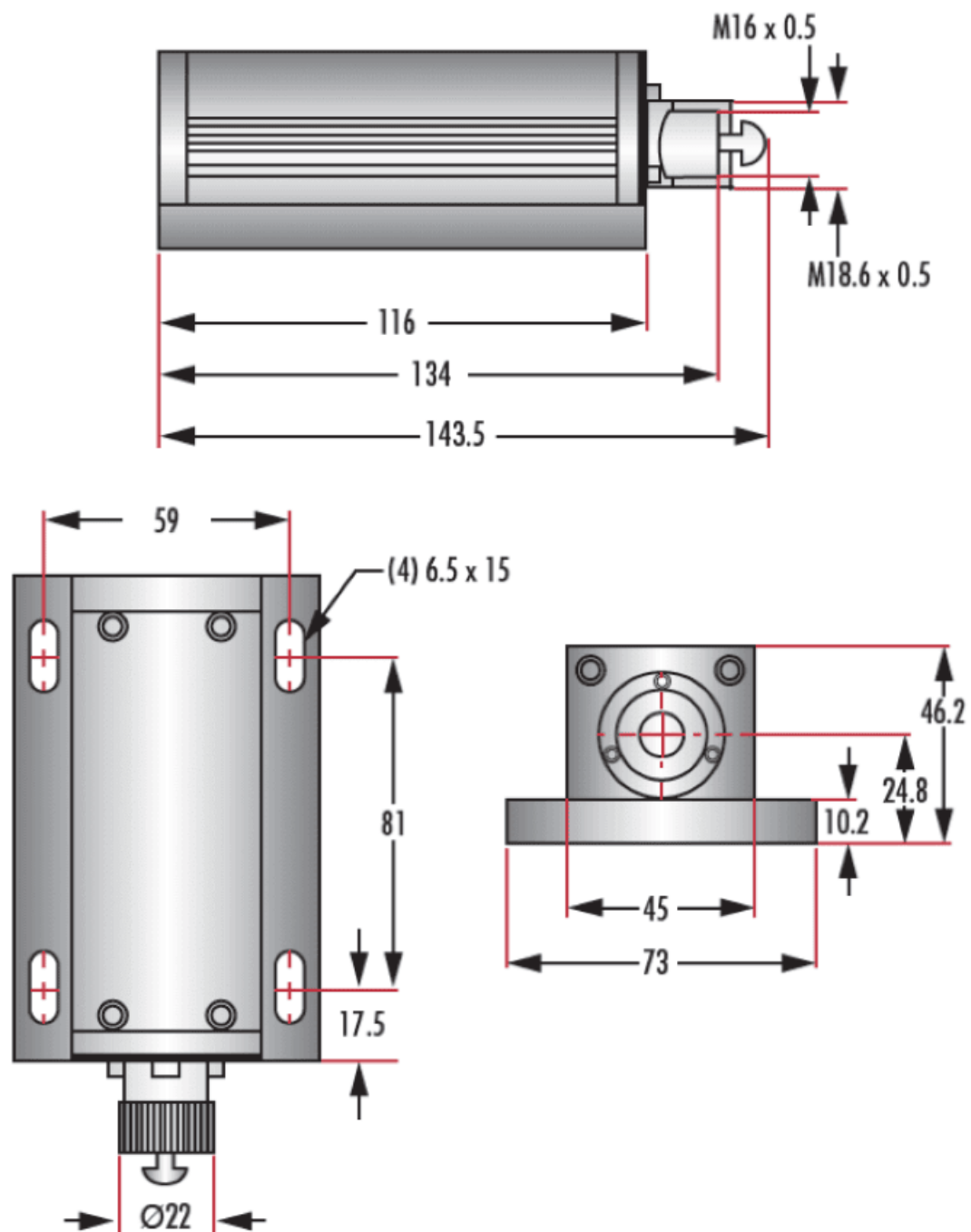

Products

Wavelength (nm)	Output Power (mW)	Output Type	Stock Number	Price	Buy
405.00	50	Free Space	#35-069	₹2,91,150 Volume Pricing	2 In Stock
473.00	50	Free Space	#35-070	₹4,14,900 Volume Pricing	2 In Stock
488.00	50	Free Space	#37-091	₹5,13,000 Volume Pricing	2 In Stock
532.00	50	Free Space	#35-072	₹2,56,500 Volume Pricing	4 In Stock
532.00	50	Fiber-Coupled	#19-486	₹3,10,050 Volume Pricing	2 In Stock
589.00	50	Free Space	#35-073	₹5,94,000 Volume Pricing	1 In Stock
640.00	50	Free Space	#35-074	₹2,61,000 Volume Pricing	2 In Stock
785.00	50	Free Space	#19-488	₹2,47,050 Volume Pricing	2 In Stock
808.00	50	Free Space	#19-489	₹2,51,550 Volume Pricing	1 In Stock
980.00	50	Free Space	#19-490	₹2,51,550 Volume Pricing	2 In Stock
1,064.00	50	Free Space	#35-075	₹2,14,650 Volume Pricing	2 In Stock
1,064.00	50	Fiber-Coupled	#19-487	₹2,86,650 Volume Pricing	2 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com