


[All Products](#) / [Optics](#) / [Polarization Optics](#) / [Retarders \(Waveplates\)](#) / [Achromatic Waveplates](#)

TECHSPEC®

Fresnel Rhomb Retarders

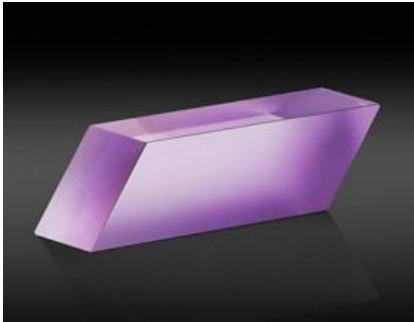

- Broadband Performance with <2% Retardance Variation
- 12.7mm and 25.4mm Options Available
- $\lambda/4$ Retardance

Common Specifications

Physical & Mechanical Properties			
Dimensional Tolerance (mm):		±0.10	Bevel: Protective as needed
Optical Properties			
Substrate:		N-BK7	Retardance: $\lambda/4$
Surface Quality:		20-10	

Technical Information

Products

Retardance	Entrance and Exit Surface (mm)	Wavelength Range (nm)	DWL (nm)	CA (mm)	Type	Stock Number	Price	Buy
$\lambda/4$	12.7	425 - 675	532	9.45 x 9.45	Fresnel Retarder	#36-140	₹26,190 Volume Pricing	20+ In Stock
$\lambda/4$	12.7	750 - 1550	1064	9.27 x 9.27	Fresnel Retarder	#36-142	₹26,190 Volume Pricing	7 In Stock
$\lambda/4$	25.4	425 - 675	532	18.81 x 18.81	Fresnel Retarder	#36-141	₹29,520 Volume Pricing	1 In Stock
$\lambda/4$	25.4	750 - 1550	1064	18.81 x 18.81	Fresnel Retarder	#36-143	₹29,520 Volume Pricing	2 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com