


[All Products](#) / [Lasers](#) / [Laser Sources](#) / [Industrial and Pointing Lasers](#)

Violet and Blue Alignment Laser Diodes

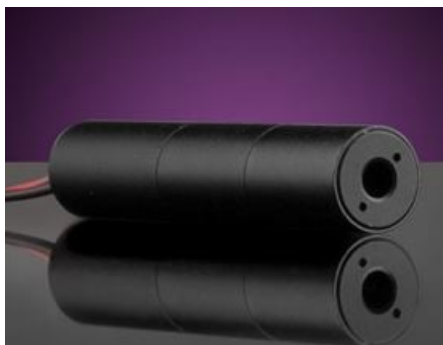

- TTL Modulation up to 10kHz
- Circular and Elliptical Beam Profiles
- Focus Adjustable



Common Specifications

Physical & Mechanical Properties

Length (mm): 36.00

Optical Properties

Wavelength Tolerance (nm): ± 5

Electrical

Modulation Frequency (kHz): 0 - 10

Hardware & Interface Connectivity

Operating Voltage (V): 5

Power Supply:

Power Supply Required and Sold Separately:

USA: [#73-818](#)

Europe: [#73-818](#)

Japan: [#13-640](#)

Korea: [#33-770](#)

China: [#73-818](#)

Technical Information

Products

Wavelength (nm)	Output Power (mW)	Beam Diameter (mm)	Beam Divergence (mrad)	Stock Number	Price	Buy
405.00	1	3.5 Typical	<0.5	#37-023	₹33,390 Volume Pricing	Contact Us
405.00	5	3.2 x 1.5	<0.5	#37-024	₹34,470 Volume Pricing	Contact Us
405.00	10	3.5 Typical	<0.5	#37-025	₹35,910 Volume Pricing	13 In Stock
405.00	25	3.5 typical	<0.5	#19-461	₹43,830 Volume Pricing	1 In Stock
450.00	1	3.5 typical	<1.0	#19-463	₹31,950 Volume Pricing	4 In Stock
450.00	5	3.5 typical	<1.0	#19-464	₹31,950 Volume Pricing	1 In Stock
450.00	10	3.5 typical	<1.0	#19-465	₹34,290 Volume Pricing	2 In Stock
450.00	25	3.5 typical	<1.0	#19-466	₹43,830 Volume Pricing	2 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com