

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Off-Axis Mirrors](#)

TECHSPEC<sup>®</sup>

Gold Off-Axis Parabolic Mirrors



- Bare or Protected Gold Coating for NIR and IR Applications
- 50Å and 100Å Surface Roughness Options
- 15°, 30°, 45°, 60°, or 90° Offset Angles
- Aluminum and Silver Coated Mirrors Also Available




Common Specifications

Optical Properties

|                                                                                                                                                                   |                                              |
|-------------------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------|
| <div>Focal Length Tolerance (%)</div> <div>±1</div>                                                                                                               | <div>Coating Type:</div> <div>Metal</div>    |
| <div>Coating Specification:</div> <div>R<sub>avg</sub>≥94% @ 700 - 800nm<br/>R<sub>avg</sub>≥97% @ 800 - 2,000nm<br/>R<sub>avg</sub>≥98% @ 2,000 - 12,000nm</div> | <div>Surface Quality:</div> <div>80-50</div> |
| <div>Substrate:</div> <div>Aluminum 6061-T6</div>                                                                                                                 |                                              |

Technical Information

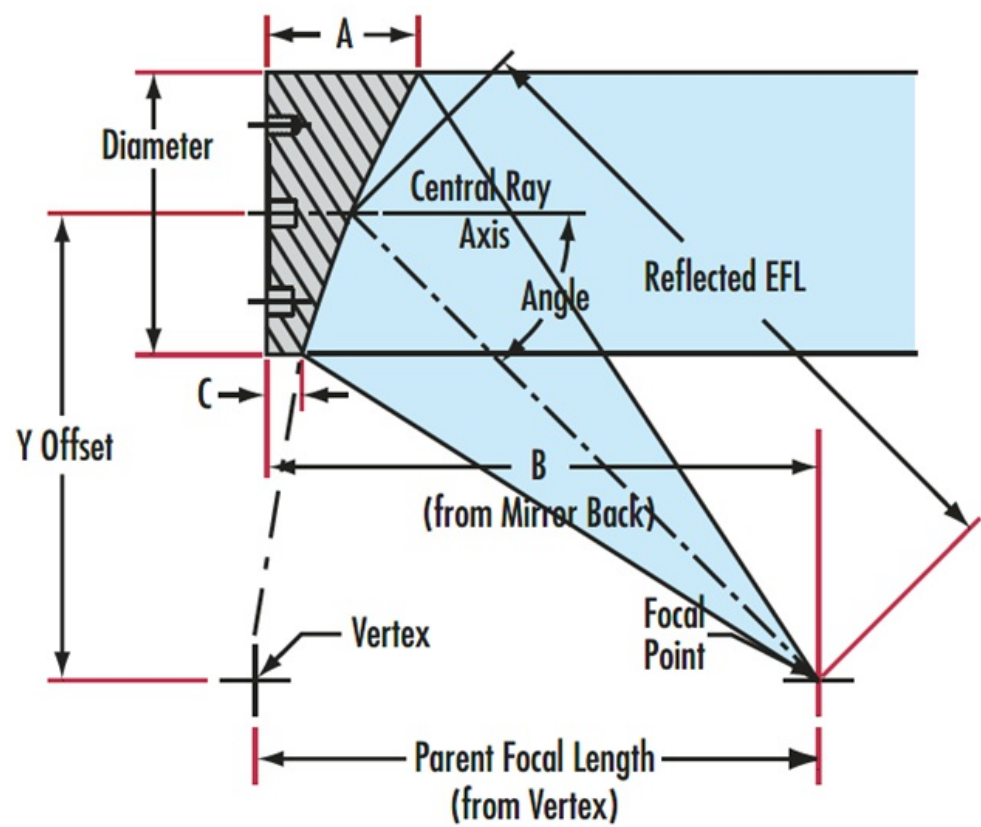

Products

| Dia.<br>(mm)                                                                        | EFL<br>(mm) | Coating                      | Off-<br>Set<br>Angle<br>(°) | Surface<br>Roughness<br>(Å) | Stock Number                                                                                                                             | Price                                     | Buy          |
|-------------------------------------------------------------------------------------|-------------|------------------------------|-----------------------------|-----------------------------|------------------------------------------------------------------------------------------------------------------------------------------|-------------------------------------------|--------------|
| 6.35                                                                                | 6.35        | Protected Gold (700-10000nm) | 90                          | <50 RMS                     | <a href="#">#37-294</a>                                                                                                                  | ₹17,127<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.35                                                                                | 12.70       | Protected Gold (700-10000nm) | 90                          | <50 RMS                     | <a href="#">#37-295</a>                                                                                                                  | ₹17,127<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 6.35                                                                                | 25.40       | Protected Gold (700-10000nm) | 90                          | <50 RMS                     | <a href="#">#37-296</a>                                                                                                                  | ₹17,127<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 6.35                                                                                | 50.80       | Protected Gold (700-10000nm) | 90                          | <50 RMS                     | <a href="#">#37-297</a>                                                                                                                  | ₹17,127<br><a href="#">Volume Pricing</a> | Contact Us   |
| <a href="#">#37-298 Clearance</a>                                                   |             |                              |                             |                             |                                                                                                                                          |                                           |              |
|  |             |                              |                             |                             |                                                                                                                                          |                                           |              |
| Clearance                                                                           |             |                              |                             |                             |                                                                                                                                          |                                           |              |
| 6.35                                                                                | 76.20       | Protected Gold (700-10000nm) | 90                          | <50 RMS                     | Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products. | ₹13,481                                   | Contact Us   |
| 6.35                                                                                | 101.60      | Protected Gold (700-10000nm) | 90                          | <50 RMS                     | <a href="#">#37-299</a>                                                                                                                  | ₹17,127<br><a href="#">Volume Pricing</a> | 5 In Stock   |

|       |        |                              |    |          |                         |                                           |             |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|-------------|
| 12.70 | 12.70  | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-270</a> | ₹19,463<br><a href="#">Volume Pricing</a> | Contact Us  |
| 12.70 | 12.70  | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-484</a> | ₹22,187<br><a href="#">Volume Pricing</a> | 9 In Stock  |
| 12.70 | 12.70  | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-487</a> | ₹17,906<br><a href="#">Volume Pricing</a> | 5 In Stock  |
| 12.70 | 25.40  | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-271</a> | ₹19,463<br><a href="#">Volume Pricing</a> | Contact Us  |
| 12.70 | 25.40  | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-485</a> | ₹22,187<br><a href="#">Volume Pricing</a> | 7 In Stock  |
| 12.70 | 25.40  | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-488</a> | ₹17,906<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 12.70 | 50.80  | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-272</a> | ₹19,463<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 12.70 | 50.80  | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-489</a> | ₹17,906<br><a href="#">Volume Pricing</a> | 17 In Stock |
| 12.70 | 76.20  | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-273</a> | ₹19,463<br><a href="#">Volume Pricing</a> | Contact Us  |
| 12.70 | 101.60 | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-274</a> | ₹19,463<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 12.70 | 203.20 | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-275</a> | ₹19,463<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 25.40 | 25.40  | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-241</a> | ₹21,409<br><a href="#">Volume Pricing</a> | 4 In Stock  |
| 25.40 | 25.40  | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-501</a> | ₹22,966<br><a href="#">Volume Pricing</a> | 9 In Stock  |

|       |       |                              |    |          |                         |                                           |              |
|-------|-------|------------------------------|----|----------|-------------------------|-------------------------------------------|--------------|
| 25.40 | 25.40 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-643</a> | ₹18,684<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.40 | 27.22 | Protected Gold (700-10000nm) | 30 | <100 RMS | <a href="#">#35-526</a> | ₹32,308<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 25.40 | 27.22 | Bare Gold                    | 30 | <100 RMS | <a href="#">#35-668</a> | ₹28,026<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 25.40 | 33.85 | Protected Gold (700-10000nm) | 60 | <100 RMS | <a href="#">#35-497</a> | ₹26,858<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 25.40 | 33.85 | Bare Gold                    | 60 | <100 RMS | <a href="#">#35-682</a> | ₹21,409<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 25.40 | 50.80 | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-242</a> | ₹21,409<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 25.40 | 50.80 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-503</a> | ₹22,966<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 25.40 | 50.80 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-644</a> | ₹18,684<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.40 | 50.80 | Protected Gold (700-10000nm) | 60 | <100 RMS | <a href="#">#35-499</a> | ₹22,966<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 25.40 | 50.80 | Bare Gold                    | 60 | <100 RMS | <a href="#">#35-683</a> | ₹18,684<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.40 | 54.45 | Protected Gold (700-10000nm) | 30 | <100 RMS | <a href="#">#35-491</a> | ₹27,248<br><a href="#">Volume Pricing</a> | Contact Us   |
| 25.40 | 54.45 | Bare Gold                    | 30 | <100 RMS | <a href="#">#35-669</a> | ₹22,966<br><a href="#">Volume Pricing</a> | Contact Us   |
| 25.40 | 76.20 | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-243</a> | ₹21,409<br><a href="#">Volume Pricing</a> | Contact Us   |
| 25.40 | 76.20 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-529</a> | ₹22,966<br><a href="#">Volume Pricing</a> | 10 In Stock  |
| 25.40 | 76.20 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-645</a> | ₹18,684<br><a href="#">Volume Pricing</a> | 20+ In Stock |

|       |        |                              |    |          |                         |                                           |            |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|
| 25.40 | 101.60 | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-244</a> | ₹21,409<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 25.40 | 101.60 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-505</a> | ₹22,966<br><a href="#">Volume Pricing</a> | 9 In Stock |
| 25.40 | 101.60 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-646</a> | ₹18,684<br><a href="#">Volume Pricing</a> | 2 In Stock |

#### [#37-245 Clearance](#)



#### Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

|       |        |                              |    |          |                         |                                           |             |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|-------------|
| 25.40 | 127.00 | Protected Gold (700-10000nm) | 90 | <50 RMS  |                         | ₹16,874                                   | 1 In Stock  |
| 25.40 | 127.00 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-567</a> | ₹28,026<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 25.40 | 127.00 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-570</a> | ₹32,308<br><a href="#">Volume Pricing</a> | 14 In Stock |
| 25.40 | 152.40 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-530</a> | ₹22,966<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 25.40 | 152.40 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-647</a> | ₹18,684<br><a href="#">Volume Pricing</a> | 6 In Stock  |
| 25.40 | 177.80 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-568</a> | ₹35,811<br><a href="#">Volume Pricing</a> | 1 In Stock  |

|       |        |                              |    |          |                         |                                           |             |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|-------------|
| 25.40 | 177.80 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-571</a> | ₹40,093<br><a href="#">Volume Pricing</a> | 4 In Stock  |
| 25.40 | 203.20 | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-248</a> | ₹21,409<br><a href="#">Volume Pricing</a> | 8 In Stock  |
| 25.40 | 203.20 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-591</a> | ₹22,966<br><a href="#">Volume Pricing</a> | 12 In Stock |
| 25.40 | 203.20 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-648</a> | ₹18,684<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 25.40 | 272.24 | Bare Gold                    | 30 | <100 RMS | <a href="#">#35-612</a> | ₹47,099<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 25.40 | 272.24 | Protected Gold (700-10000nm) | 30 | <100 RMS | <a href="#">#35-617</a> | ₹51,770<br><a href="#">Volume Pricing</a> | 5 In Stock  |
| 25.40 | 387.60 | Protected Gold (700-10000nm) | 15 | <100 RMS | <a href="#">#35-539</a> | ₹27,637<br><a href="#">Volume Pricing</a> | 3 In Stock  |
| 25.40 | 387.60 | Bare Gold                    | 15 | <100 RMS | <a href="#">#35-662</a> | ₹23,355<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 25.40 | 646.00 | Protected Gold (700-10000nm) | 15 | <100 RMS | <a href="#">#35-541</a> | ₹27,637<br><a href="#">Volume Pricing</a> | 7 In Stock  |
| 25.40 | 646.00 | Bare Gold                    | 15 | <100 RMS | <a href="#">#35-663</a> | ₹23,355<br><a href="#">Volume Pricing</a> | 3 In Stock  |

### [#35-635 Clearance](#)



#### Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

|       |       |                              |    |          |  |         |            |
|-------|-------|------------------------------|----|----------|--|---------|------------|
| 50.80 | 44.64 | Protected Gold (700-10000nm) | 45 | <100 RMS |  | ₹52,196 | 2 In Stock |
|-------|-------|------------------------------|----|----------|--|---------|------------|

---

|       |       |                              |    |         |                         |                                           |            |
|-------|-------|------------------------------|----|---------|-------------------------|-------------------------------------------|------------|
| 50.80 | 50.80 | Protected Gold (700-10000nm) | 90 | <50 RMS | <a href="#">#37-308</a> | ₹39,704<br><a href="#">Volume Pricing</a> | 8 In Stock |
|-------|-------|------------------------------|----|---------|-------------------------|-------------------------------------------|------------|

---

|       |       |                              |    |          |                         |                                           |              |
|-------|-------|------------------------------|----|----------|-------------------------|-------------------------------------------|--------------|
| 50.80 | 50.80 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-507</a> | ₹40,093<br><a href="#">Volume Pricing</a> | 20+ In Stock |
|-------|-------|------------------------------|----|----------|-------------------------|-------------------------------------------|--------------|

---

|       |       |           |    |          |                         |                                           |            |
|-------|-------|-----------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 50.80 | Bare Gold | 90 | <100 RMS | <a href="#">#35-649</a> | ₹35,811<br><a href="#">Volume Pricing</a> | Contact Us |
|-------|-------|-----------|----|----------|-------------------------|-------------------------------------------|------------|

---

|       |       |                              |    |          |                         |                                           |            |
|-------|-------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 54.45 | Protected Gold (700-10000nm) | 30 | <100 RMS | <a href="#">#35-493</a> | ₹42,039<br><a href="#">Volume Pricing</a> | 2 In Stock |
|-------|-------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|

---

|       |       |           |    |          |                         |                                           |            |
|-------|-------|-----------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 54.45 | Bare Gold | 30 | <100 RMS | <a href="#">#35-622</a> | ₹38,147<br><a href="#">Volume Pricing</a> | 3 In Stock |
|-------|-------|-----------|----|----------|-------------------------|-------------------------------------------|------------|

---

|       |       |                              |    |          |                         |                                           |            |
|-------|-------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 59.51 | Protected Gold (700-10000nm) | 45 | <100 RMS | <a href="#">#35-551</a> | ₹41,650<br><a href="#">Volume Pricing</a> | 4 In Stock |
|-------|-------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|

---

|       |       |           |    |          |                         |                                           |            |
|-------|-------|-----------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 59.51 | Bare Gold | 45 | <100 RMS | <a href="#">#35-678</a> | ₹37,368<br><a href="#">Volume Pricing</a> | 1 In Stock |
|-------|-------|-----------|----|----------|-------------------------|-------------------------------------------|------------|

---

|       |       |                              |    |         |                         |                                           |            |
|-------|-------|------------------------------|----|---------|-------------------------|-------------------------------------------|------------|
| 50.80 | 76.20 | Protected Gold (700-10000nm) | 90 | <50 RMS | <a href="#">#37-989</a> | ₹39,704<br><a href="#">Volume Pricing</a> | 6 In Stock |
|-------|-------|------------------------------|----|---------|-------------------------|-------------------------------------------|------------|

---

|       |        |                              |    |          |                         |                                           |             |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|-------------|
| 50.80 | 76.20  | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-509</a> | ₹40,093<br><a href="#">Volume Pricing</a> | 5 In Stock  |
| 50.80 | 76.20  | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-650</a> | ₹35,811<br><a href="#">Volume Pricing</a> | 11 In Stock |
| 50.80 | 81.67  | Bare Gold                    | 30 | <100 RMS | <a href="#">#35-613</a> | ₹38,147<br><a href="#">Volume Pricing</a> | 4 In Stock  |
| 50.80 | 81.67  | Protected Gold (700-10000nm) | 30 | <100 RMS | <a href="#">#35-618</a> | ₹42,039<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 50.80 | 89.28  | Protected Gold (700-10000nm) | 45 | <100 RMS | <a href="#">#35-553</a> | ₹41,650<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 50.80 | 89.28  | Bare Gold                    | 45 | <100 RMS | <a href="#">#35-679</a> | ₹37,368<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 50.80 | 101.60 | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-309</a> | ₹39,704<br><a href="#">Volume Pricing</a> | 6 In Stock  |
| 50.80 | 101.60 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-511</a> | ₹40,093<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 50.80 | 101.60 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-651</a> | ₹35,811<br><a href="#">Volume Pricing</a> | 6 In Stock  |
| 50.80 | 101.60 | Protected Gold (700-10000nm) | 60 | <100 RMS | <a href="#">#35-528</a> | ₹43,985<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 50.80 | 101.60 | Bare Gold                    | 60 | <100 RMS | <a href="#">#35-686</a> | ₹40,093<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 50.80 | 108.89 | Protected Gold (700-10000nm) | 30 | <100 RMS | <a href="#">#35-495</a> | ₹42,039<br><a href="#">Volume Pricing</a> | 3 In Stock  |
| 50.80 | 108.89 | Bare Gold                    | 30 | <100 RMS | <a href="#">#35-641</a> | ₹38,147<br><a href="#">Volume Pricing</a> | 3 In Stock  |

[#47-090 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

|       |        |                              |    |          |  |         |            |
|-------|--------|------------------------------|----|----------|--|---------|------------|
| 50.80 | 108.89 | Protected Gold (700-10000nm) | 30 | <175 RMS |  | ₹34,796 | 1 In Stock |
|-------|--------|------------------------------|----|----------|--|---------|------------|

|       |        |           |    |          |                         |                                           |            |
|-------|--------|-----------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 136.12 | Bare Gold | 30 | <100 RMS | <a href="#">#35-614</a> | ₹41,650<br><a href="#">Volume Pricing</a> | 4 In Stock |
|-------|--------|-----------|----|----------|-------------------------|-------------------------------------------|------------|

|       |        |                              |    |          |                         |                                           |            |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 136.12 | Protected Gold (700-10000nm) | 30 | <100 RMS | <a href="#">#35-619</a> | ₹45,542<br><a href="#">Volume Pricing</a> | 4 In Stock |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|

|       |        |                              |    |          |                         |                                           |            |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 152.40 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-513</a> | ₹40,093<br><a href="#">Volume Pricing</a> | Contact Us |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|

|       |        |           |    |          |                         |                                           |            |
|-------|--------|-----------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 152.40 | Bare Gold | 90 | <100 RMS | <a href="#">#35-652</a> | ₹35,811<br><a href="#">Volume Pricing</a> | 1 In Stock |
|-------|--------|-----------|----|----------|-------------------------|-------------------------------------------|------------|

|       |        |                              |    |          |                         |                                           |            |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 177.80 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-531</a> | ₹40,093<br><a href="#">Volume Pricing</a> | 1 In Stock |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|

|       |        |           |    |          |                         |                                           |            |
|-------|--------|-----------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 177.80 | Bare Gold | 90 | <100 RMS | <a href="#">#35-653</a> | ₹35,811<br><a href="#">Volume Pricing</a> | 1 In Stock |
|-------|--------|-----------|----|----------|-------------------------|-------------------------------------------|------------|

|       |        |                              |    |          |                         |                                           |            |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 190.50 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-532</a> | ₹40,093<br><a href="#">Volume Pricing</a> | Contact Us |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|

|       |        |           |    |          |                         |                                           |            |
|-------|--------|-----------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 190.50 | Bare Gold | 90 | <100 RMS | <a href="#">#35-654</a> | ₹35,811<br><a href="#">Volume Pricing</a> | 9 In Stock |
|-------|--------|-----------|----|----------|-------------------------|-------------------------------------------|------------|

|       |        |                              |    |          |                         |                                           |            |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|------------|
| 50.80 | 190.60 | Protected Gold (700-10000nm) | 90 | <50 RMS  | <a href="#">#37-992</a> | ₹39,704<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 50.80 | 272.24 | Bare Gold                    | 30 | <100 RMS | <a href="#">#35-615</a> | ₹38,147<br><a href="#">Volume Pricing</a> | 2 In Stock |
| 50.80 | 272.24 | Protected Gold (700-10000nm) | 30 | <100 RMS | <a href="#">#35-620</a> | ₹42,039<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 50.80 | 310.08 | Bare Gold                    | 15 | <100 RMS | <a href="#">#35-664</a> | ₹31,140<br><a href="#">Volume Pricing</a> | 2 In Stock |
| 50.80 | 310.08 | Protected Gold (700-10000nm) | 15 | <100 RMS | <a href="#">#35-543</a> | ₹35,422<br><a href="#">Volume Pricing</a> | 2 In Stock |
| 50.80 | 387.60 | Bare Gold                    | 15 | <100 RMS | <a href="#">#35-598</a> | ₹31,140<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 50.80 | 387.60 | Protected Gold (700-10000nm) | 15 | <100 RMS | <a href="#">#35-602</a> | ₹35,422<br><a href="#">Volume Pricing</a> | 4 In Stock |
| 50.80 | 516.81 | Protected Gold (700-10000nm) | 15 | <100 RMS | <a href="#">#35-545</a> | ₹35,422<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 50.80 | 516.81 | Bare Gold                    | 15 | <100 RMS | <a href="#">#35-665</a> | ₹31,140<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 76.20 | 50.80  | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-533</a> | ₹76,293<br><a href="#">Volume Pricing</a> | 8 In Stock |
| 76.20 | 50.80  | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-655</a> | ₹72,401<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 76.20 | 76.20  | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-534</a> | ₹63,448<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 76.20 | 76.20  | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-656</a> | ₹59,166<br><a href="#">Volume Pricing</a> | 8 In Stock |
| 76.20 | 89.28  | Protected Gold (700-10000nm) | 45 | <100 RMS | <a href="#">#35-587</a> | ₹72,011<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 76.20 | 89.28  | Bare Gold                    | 45 | <100 RMS | <a href="#">#35-680</a> | ₹67,340<br><a href="#">Volume Pricing</a> | 2 In Stock |

|       |        |                              |    |          |                         |                                           |             |
|-------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|-------------|
| 76.20 | 101.60 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-569</a> | ₹59,166<br><a href="#">Volume Pricing</a> | 3 In Stock  |
| 76.20 | 101.60 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-572</a> | ₹63,448<br><a href="#">Volume Pricing</a> | 11 In Stock |
| 76.20 | 127.00 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-535</a> | ₹61,502<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 76.20 | 127.00 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-657</a> | ₹57,220<br><a href="#">Volume Pricing</a> | 5 In Stock  |
| 76.20 | 152.40 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-536</a> | ₹61,502<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 76.20 | 152.40 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-658</a> | ₹57,220<br><a href="#">Volume Pricing</a> | 6 In Stock  |
| 76.20 | 177.80 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-537</a> | ₹61,502<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 76.20 | 177.80 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-659</a> | ₹57,220<br><a href="#">Volume Pricing</a> | Contact Us  |
| 76.20 | 178.53 | Protected Gold (700-10000nm) | 45 | <100 RMS | <a href="#">#35-589</a> | ₹63,448<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 76.20 | 178.53 | Bare Gold                    | 45 | <100 RMS | <a href="#">#35-681</a> | ₹59,166<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 76.20 | 272.23 | Protected Gold (700-10000nm) | 30 | <100 RMS | <a href="#">#35-581</a> | ₹65,005<br><a href="#">Volume Pricing</a> | 4 In Stock  |
| 76.20 | 272.23 | Bare Gold                    | 30 | <100 RMS | <a href="#">#35-671</a> | ₹61,112<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 76.20 | 646.00 | Bare Gold                    | 15 | <100 RMS | <a href="#">#35-601</a> | ₹61,112<br><a href="#">Volume Pricing</a> | Contact Us  |
| 76.20 | 646.00 | Protected Gold (700-10000nm) | 15 | <100 RMS | <a href="#">#35-605</a> | ₹65,005<br><a href="#">Volume Pricing</a> | 7 In Stock  |

|        |        |                              |    |          |                         |                                           |              |
|--------|--------|------------------------------|----|----------|-------------------------|-------------------------------------------|--------------|
| 101.60 | 101.60 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-688</a> | ₹75,904<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 101.60 | 101.60 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-573</a> | ₹80,575<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 101.60 | 119.03 | Bare Gold                    | 45 | <100 RMS | <a href="#">#35-633</a> | ₹72,401<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 101.60 | 119.03 | Protected Gold (700-10000nm) | 45 | <100 RMS | <a href="#">#35-639</a> | ₹76,293<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 101.60 | 152.40 | Bare Gold                    | 90 | <100 RMS | <a href="#">#35-660</a> | ₹75,904<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 101.60 | 152.40 | Protected Gold (700-10000nm) | 90 | <100 RMS | <a href="#">#35-593</a> | ₹80,575<br><a href="#">Volume Pricing</a> | 16 In Stock  |
| 101.60 | 178.55 | Bare Gold                    | 45 | <100 RMS | <a href="#">#35-634</a> | ₹72,401<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 101.60 | 178.55 | Protected Gold (700-10000nm) | 45 | <100 RMS | <a href="#">#35-640</a> | ₹76,293<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 101.60 | 326.69 | Bare Gold                    | 30 | <100 RMS | <a href="#">#35-623</a> | ₹75,904<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 101.60 | 387.60 | Protected Gold (700-10000nm) | 30 | <100 RMS | <a href="#">#35-585</a> | ₹80,575<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 101.60 | 387.60 | Bare Gold                    | 15 | <100 RMS | <a href="#">#35-575</a> | ₹76,293<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 101.60 | 516.81 | Bare Gold                    | 15 | <100 RMS | <a href="#">#35-667</a> | ₹72,401<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 101.60 | 516.81 | Protected Gold (700-10000nm) | 15 | <100 RMS | <a href="#">#35-577</a> | ₹76,293<br><a href="#">Volume Pricing</a> | Contact Us   |



**Edmund**  
optics | worldwide

Copyright © 2023 Edmund Optics India Private Limited, #267 Grey Stone Building, Second Floor, 6th Cross Rd, Binnamangla, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :  
[www.edmundoptics.com](http://www.edmundoptics.com)