


[All Products](#) / [Optics](#) / [Diffractive Optical Elements \(DOE\)](#)

HOLO/OR Diffractive Diffusers

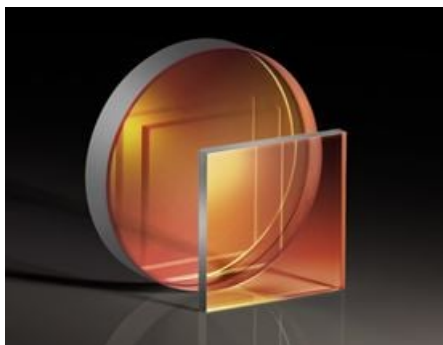

- Shape Laser Beams with Homogenized Distribution
- Circular or Square Output Shapes
- Designs for 532nm and 1064nm Nd:YAG Lasers
- Compatible with Single Mode or Multimode Beams

Common Specifications

Optical Properties

Substrate: Fused Silica (Corning 7980)	Input Beam Mode: SM or MM
Damage Threshold, Reference: See Link for More Details	

Technical Information

Products

Title	Stock Number	Price	Buy
1064nm, 20mm Dia., Square Output, High Homogeneity Diffractive Diffuser	#14-681	₹1,40,832	5 In Stock
1064nm, 15mm Dia., Round Output, Diffractive Diffuser	#14-682	₹97,189	1 In Stock
532nm, 15 x 15mm, Round Output, High Homogeneity Diffractive Diffuser	#14-683	₹1,76,774	9 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com