

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Aspheric Lenses](#) / [Glass Molded](#)

TECHSPEC® Precision Molded Aspheric Lenses



- Precision Glass Molded Lenses
- Ideal for High Volume Production Requirements
- Available in Convenient Packs of 10 for Volume Integration

Common Specifications


Physical & Mechanical Properties

Centering (arcmin):	≤5	Bevel:	Protective as needed
Shape of Back Surface:	Plano	Surface Roughness (Å):	22 (typical)

Optical Properties

Substrate:	L-BAL35	Asphere Figure Error, RMS @ 632.8nm:	1.2λ
Surface Quality:	60-40	Conjugate Distance:	Infinite

Technical Information

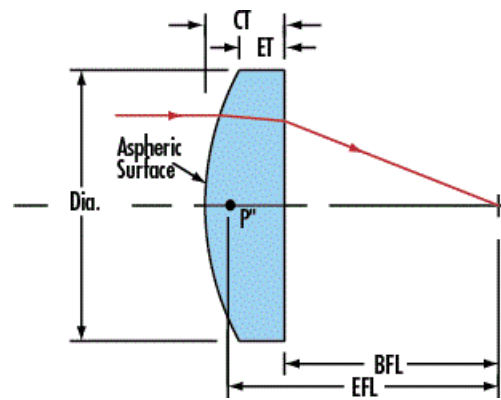

Products

Title	Stock Number	Price	Buy
25mm Dia., 0.50 Numerical Aperture, Uncoated, Precision Molded Aspheric Lens	#17-082	₹18,606	20+ In Stock
25mm Dia., 0.50 Numerical Aperture, Uncoated, Precision Molded Aspheric Lens (Pack of 10)	#17-156	₹1,29,620 Volume Pricing	1 In Stock
15mm Dia., 0.66 Numerical Aperture, Uncoated, Precision Molded Aspheric Lens	#29-506	₹14,558	20+ In Stock
15mm Dia., 0.66 Numerical Aperture, VIS Coated, Precision Molded Aspheric Lens	#29-507	₹16,193	20+ In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com