


[All Products](#) / [Cameras](#) / [Gigabit Ethernet Cameras](#)

Teledyne DALSA Genie™ Nano 10GigE Cameras See More by [Teledyne DALSA](#)

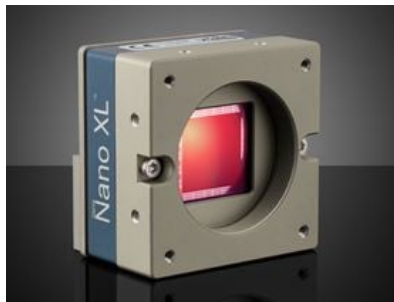

- Up to 67.10 MP Resolution with Framrates up to 18.50FPS
- Supports Trigger-to-Image Reliability (T2IR) Framework
- Compact (44 x 59 x 59mm), M42-Mount, Lightweight, and Robust All Metal Design



Common Specifications

General

Manufacturer:	Teledyne DALSA	Camera Series:	Genie Nano-10GigE
----------------------	----------------	-----------------------	-------------------

Physical & Mechanical Properties

Dimensions (mm):	59 x 59 x 41 (excludes connectors and lens mount)	Weight (g):	183
-------------------------	---	--------------------	-----

Housing:	Full
-----------------	------

Sensor

Pixel Size, H x V (µm):	2.50 x 2.50
--------------------------------	-------------

Type of Sensor:	Progressive Scan CMOS	Shutter Type:	Global
------------------------	-----------------------	----------------------	--------

Pixel Depth:	8/10 bit	Exposure Time:	Automatic, Programmable, or via External Trigger
---------------------	----------	-----------------------	--

Dynamic Range (dB):	62.00	Machine Vision Standard:	GigE Vision v2.0
----------------------------	-------	---------------------------------	------------------

Electrical

Power Consumption (W):	12.5
-------------------------------	------

Hardware & Interface Connectivity

Interface:	10GigE (PoE)
-------------------	--------------

Connector:	5GigE, RJ45 with Screw Locks	GPIOs:	2 opto-isolated input, 3 opto-isolated output
Synchronization:	Hardware Trigger (GPIO) or Software Trigger	Interface Port Orientation:	Back Panel
GPIO Connector Type:	6-pin Hirose (HR10)		

Threading & Mounting

Mount:	M42-Mount
Mounting Threads:	1/4-20 with Tripod Mount Adapter #34-966

Environmental & Durability Factors

Operating Temperature (°C):	-20 to +60
Storage Temperature (°C):	-30 to +60

Technical Information

Products

Type	Model Number	Sensor Format	Resolution (Megapixels)	Connector	Mount	Stock Number	Price	Buy
Color Camera	G6-GC31-C6205	1.4"	37.70	5GigE, RJ45 with Screw Locks	M42-Mount	#28-677	₹5,11,560	Contact Us
Monochrome Camera	G6-GM31-M6205	1.4"	37.70	5GigE, RJ45 with Screw Locks	M42-Mount	#28-678	₹4,93,290	1 In Stock
Color Camera	G6-GC31-C8205	APS-C	67.10	5GigE, RJ45 with Screw Locks	M42-Mount	#28-679	₹6,11,610	1 In Stock
Monochrome Camera	G6-GM31-M8205	APS-C	67.10	5GigE, RJ45 with Screw Locks	M42-Mount	#28-680	₹5,93,775	1 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

www.edmundoptics.com