

[All Products](#) / [Lights and Illumination](#) / [Microscopy Lighting](#) / [Fiber Optic Illuminators](#)

## SCHOTT KL Fiber Optic Light Sources See More by [SCHOTT Optical Components](#)



- Maximum Light Intensity of 1100 Lumens
- Continuous Dimming from 0 - 100%
- Various Light Guide Options Available
- Ideal for Use with Stereo Microscopes

# Common Specifications


General			
Operating Lifetime (hours):	>50,000	Intensity Control Option:	Yes
Type of Illumination:	LED Illuminator	Manufacturer:	SCHOTT
Illumination Mode:	Constant		

Physical & Mechanical Properties	
Dimensions (mm):	114L x 231W x 137H
Optical Properties	
Color:	White

Hardware & Interface Connectivity			
Input Voltage (V):	24 DC		
Power Supply:	Power Cord Required and Sold Separately: USA: <a href="#">#16-792</a> Europe: <a href="#">#18-492</a> Japan: <a href="#">#78-580</a> Korea: <a href="#">#16-792</a> China: <a href="#">#16-792</a> UK: <a href="#">#18-493</a> Switzerland: <a href="#">#18-494</a>		

Environmental & Durability Factors			
Color Temperature (K):	5600		

# Technical Information

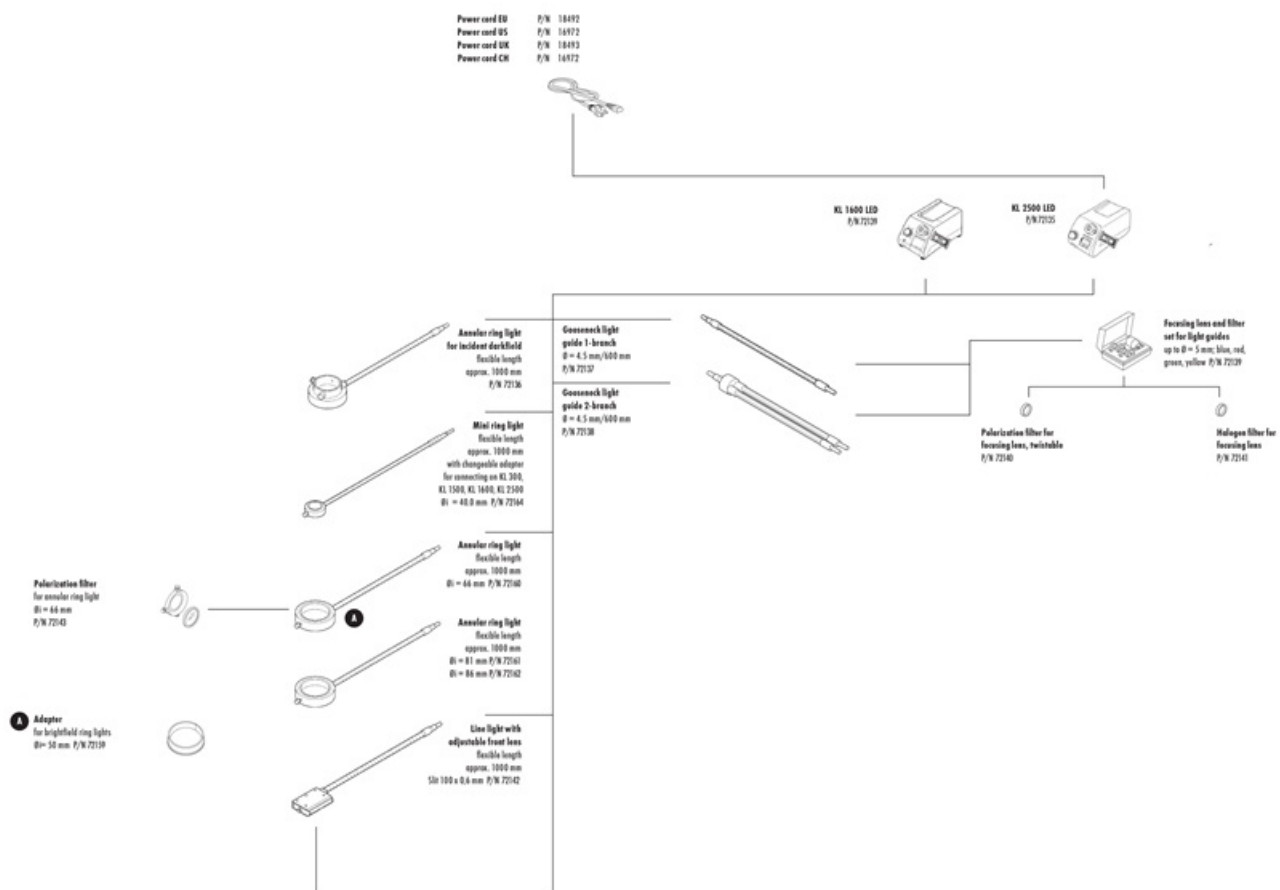

**SCHOTT**  
glass made of ideas

## Products

Title	Stock Number	Price	Buy
Schott KL 1600 LED Light Source	<a href="#">#72-134</a>	₹87,840	2 In Stock
Schott KL 2500 LED Light Source	<a href="#">#72-135</a>	₹1,30,950	1 In Stock



Copyright 2023, Edmund Optics India Private Limited, #267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038

Phone: 1-800-363-1992 :

[www.edmundoptics.com](http://www.edmundoptics.com)